


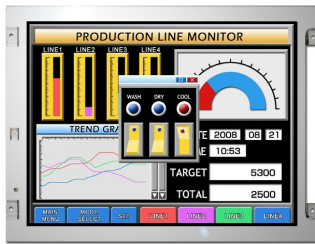

PRODUCT DETAILS

[Find More Products ▶](#)
[Request More Info](#)


Part Number

NL8060BC21-11

Diagonal Size (in)	8.4
Pixel Resolution	800 x 600
Interface	LVDS
Display Mode	TN
Technology	a-Si
Display Module Size (mm)	200 x 152.0 x 8.2
Display Active Area (mm)	
Aspect Ratio	4:3
Backlight Luminance (nits)	400
LED Driver	104PW03F
Contrast Ratio	800:1
Viewing Angles (T/B/L/R)	80/80/80/80
Driver IC	
Response Time (ms)	18
Operating Temperature (°C)	-30 to 80
Touch Panel	
Others	

