
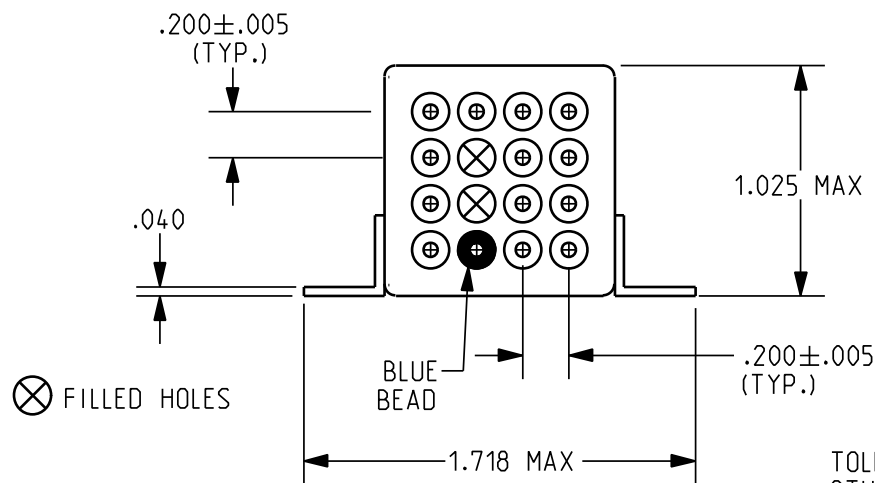


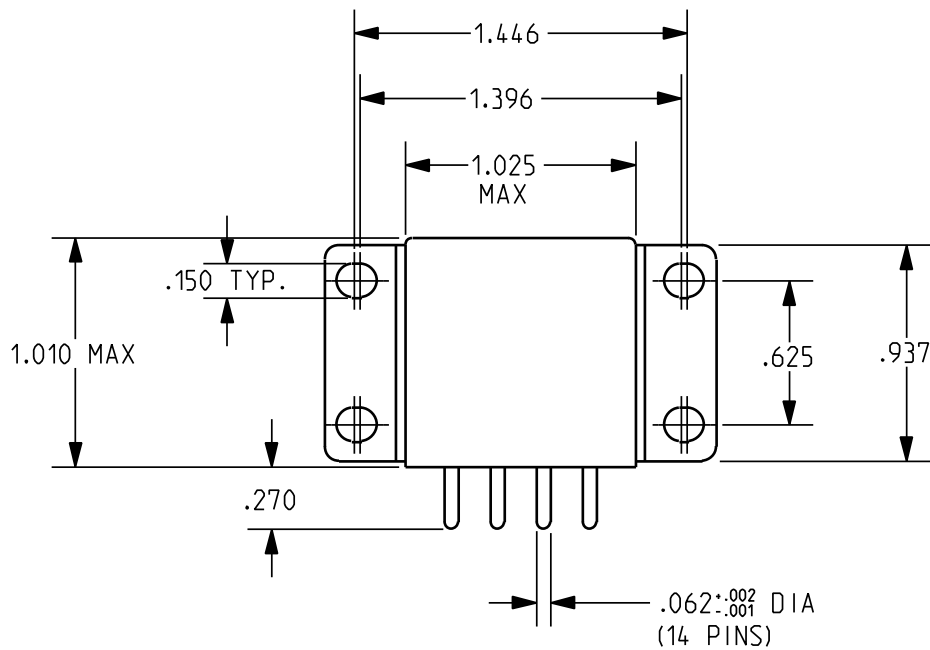

REV. A
DCO 300859


TOLERANCES ±.010" - UNLESS
OTHERWISE SPECIFIED

COIL: @ 25°C
 RESISTANCE 290 OHMS ±10%
 NOMINAL VOLTAGE 28 VDC
 MUST OPERATE 13.5 VDC MAX.
 COIL TRANSIENT SUPPRESSION: 42 VDC MAX.
 MUST RELEASE 5.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:
 VIBRATION 57 Hz TO 3000 Hz @ 20 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -70 °C TO +125 °C

NOTES: OPERATE, RELEASE 15 MS MAX.
 CONTACT BOUNCE 1 MS MAX.
 CONTACT BREAK BOUNCE 0.1 MS MAX.

CUSTOMER DATA SHEET

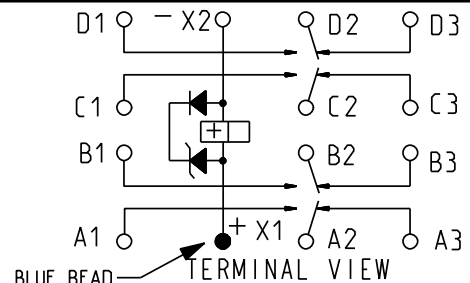

CONTACT RATING:
 10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
 100,000 OPERATIONS

DR. B.D. 16MAY2008 CK. J.M.B. 5/19/08

Tyco Electronics

©COPYRIGHT 2005
 TYCO ELECTRONICS CORPORATION
 ALL INTERNATIONAL RIGHTS RESERVED

CUST. CATALOG ITEM
 CUST. NO. ---- REV. ----

TE NUMBER
 8-1617755-7

CII PART NUMBER
 FCA-410-BX4