



BD070LIC2 (DISPLAY KIT + PLEXIGLASS STAND)

7" 1280x800 Display with PCAP Multi-touch.
BD070LIC2 includes display + touchscreen unit and display kit with a PlexiGlass stand
Contact us for volume pricing

25 in stock (can be backordered)

[Add to cart](#)

The BD070LIC2 is a 7" Display with 1280×800 resolution with 5-point PCAP multi-touch. This is the replacement panel for the BD070LIC1. This 7" display has the Tianma TM070JDHG30-00. The touch screen is a PCAP multi-touch with an I2C interface and Chemically Hardened Glass using an FT5426 touch controller. The display kit ships with a daughter board and cable that interfaces with all Boundary Devices i.MX6 boards. Touch Screen Driver is integrated with all Boundary Devices kernels.

If you wish to purchase without the Plexiglass stand purchase [BD070LIC2_NoPlexi](#). if you would like the display + touchscreen unit without any accessories purchase [BD070LIC2_DSP](#)

Please make sure to upgrade to the latest 2016 uboot. For 3.14 and newer kernels, just use this environment variable:


```
setenv fb_lvsd tm070jdhg30:24:68152388,1280,800,5,63,2,39,1,1
savee
```

For older kernels, you will need to modify the bootscript to use this display with the above timings.

Compatible Products



BD-SL-i.MX6

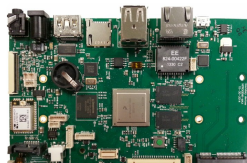

Nitrogen6_MAX



Nitrogen6X



Nitrogen6 SoloX

formerly SABRE Lite

i.MX6Q/QPlus + 4GB

NXP i.MX6 Based SBC

i.MX6 SoloX


DDR3



Nitrogen6 Lite

i.MX6 Solo, 512MB

DDR3

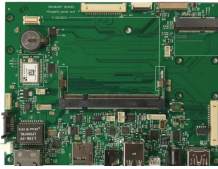

Nit6X_Carrier



[Products](#)

[Custom](#)

[Video Reviews](#)

[Where To Buy](#)

[Support](#)

[Contact](#)

[Log In](#)

[Blog](#)

[About Us](#)

[Careers](#)

[Privacy Policy](#)

[Return Policy](#)

[Terms and Conditions](#)

Register for Downloads

[Go!](#)

Product Selector Guide

Still not sure about exactly what you need? Check out our informative guide!

[Go!](#)