

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0731337003

Status:

Active

Overview:

BNC Miniature RF Connectors and Cable Assemblies

Description:


75 Ohms, BNC Vertical PCB Jack Receptacle

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	RF/Coax Connectors
Series	73133
Overview	BNC Miniature RF Connectors and Cable Assemblies
Product Name	BNC
Style	PCB
Type	Miniature
UPC	800753680388
Wire/Cable Type	N/A
Physical	
Cable Attachment	N/A
Gender	Jack
Keying to Mating Part	None
Net Weight	8.698/g
Orientation	Straight
PCB Mounting	Through Hole
PCB Thickness - Recommended	3.90mm
Packaging Type	Bag
Panel Mount	No
Panel Mount Method	N/A
Reverse Polar	No
Electrical	
Frequency	2 GHz
Impedance	75Ω
Power / Voltage	VOLTAGE: 500 Vrms@Sea Level
Solder Process Data	
Duration at Max. Process Temperature (seconds)	010
Lead-freeProcess Capability	SMC&WAVE
Max. Cycles at Max. Process Temperature	001
Process Temperature max. C	260
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SDA-73133-7003

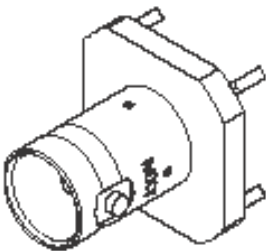

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2020)4578-DC (25 June 2020)	
Lead	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

73133 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION