

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1040921500](#)
Status: **Active**
Description: IllumiMate 1.25mm Pitch Wire-to-Board Crimp Housing, Single Row, 15 Circuits, Natural

Documents:

[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-104091-001-001 \(PDF\)](#)
[Packaging Specification PK-104092-001-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Crimp Housings
Series [104092](#)
Application Signal, Wire-to-Board
Product Name IllumiMate
UPC 887191147536

Physical

Circuits (maximum) 15
Color - Resin Natural
Gender Receptacle
Glow-Wire Capable No
Keying to Mating Part None
Lock to Mating Part Yes
Material - Resin High Temperature Thermoplastic
Net Weight 0.411/g
Number of Rows 1
Packaging Type Embossed Tape on Reel
Panel Mount No
Pitch - Mating Interface 1.25mm
Polarized to Mating Part Yes
Temperature Range - Operating -25° to +130°C

Electrical

Current - Maximum per Contact 1.5A


Solder Process Data

Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers

Packaging Specification PK-104092-001-001
Product Specification PS-104091-001-001
Sales Drawing SD-104092-006

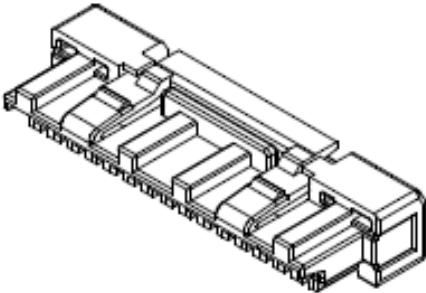

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[104092](#) Series

Mates With

[1040911520](#)

Use With

[1045216001](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION