

Data Sheet | Item Number: 756-3204/190-100

Connecting cable; 19-pole; Length: 10 m



<https://www.wago.com/756-3204/190-100>



Pin 6, 12, 19: 1,00 mm²;
Pin 1 - 5, 7 - 11, 13 - 19: 0,34 mm²

1	violett	11	schwarz
2	rot	12	grün-gelb
3	grau	13	gelb-braun
4	rot-blau	14	braun-grün
5	grün	15	weiß
6	blau	16	gelb
7	grau-rosa	17	rosa
8	weiß-grün	18	grau-braun
9	weiß-gelb	19	braun
10	weiß-grau		

Color: ■ black

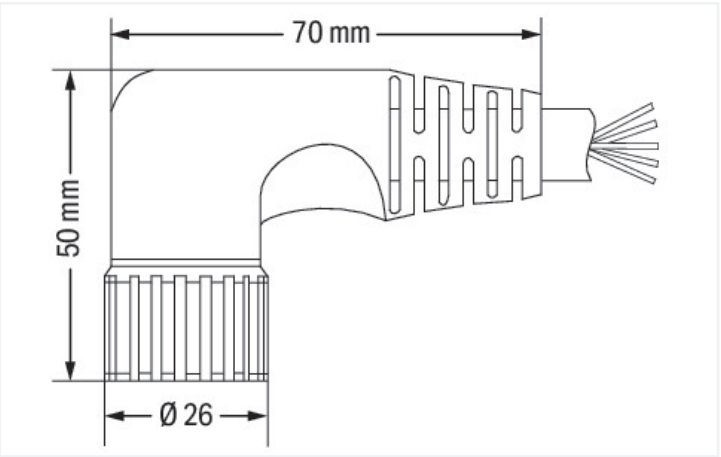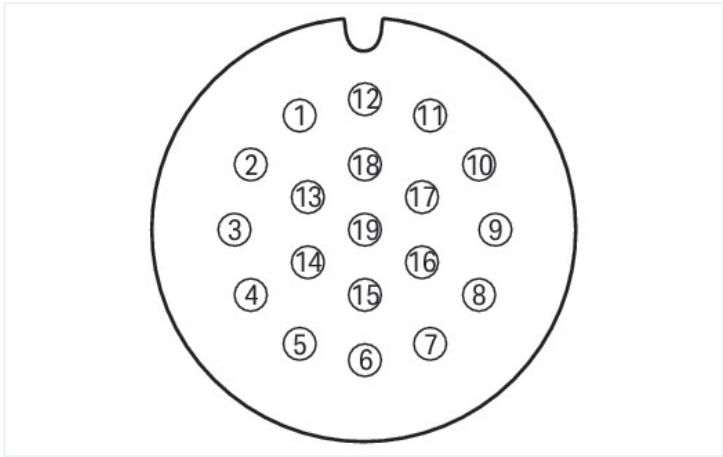

Dimensions in mm

Technical data	
Connection type	M23 socket - free end
Pole number	19
Cable connection direction to mating direction	90 °
Cable length	10 m
Operating voltage	≤ 300 V
Operating current	8 A
Operating current	10 mm ² 1 A
Rated impulse withstand voltage	≥ 2.0 kV rms



Mechanical data	
Bending cycles	2 million
Drag chain capability	Yes
Weight	1438 g
Color	black

Environmental requirements	
Ambient (operating) temperature (dynamic)	-25 ... +80 °C
Ambient (operating) temperature (static)	-40 ... +90 °C
Protection type	IP67
Fire load	0 MJ

Commercial data	
Product Group	23 (I/O passive and accessories)
PU (SPU)	1 pcs
Packaging type	Box
Country of origin	DE
GTIN	4044918569088
Customs tariff number	85444290900

Product Classification	
UNSPSC	26121629
eCl@ss 10.0	27-06-03-11
eCl@ss 9.0	27-06-03-11
ETIM 9.0	EC001855
ETIM 10.0	EC001855
ECCN	NO US CLASSIFICATION

Environmental Product Compliance	
RoHS Compliance Status	Compliant, No Exemption

Downloads

Environmental Product Compliance

Compliance Search

Environmental Product Compliance756-3204/190-100

↓



Documentation

System Description

Sensor/Actuator Boxes – General Product Infor- mation	pdf 428.34 KB	
---	------------------	---

CAD/CAE-Data

CAE data

WSCAD Universe 756-3204/190-100	
------------------------------------	---