


1	2	3	4	5	6	7	8
---	---	---	---	---	---	---	---




7	8
---	---

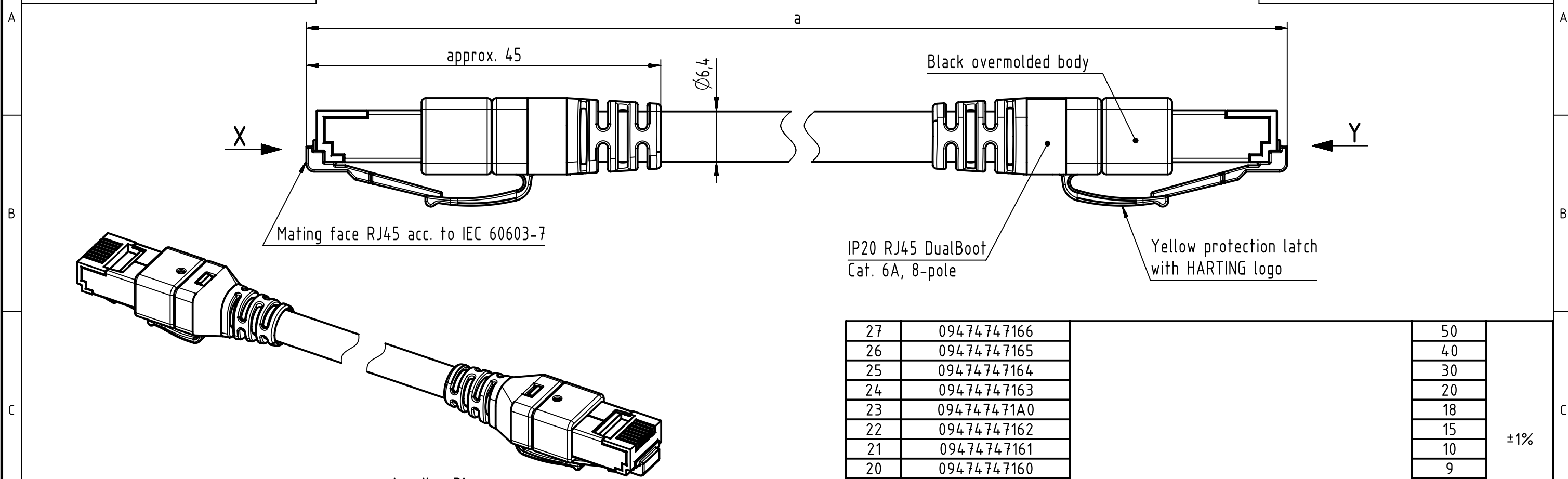

acc. to TIA/EIA 568B

male

male

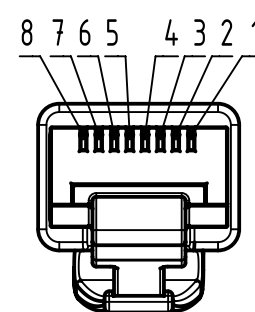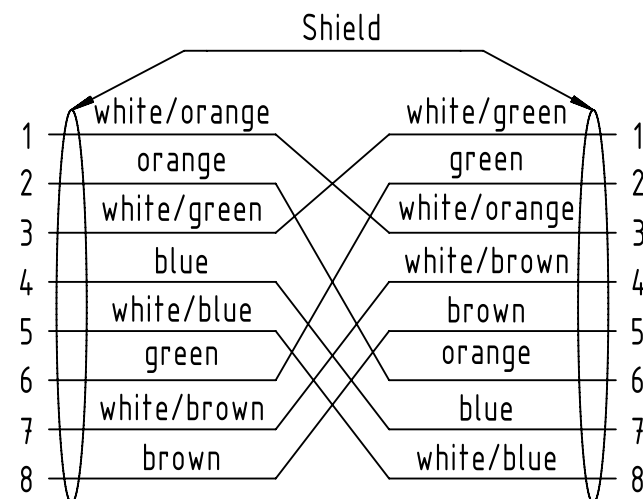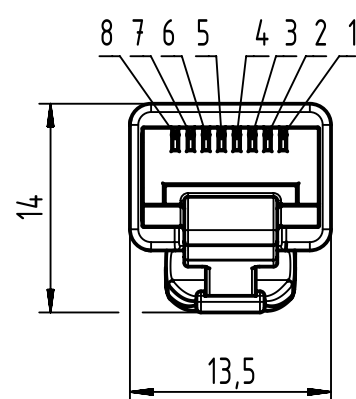

Temperature range:

- Fixed installation: -30°C ...+75°C
- Dynamic installation: -5°C ...+50°C

 
NOTE:

For lengths $< 1.0\text{m}$:

- relative positioning of the connectors to each other will be as presented in the drawing, however with an admissible angular deviation around cable axis of $\pm 30^\circ$

For lengths $\geq 1.0\text{m}$:

- relative positioning of the connectors to each other not obligatory

27	09474747166	4x2xAWG26/7, S/FTP, PUR, Cat.7, yellow	50	±1%		
26	09474747165		40			
25	09474747164		30			
24	09474747163		20			
23	094747471A0		18			
22	09474747162		15			
21	09474747161		10			
20	09474747160		9			
19	09474747159		8			
18	09474747158		7.5	+0.04		
17	09474747157		7			
16	09474747156		6			
15	09474747155		5			
14	09474747154		4			
13	09474747153		3			
12	09474747152		2.5			
11	09474747151		2			
10	09474747150		1.5			
9	09474747149		1			
8	09474747148		0.9	+0.02		
7	09474747147		0.8			
6	09474747146		0.7			
5	09474747145		0.6			
4	09474747144		0.5			
3	09474747143		0.4			
2	09474747142		0.3			
1	09474747141		0.2			
Cont. no.	Part no.	Type of cable	Dim. a[m]			
	All Dimensions in mm	Tech. Character.	Free size tol.	According to production drawing		
	All rights reserved	Created by COSTEA	Inspected by STOCHECIC	Standardisation MUNTEANV	Date 2019-09-05	State Final Release
	Department HCS - RO	Coslea	Stocheci	Muntean		
HARTING Customised Solutions		Title RJ1 x-over 4x2xAWG26/7 CAT6A PUR				Doc-Key / ECM-Nr. 100170398/UGD/022/E 500000157666
D-32339 Espelkamp		Type TB	Number 09474747XXX			Rev. E Page 1/1