




+ CONNECTORS
RF CONNECTORS

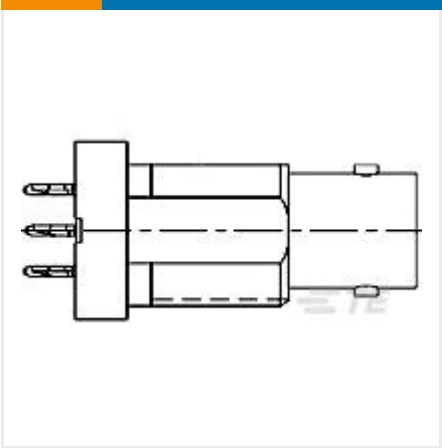

✓ Active

TE CONNECTIVITY (TE)
JACK,PCB,PIN,BNC,75 OHM
Miniature Coax | [OCM](#) , [PCF](#)

5415456-1
TE Internal Number: 5415456-1

[EU RoHS Compliant with Exemptions](#)
[EU ELV Compliant with Exemptions](#)

Connector Interface BNC

Connector Style Jack

Mated Outer Diameter (Approximate) 14.529 mm [.572 in]

Impedance (Ω) 75

Number of Positions 1

↓ **PRODUCT DRAWING**
English

↓ **3D PDF**

DOCUMENTATION

Product Drawings

JACK, PRESS FIT, 75 OHM, PCB, BNC

PDF [\(TIFF AVAILABLE\)](#)

English

CAD Files

3D PDF

PDF

3D

Customer View Model

2D_DXF.ZIP

English

Customer View Model

3D_IGS.ZIP

English

Customer View Model

3D_STP.ZIP

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

- Connector Interface BNC
- Connector Style Jack
- Sealable No
- Connector & Contact Terminates To Printed Circuit Board

Configuration Features

- Number of Positions 1
- PCB Mounting Orientation Vertical

Electrical Characteristics

- Impedance (Ω) 75

Body Features

- Body Material Zinc
- Body Plating Material Nickel
- Body Insulation Without

Contact Features

- Center Contact Plating Material Gold
- Center Contact Material Beryllium Copper
- Center Contact Plating Thickness (μ in) 1651

Termination Features

- Termination Method to PC Board Through Hole - Press-Fit

Mechanical Attachment

- Panel Mount Retention Type Lockwasher and Nut
- Connector Mounting Type Panel
- Panel Attachment Style Rear Mount
- PCB Mount Retention With

Dimensions

Mated Outer Diameter (Approximate) 14.529 mm [.572 in]
Height above PCB 28.77 mm [1.133 in]

Packaging Features

Packaging Method Carton

Other

Dielectric Material PTFE

Additional Features Hardware Included

Comment Screw and Jam Nut Included

Grade Commercial

PRODUCT COMPLIANCE



Statement of Compliance

Statement of Compliance

PDF