

Data Sheet

LL01ED-ACAxL14

CITIZEN
 Micro HumanTech



■ Features & Typical Applications

- High efficiency
- Available with 2 beam angle
- Optimized Uniformity
- Lens without Holder
- Architectural Lighting
- Commercial Lighting

■ Table of Contents


General Information & Product Nomenclature.....	P.2
Optical Specifications	P.3
Mechanical Specifications	P.4
Package Specifications.....	P.5

LL01ED-ACAxxL14

General Information

- Lens Material : PC 1250Y
- Operating Temperature range -40°C~+110°C(upper limit +120°C).
- Storage Temperature range -40°C~+110°C(upper limit +120°C).
 - * Average transmittance in visible spectrum 400nm~700nm>90%.
- Usage and Maintenance:
 1. If necessary, clean lenses with mild soap, water and soft cloth.
 2. Never use any commercial cleaning solvents on lenses, like alcohol.
 3. Please handle or install lenses with wearing gloves, skin oils may damage lens or its optical characteristic.

Product Nomenclature

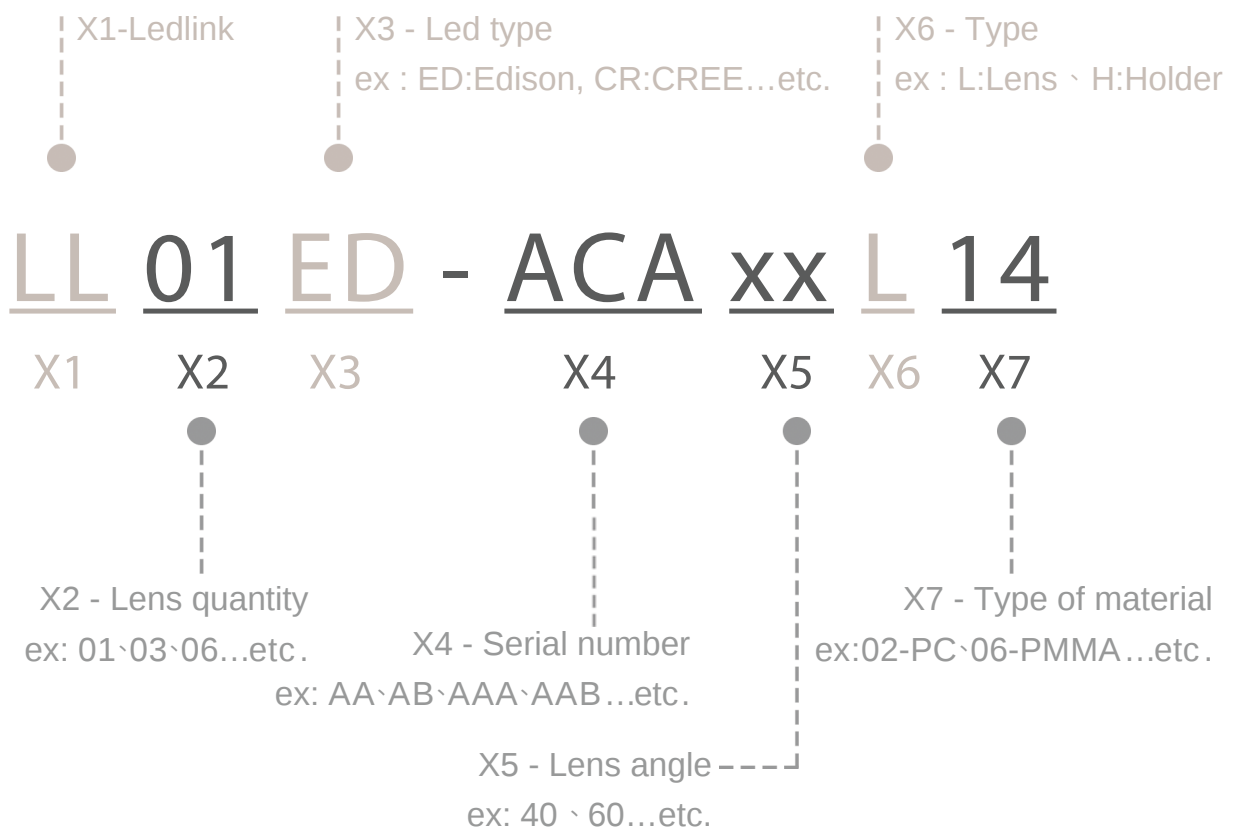



LL01ED-ACAxL14

Optical Specifications

CITIZEN
 Micro HumanTech


CLU 028

Note: (1) All the results of analysis are based on 0 degrees of elevation.
 (2) Tolerance: $\pm 10\%$.
 (3) Led Luminous Flux(lm): 779($\pm 5\%$).

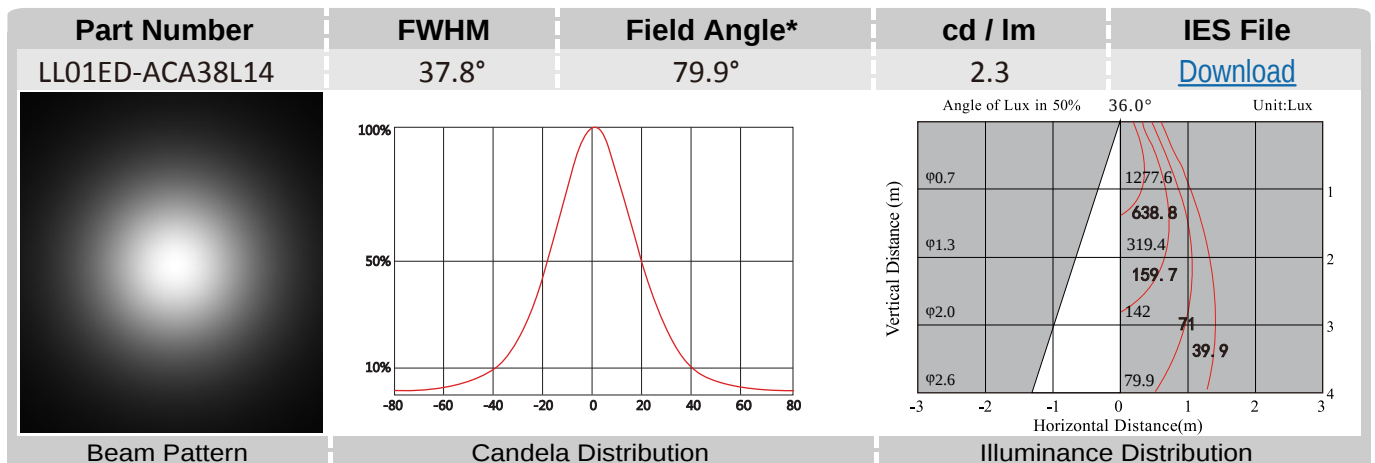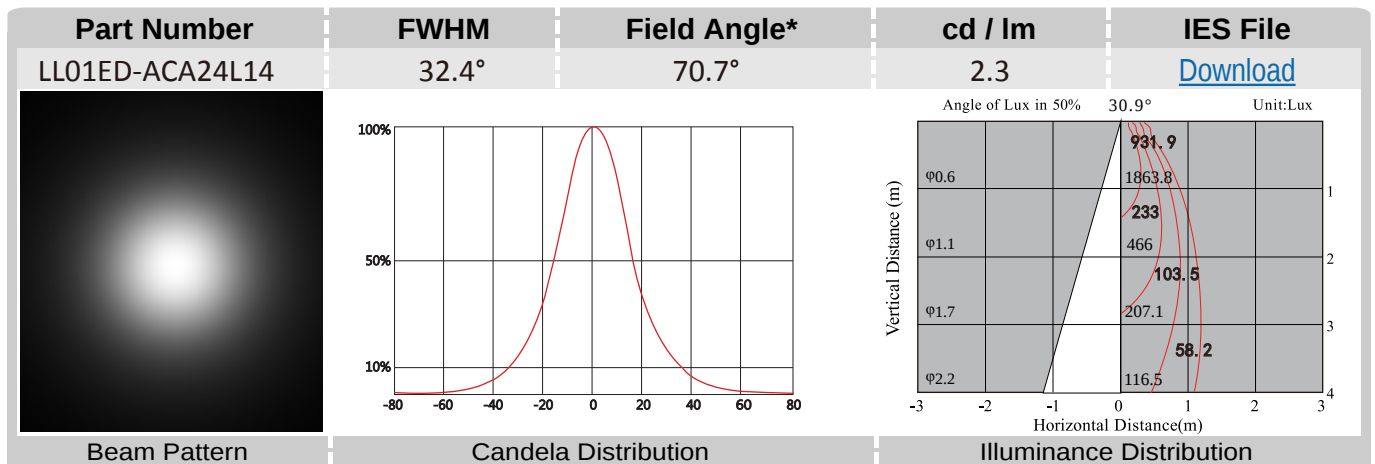

*The Field Angle is the angle between the two directions opposed to each other over the beam axis for which the luminous intensity is 10% that of the maximum luminous intensity.
 *This testing result is obtained through testing the popular rank LED samples which provided by the original manufacturer. Hence, the testing results would be varied as the users choose same LED model but different rank.

LL01ED-ACAxXL14


Mechanical Specification

1. Fixing method


Note: (1) All dimensions are in mm.

☐ Glue
 ☐ Screw
 ☐ Tape
 ☐ Fixing-ring
 ☒ Frame

2. Lens dimension

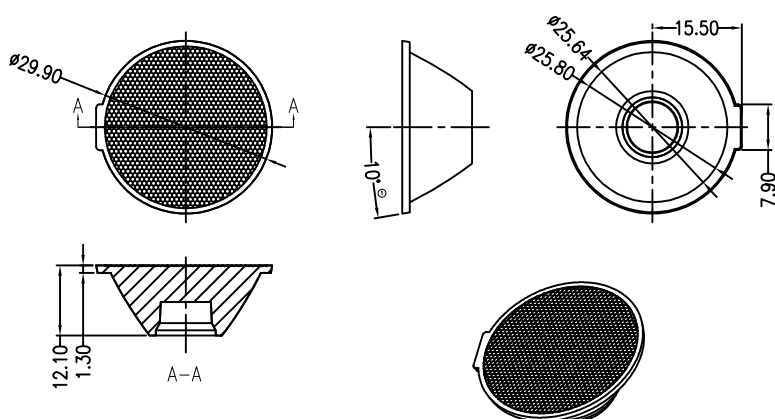


3. Leds assembly instruction

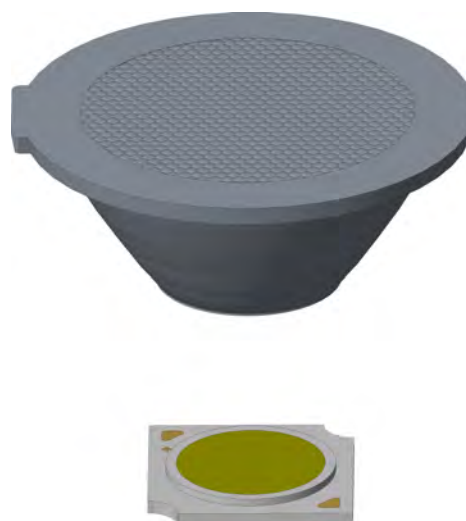

4. Holder dimension


5. View assembly lens with LED:

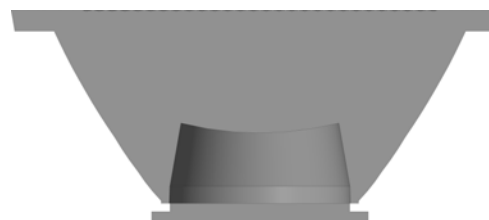



LL01ED-ACAxxL14

Package Specifications

Item	Quantity	Total	Size(L*W*H)	G.W
plastic box	56 pcs/plastic box	56 pcs	33.4*29.4*1.3cm	4.5g
outer box	15 plastic box/outer box	840 pcs	35*31*21cm	

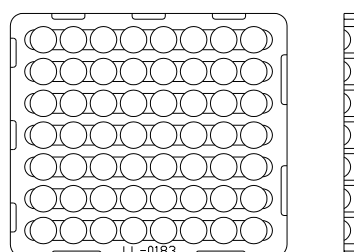

56 pcs/plastic box

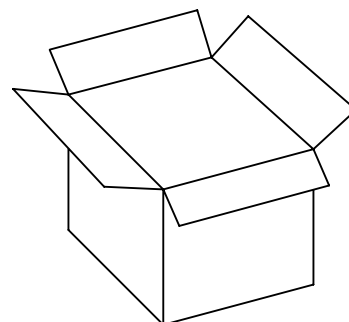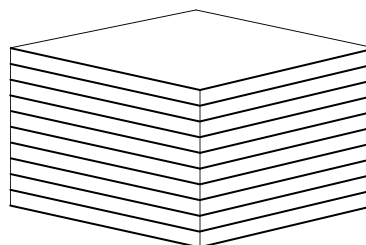

840 pcs/outer box



Note: