

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2042811200

Status:


Active

Overview:

Internet of Things (IoT) Antennas: Wi-Fi, Bluetooth, Zigbee

Description:

Wi-Fi 6E Flex Cabled Side-Fed Balanced Antenna, 200.00mm Cable Length,
Compatible with I-PEX MHF4 Connectors

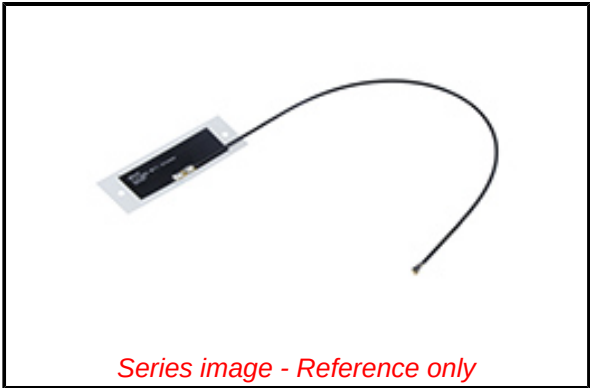

Documents:	
3D Model	Application Specification 2042810100-AS (PDF)
3D Model (PDF)	Packaging Specification 2042810100-PK (PDF)
Drawing (PDF)	Datasheet (PDF)
Product Specification 2042810100-PS (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	Antennas
Series	204281
Component Type	Flexible Antenna with Cable
Function	Signal
Overview	Internet of Things (IoT) Antennas: Wi-Fi, Bluetooth, Zigbee
Product Name	2.4/5GHz Wi-Fi Antenna
Protocol	BLE, BT, Thread, Wi-Fi, Wireless Hart, Zigbee
Taxonomy	Antennas
Type	Internal, Wi-Fi Antenna
UPC	191128462549
Physical	
Cable Length	200.00mm
Length	35.00mm
Mounting Style	Adhesive
Net Weight	0.935/g
Packaging Type	PET Film
Polarization	Linear
Radiation Pattern	Omnidirectional
Thickness	0.10mm
Width	11.00mm
Electrical	
Band#1 F_End (MHz)	2483.5
Band#1 F_Start (MHz)	2400
Band#2 F_End (MHz)	5850
Band#2 F_Start (MHz)	5150
Electrical Connectivity	Cable
Peak Gain (dBi)	1.6 @ 2.4 GHz, 2.8 @ 5 GHz
Return Loss - S11 (dB)	< -10
Total Efficiency	>60% @2.4 GHz, >64% @ 5 GHz
Material Info	
Reference - Drawing Numbers	
Application Specification	2042810100-AS
Packaging Specification	2042810100-PK
Product Specification	2042810100-PS
Sales Drawing	2042811100-000

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Contained per -
D(2022)9120-DC (17
Jan 2023)
2-Methyl-1-(4-
methylthiophenyl)-2-
morpholinoprop

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

204281 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION