




Color: white

Similar to illustration

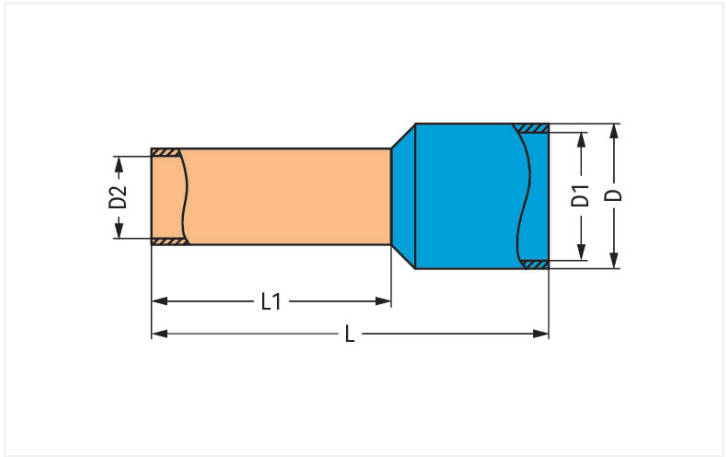

Dimensions in mm

Connection data	
Cross-section metric	0.5 mm²
Strip length	14 ... 15 mm / 0.55 ... 0.59 inches
Cross-section AWG	20 AWG

Physical data	
Total length	18 mm
Wall thickness crimp sleeve	0.15 mm
Wall thickness plastic collar	0.25 mm
Crimp length (length of sleeve)	12 mm
Inner Diameter plastic collar	2.6 mm
Diameter crimp sleeve inside	1 mm

Mechanical data	
Plastic collar	Standard collar

Material data	
Color	white
Fire load	0 MJ
Weight	0.1 g

Commercial data	
PU (SPU)	1000 pcs
Packaging type	Bag
GTIN	4055143570503
Customs tariff number	85369010000



Product classification	
UNSPSC	39121405
ETIM 9.0	EC000005
ETIM 8.0	EC000005
ECCN	NO US CLASSIFICATION

Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Downloads


Environmental Product Compliance

Compliance Search

Environmental Product Compliance 216-1261

↓

Installation Notes

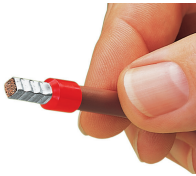

A perfect gas-tight crimp – both electrical-ly and mechanically reliable