
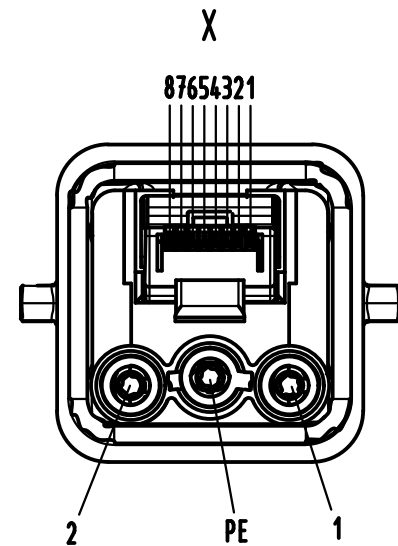


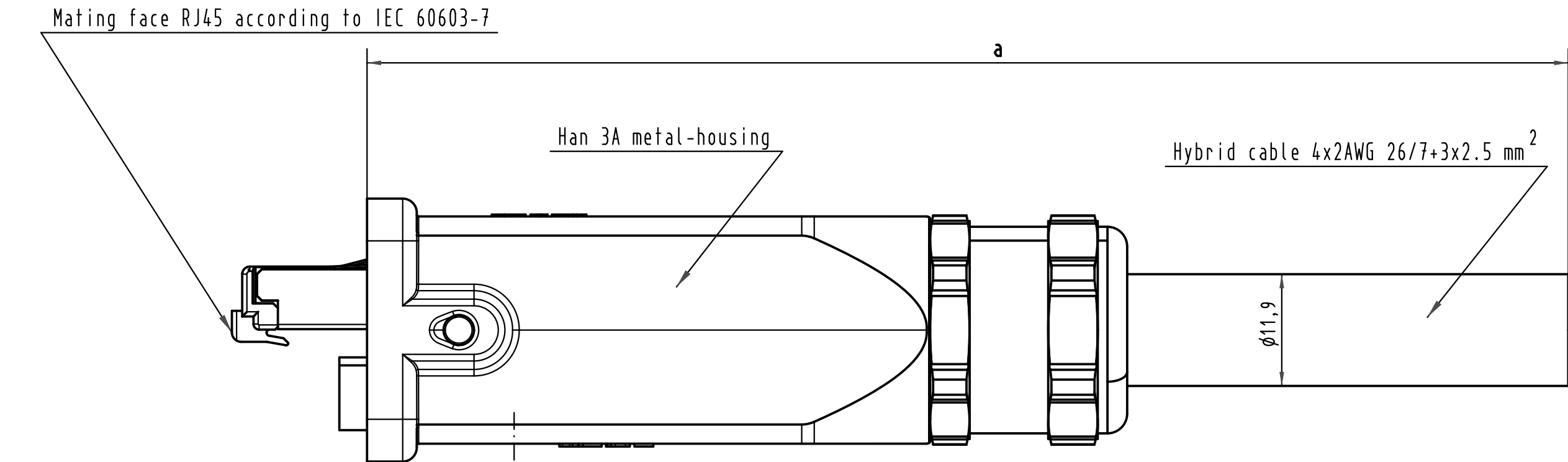

Loading-Plan
(Data)

Shield	
1	White/green
2	Green
3	White/orange
4	Blue
5	White/blue
6	Orange
7	White/brown
8	Brown


Loading-Plan
DC version

1	black	1
2	blue	2
PE	green/yellow	PE

-Protection level: IP67
-Temperature range: -20°C ...+70°C

Data Part
-Transmission properties in accordance
with ISO/IEC 11801:2002: Class D.

???????R??

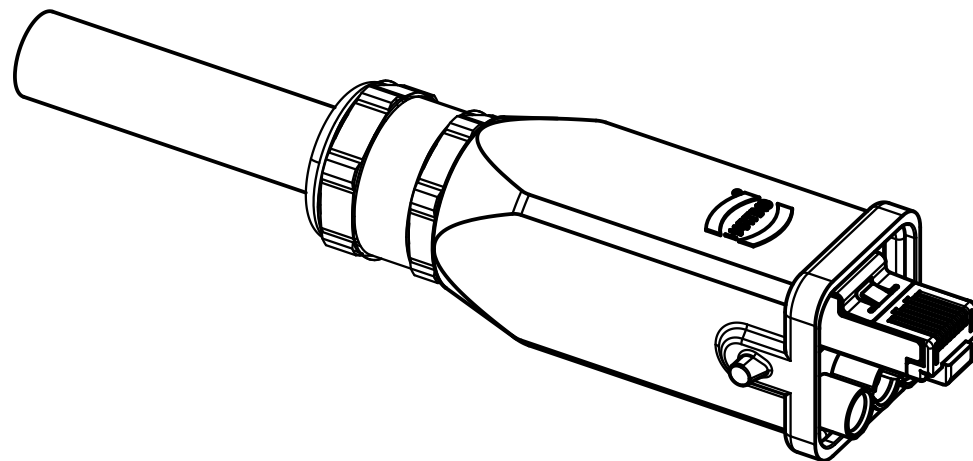

7	Hybrid cable 4x2AWG26/7+3x2,5 mm²	DC	33 57 111 080 0001	80 m
6	Hybrid cable 4x2AWG26/7+3x2,5 mm²	DC	33 57 111 060 0002	60 m
5	Hybrid cable 4x2AWG26/7+3x2,5 mm²	DC	33 57 111 040 0001	40 m
4	Hybrid cable 4x2AWG26/7+3x2,5 mm²	DC	33 57 111 020 0001	20 m
3	Hybrid cable 4x2AWG26/7+3x2,5 mm²	DC	33 57 111 010 0001	10 m
2	Hybrid cable 4x2AWG26/7+3x2,5 mm²	DC	33 57 111 005 0001	5 m
1	Hybrid cable 4x2AWG26/7+3x2,5 mm²	DC	33 57 111 001 0001	1 m

Cont No.	Type of cable	Part-No.	Dim. a
----------	---------------	----------	--------

			All Dimensions in mm Original Size DIN A 3			Nicht tol. Maße/ Free size tol.			Ref. MB		
						Oberflguete/ Surface qual.			Mat.		
						Oberflschutz/ Coating					
						V=					