

Data Sheet | Item Number: 216-288


Ferrule; Sleeve for 6 mm² / AWG 10; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90; yellow

<https://www.wago.com/216-288>



Color: ■ yellow

Similar to illustration

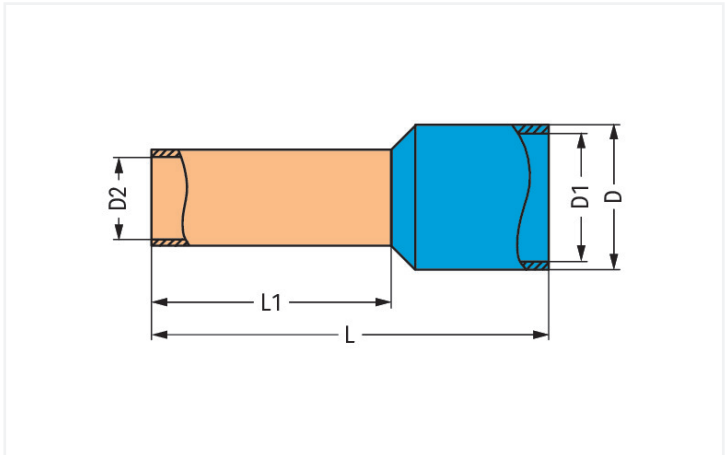

Dimensions in mm

Connection data	
Cross-section metric	6 mm²
Strip length	20 ... 21 mm / 0.79 ... 0.83 inches
Cross-section AWG	10 AWG

Physical data	
Wall thickness crimp sleeve	0.2 mm
Wall thickness plastic collar	0.3 mm
Total length	26 mm
Crimp length (length of sleeve)	18 mm
Inner Diameter plastic collar	6.3 mm
Diameter crimp sleeve inside	3.5 mm

Mechanical data	
Plastic collar	Standard collar
Suitable	2010 to 2016 Series

Material data	
Color	yellow
Fire load	0.016 MJ
Weight	0.5 g

Commercial data	
Product Group	2 (Terminal Block Accessories)
PU (SPU)	100 pcs
Packaging type	Bag
Country of origin	DE
GTIN	4055143654760
Customs tariff number	85369010000



Product classification	
UNSPSC	39121405
eCl@ss 10.0	27-40-02-01
eCl@ss 9.0	27-40-02-01
ETIM 9.0	EC000005
ETIM 8.0	EC000005
ECCN	NO US CLASSIFICATION

Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Downloads

Environmental Product Compliance

Compliance Search

Environmental Product Compliance 216-288

↓

Documentation				
Bid Text				
216-288	11.09.2017	doc	24.50 KB	↓
216-288	19.02.2019	xml	2.80 KB	↓


CAD/CAE-Data

CAD data

2D/3D Models 216-288

↓

Installation Notes

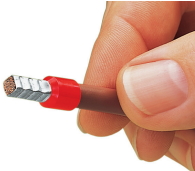

A perfect gas-tight crimp – both electrical-ly and mechanically reliable