


TELLING LIFE'S STORIES FROM MEMORY™

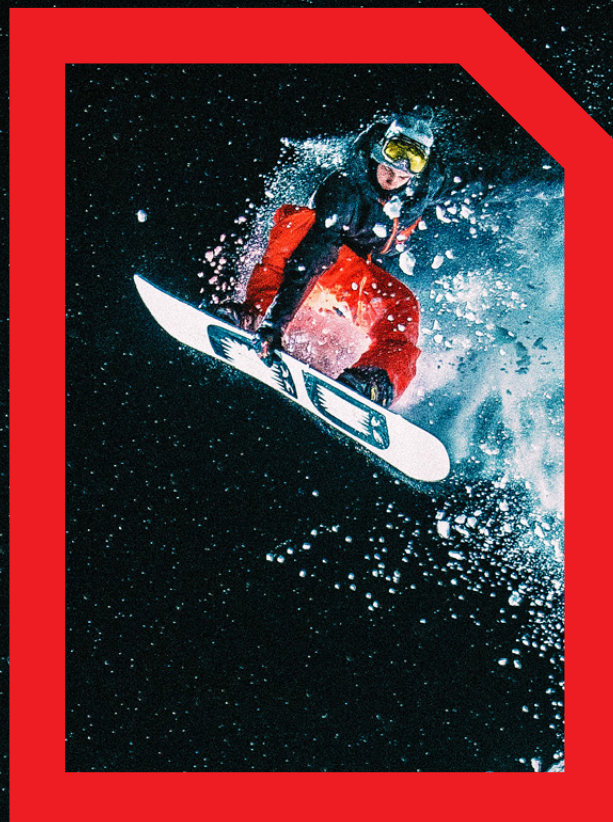

Trusting them to
SanDisk®

© Kirill Umrikhin, SanDisk Extreme™ Team Photographer

CARDS



MOBILE STORAGE SOLUTIONS



SSD



USB



2016 PRODUCT LINE CARD

IMAGING MEMORY CARDS



SanDisk Extreme PRO®, SanDisk Extreme® PLUS
and SanDisk Extreme® Memory Cards

SanDisk Ultra®
Memory Cards

SanDisk®
Memory Cards

PRODUCT NAME / PART #		IDEAL FOR	CAPACITY¹	PERFORMANCE*	VIDEO CAPTURE SPEED	VIDEO PICTURE DEFINITION²	LIMITED WARRANTY³
CFAST™ Memory Cards							
SanDisk Extreme PRO® CFAST™ 2.0 Card							
SDCFSP-064G-G46		Broadcast, cinema and photography professionals	64GB	Up to 515MB/s read, write lower	N/A	4K Ultra HD, Full HD Video	Lifetime
SDCFSP-128G-G46B			128GB				
CompactFlash® Memory Cards							
SanDisk Extreme PRO® CompactFlash® Cards							
SDCFXPS-016G-X46		DSLRs, pro video cameras and HD camcorders	16GB	Up to 160MB/s read, Up to 150MB/s write	VPG-65¹²	4K Ultra HD, Full HD Video	Lifetime
SDCFXPS-032G-X46			32GB				
SDCFXPS-064G-X46			64GB				
SDCFXPS-128G-X46			128GB				
SDCFXPS-256G-X46			256GB				
SanDisk Extreme® CompactFlash® Cards							
SDCFXS-016G-X46		Mid-to-high-end DSLR cameras and HD camcorders	16GB	Up to 120MB/s read, Up to 60MB/s write	VPG-20	Full HD Video	Lifetime
SDCFXS-032G-X46			32GB	Up to 120MB/s read, Up to 85MB/s write			
SDCFXS-064G-X46			64GB				
SDCFXS-128G-X46			128GB				
SanDisk Ultra® CompactFlash® Cards							
SDCFHS-008G-G46		Entry to mid-range DSLRs	8GB	Up to 50MB/s read, write lower	N/A	Full HD Video	10 Years
SDCFHS-016G-G46			16GB				
SDCFHS-032G-G46			32GB				
SD™ Memory Cards							
SanDisk Extreme PRO® SDHC™ and SDXC™ UHS-II Cards							
SDSDXPB-016G-G46		DSLRs, pro video cameras and HD camcorders	16GB	Up to 280MB/s read, Up to 250MB/s write	Class 10, UHS Speed Class 3	4K Ultra HD, Full HD Video	Lifetime
SDSDXPB-032G-G46			32GB				
SDSDXPB-064G-G46			64GB				
SanDisk Extreme PRO® SDHC™ and SDXC™ UHS-I Cards							
SDSDXPA-016G-X46		DSLRs, pro video cameras and HD camcorders	16GB	Up to 95MB/s read, Up to 90MB/s write	Class 10, UHS Speed Class 3	4K Ultra HD, Full HD Video	Lifetime
SDSDXPA-032G-X46			32GB				
SDSDXPA-064G-X46			64GB				
SDSDXPA-128G-G46			128GB				
SDSDXPA-256G-G46			256GB				
SDSDXPA-512G-G46			512GB				
SanDisk Extreme® PLUS SDHC™ and SDXC™ UHS-I Cards							
SDSDXSF-016G-GNCIN		DSLRs, advanced cameras and HD camcorders	16GB	Up to 90MB/s read, Up to 60MB/s write	Class 10, UHS Speed Class 3	4K Ultra HD, Full HD Video	Lifetime
SDSDXSF-032G-GNCIN			32GB				
SDSDXSF-064G-GNCIN			64GB				
SanDisk Extreme® SDHC™ and SDXC™ UHS-I Cards							
SDSDXNE-016G-GNCIN		DSLRs, advanced cameras and HD camcorders	16GB	Up to 90MB/s read, Up to 40MB/s write	Class 10, UHS Speed Class 3	4K Ultra HD, Full HD Video	Lifetime
SDSDXNE-032G-GNCIN			32GB				
SDSDXNE-064G-GNCIN			64GB				
SDSDXNF-128G-GNCIN			128GB				
SDSDXNF-256G-GNCIN			256GB				
SanDisk Ultra® SDHC™ and SDXC™ UHS-I Cards							
SDSDUN-008G-G46		Compact to mid-range point-and-shoot cameras and camcorders	8GB	Up to 40MB/s read, write lower	Class 10	Full HD Video	10 Years
SDSDUNC-016G-GN6IN			16GB	Up to 80MB/s read, write lower			
SDSDUNC-032G-GN6IN			32GB				
SDSDUNC-064G-GN6IN			64GB				
SDSDUNC-128G-GN6IN			128GB				
SanDisk Ultra® SDHC™ and SDXC™ UHS-I Cards (48MB/s)							
SDSDUNB-016G-GN3IN		Compact to mid-range point-and-shoot cameras and camcorders	16GB	Up to 48MB/s read	Class 10	Full HD Video	7 Years
SDSDUNB-032G-GN3IN			32GB				
SDSDUNB-064G-GN3IN			64GB				
SanDisk SDHC™ and SDXC™ Cards							
SDSDB-008G-B35		Standard point-and-shoot cameras	8GB	N/A	Class 4	HD Video	5 Years
SDSDB-016G-B35			16GB				
SDSDB-032G-B35			32GB				
SDSDB-064G-B35			64GB				
microSD™ Memory Cards							
SanDisk Extreme® microSDHC™ and microSDXC™ Action Cam Card							
SDSQXNE-032G-GN6AA		Action cameras and smartphones and tablets,	32GB	Up to 90MB/s read, Up to 40MB/s write	Class 10, UHS Speed Class 3	4K Ultra HD, Full HD Video	Lifetime
SDSQXNE-064G-GN6AA			64GB				
SanDisk Ultra® microSDHC™ and microSDXC™ Cards with Adapter							
SDSDQUIN-008G-G4		Compact to mid-range point-and-shoot cameras and camcorders	8GB	Up to 48MB/s read, write lower	Class 10	Full HD Video	10 Years
SDSQUNC-016G-GN6IA			16GB	Up to 80MB/s read, write lower			
SDSQUNC-032G-GN6IA			32GB				
SDSQUNC-064G-GN6IA			64GB				
SDSQUNC-128G-GN6IA			128GB				
SanDisk microSDHC™ Cards with Adapter							
SDSDQB-008G-B35		Cameras and phones	8GB	N/A	Class 4	HD Video	5 Years
SDSDQB-016G-B35			16GB				
SDSDQB-032G-B35			32GB				

To learn more about SanDisk products and promotions visit www.sandisk.com

USB FLASH DRIVES



SanDisk® USB Flash Drives



NEW Products

USB FLASH DRIVES

PRODUCT NAME / PART #		IDEAL FOR		CAPACITY¹	TRANSFER SPEED	INTERFACE	LIMITED WARRANTY³
SanDisk Extreme PRO®							
SanDisk Extreme PRO® USB 3.0 Flash Drive							
SDCZ88-128G-G46		Data, Music, Photos, Video	128GB	Up to 260MB/s read ^{8**} 60X faster ¹⁴ than standard USB 2.0 drives	USB 3.0 (Up to 260MB/s read ⁹)	Lifetime	
SanDisk Extreme®							
SanDisk Extreme® USB 3.0 Flash Drive							
SDCZ80-016G-G46		Data, Music, Photos, Video	16GB	Up to 245MB/s read ^{8**} Up to 45X faster ¹⁵ than standard USB 2.0 drives (64GB only)	USB 3.0 (Up to 245MB/s read ⁹)	Lifetime	
SDCZ80-032G-G46			32GB				
SDCZ80-064G-G46			64GB				
SanDisk Ultra®							
SanDisk Ultra® USB 3.0 Flash Drive							
SDCZ48-016G-U46		Data, Music, Photos, Video	16GB	Up to 100MB/s read ^{8**} Up to 10X faster ¹⁶ than standard USB 2.0 drives	USB 3.0 (Up to 100MB/s read ⁹)	5 Years	
SDCZ48-032G-U46			32GB				
SDCZ48-064G-U46			64GB				
SDCZ48-128G-U46			128GB				
SDCZ48-256G-G46			256GB				
SanDisk Ultra Fit™ USB 3.0 Flash Drive							
SDCZ43-016G-G46		Data, Music, Photos, Video	16GB	Up to 130MB/s read ^{8**} Up to 10X faster ¹⁷ than standard USB 2.0 drives	USB 3.0 (Up to 130MB/s read ⁹)	5 Years	
SDCZ43-032G-G46			32GB				
SDCZ43-064G-G46			64GB				
SDCZ43-128G-G46			128GB				
SanDisk Ultra Flair™ USB 3.0 Flash Drive							
SDCZ73-016G-G46		Data, Music, Photos, Video	16GB	Up to 150MB/s read ^{8***} Up to 15X faster ¹⁸ than standard USB 2.0 drives	USB 3.0 (Up to 150MB/s read ⁹)	5 Years	
SDCZ73-032G-G46			32GB				
SDCZ73-064G-G46			64GB				
SDCZ73-128G-G46			128GB				
SanDisk USB Flash Drives							
SanDisk Cruzer Force™ USB Flash Drive							
SDCZ71-008G-B35		Data, Music, Photos, Video	8GB	N/A	USB 2.0	5 Years	
SDCZ71-016G-B35			16GB				
SDCZ71-032G-B35			32GB				
SDCZ71-064G-B35			64GB				
SanDisk Cruzer Glide™ USB Flash Drive							
SDCZ60-008G-B35		Data, Music, Photos, Video	8GB	N/A	USB 2.0	5 Years	
SDCZ60-016G-B35			16GB				
SDCZ60-032G-B35			32GB				
SDCZ60-064G-B35			64GB				
SDCZ60-128G-B35			128GB				
SDCZ60-256G-B35			256GB				
SanDisk Cruzer Facet™ USB Flash Drive (Red/Black)							
SDCZ55-008G-B35R. Red		Data, Music, Photos, Video	8GB	N/A	USB 2.0	5 Years	
SDCZ55-016G-B35R. Red			16GB				
SDCZ55-008G-B35Z. Black			8GB				
SDCZ55-016G-B35Z. Black			16GB				
SDCZ55-032G-B35Z. Black			32GB				
SanDisk Cruzer Switch™ USB Flash Drive							
SDCZ52-008G-B35		Data, Music, Photos, Video	8GB	N/A	USB 2.0	5 Years	
SDCZ52-016G-B35			16GB				
SDCZ52-032G-B35			32GB				
SDCZ52-064G-B35			64GB				
SanDisk Cruzer Edge™ USB Flash Drive							
SDCZ51-008G-B35		Data, Music, Photos, Video	8GB	N/A	USB 2.0	5 Years	
SDCZ51-016G-B35			16GB				
SDCZ51-032G-B35			32GB				
SDCZ51-064G-B35			64GB				
SanDisk Cruzer Blade™ USB Flash Drive							
SDCZ50C-008G-B35W. White		Data, Music, Photos, Video	8GB	N/A	USB 2.0	5 Years	
SDCZ50C-016G-B35W. White			16GB				
SDCZ50C-008G-B35BE. Electric Blue			8GB				
SDCZ50C-008G-B35GE. Electric Green			8GB				
SDCZ50C-008G-B35PE. Electric Pink			8GB				
SDCZ50C-016G-B35BE. Electric Blue			16GB				
SDCZ50C-016G-B35GE. Electric Green			16GB				
SDCZ50C-016G-B35PE. Electric Pink			16GB				
SDCZ50-008G-B35. Black			8GB				
SDCZ50-016G-B35. Black			16GB				
SDCZ50-032G-B35. Black			32GB				
SDCZ50-064G-B35. Black			64GB				
SDCZ50-128G-B35. Black			128GB				
SanDisk Cruzer Blade™ USB Flash Drive - 3-Pack Colours							
SDCZ50C-008G-B46T. Green, Blue, Pink		Data, Music, Photos, Video	8GB	N/A	USB 2.0	5 Years	
SDCZ50-008G-B46T. Black, Blue & White			8GB				
SanDisk Cruzer Fit™ USB Flash Drive							
SDCZ33-008G-B35		Data, Music, Photos, Video	8GB	N/A	USB 2.0	5 Years	
SDCZ33-016G-B35			16GB				
SDCZ33-032G-B35			32GB				
SDCZ33-064G-B35			64GB				
SanDisk Cruzer U™ USB Flash Drive							
SDCZ59-016G-B35BT. Blue Triangles		Data, Music, Photos, Video	16GB	N/A	USB 2.0	5 Years	
SDCZ59-016G-B35BZ. Blue			16GB				
SDCZ59-016G-B35PD. Polka Dots			16GB				
SDCZ59-016G-B35PZ. Pink			16GB				
SDCZ59-032G-B35BZ. Blue			32GB				
SDCZ59-032G-B35PZ. Pink			32GB				
SanDisk Cruzer Pop™ USB Flash Drive ROMERO BRITTO™ “A New Day” Special Edition							
SDCZ53-016G-B35		Data, Music, Photos, Video	16GB	N/A	USB 2.0	5 Years	

To learn more about SanDisk products and promotions visit www.sandisk.com

SPECIAL FOOTBALL PROMOTION USB FLASH DRIVES



NEW Products : 13 Cruzer Edge™ USB Flash Drive Football Promotion SKUs

PRODUCT NAME / PART #		IDEAL FOR	CAPACITY¹	TRANSFER SPEED	INTERFACE	LIMITED WARRANTY²
USB FLASH DRIVES	Football Promotion SKU USB Flash Drives					
	SDCZ51-008G-E35BG Cruzer Edge™. Blue		8GB	N/A	USB 2.0	5 Years
	SDCZ51-016G-E35BG Cruzer Edge™. Blue		16GB			
	SDCZ51-032G-E35BG Cruzer Edge™. Blue		32GB			
	SDCZ51-064G-E35BG Cruzer Edge™. Blue		64GB			
	SDCZ51-008G-E35WG Cruzer Edge™. White		8GB	N/A	USB 2.0	5 Years
	SDCZ51-016G-E35WG Cruzer Edge™. White		16GB			
	SDCZ51-032G-E35WG Cruzer Edge™. White		32GB			
	SDCZ51-064G-E35WG Cruzer Edge™. White		64GB			
	SDCZ51-008G-E35RG Cruzer Edge™. Red		8GB	N/A	USB 2.0	5 Years
	SDCZ51-016G-E35RG Cruzer Edge™. Red		16GB			
	SDCZ51-032G-E35RG Cruzer Edge™. Red		32GB			
	SDCZ51-064G-E35RG Cruzer Edge™. Red		64GB			
	SDCZ51-016G-E46T Cruzer Edge™. 3-pack		16GB	N/A	USB 2.0	5 Years

TELLING LIFE'S STORIES FROM MEMORY
Trusting them to SanDisk™

SanDisk™

Photo © Lars Schwallenhus

MOBILE STORAGE SOLUTIONS

Up to 200GB  Enhanced Speed  Advanced Speed  Super-fast Speed Increase your Android smartphone or tablet memory		 A USB for your Android smartphone or tablet	For Apple Made for iPhone iPad  A USB for your iPad or iPhone	For Android and Apple  Wireless USB for your smartphone, tablet, PC and Mac computer  Wireless memory - wirelessly share your content and stream media on the go			
PRODUCT NAME / PART #		IDEAL FOR	CAPACITY¹	PERFORMANCE*	VIDEO CAPTURE SPEED	VIDEO PICTURE DEFINITION²	LIMITED WARRANTY³
SanDisk Extreme PRO® microSDHC™ and microSDXC™ UHS-I Cards							
SDSDQXP-016G-X46			16 GB	Up to 95MB/s read, Up to 90MB/s write	Class 10, UHS Speed Class 3	4K Ultra HD, Full HD Video	Lifetime
SDSDQXP-032G-G46A			32 GB				
SDSDQXP-064G-G46A			64 GB				
SanDisk Extreme® PLUS microSDHC™ and microSDXC™ UHS-I Cards with Adapter							
SDSQXSG-016G-GN6MA			16 GB	Up to 95MB/s read, Up to 90MB/s write	Class 10, UHS Speed Class 3	4K Ultra HD, Full HD Video	Lifetime
SDSQXSG-032G-GN6MA			32 GB				
SDSQXSG-064G-GN6MA			64 GB				
SanDisk Extreme® microSDHC™ and microSDXC™ UHS-I Cards with Adapter							
SDSQXNE-016G-GN6MA			16 GB	Up to 90MB/s read, Up to 40MB/s write	Class 10, UHS Speed Class 3	4K Ultra HD, Full HD Video	Lifetime
SDSQXNE-032G-GN6MA			32 GB				
SDSQXNE-064G-GN6MA			64 GB				
SanDisk Ultra® microSDHC™ and microSDXC™ UHS-I Cards with Adapter							
SDSDQUAN-008G-G4A			8 GB	Up to 48MB/s read, write lower	Class 10	Full HD Video	10 Years
SDSQUNC-016G-GN6MA			16 GB				
SDSQUNC-032G-GN6MA			32 GB	Up to 80MB/s read			
SDSQUNC-064G-GN6MA			64 GB				
SDSQUNC-128G-GN6MA			128 GB				
SDSDQUAN-200G-G4A			200GB				
SanDisk Ultra® microSDHC™ and microSDXC™ UHS-I Cards							
SDSQUNB-016G-GN3MN			16 GB	Up to 48MB/s read	Class 10	Full HD Video	10 Years
SDSQUNB-032G-GN3MN			32 GB				
SDSQUNB-064G-GN3MN			64 GB				
SanDisk microSDHC™ Cards							
SDSDQM-008G-B35			8 GB	N/A	Class 4	HD Video	5 Years
SDSDQM-016G-B35			16 GB				
SDSDQM-032G-B35			32 GB				
SanDisk microSDHC™ Cards with Adapter							
SDSDQM-008G-B35A			8 GB	N/A	Class 4	HD Video	5 Years
SDSDQM-016G-B35A			16 GB				
SDSDQM-032G-B35A			32 GB				
SanDisk® High Endurance Video Monitoring Card with Adapter							
SDSDQQ-032G-G46A			32 GB	Up to 20MB/s read and write	Class 10	Full HD Video	2 Years
SDSDQQ-064G-G46A			64 GB				
SanDisk Ultra® Mobile Storage Pack (SanDisk Ultra® Dual USB Drive 3.0 32GB and SanDisk Ultra® microSDHC™ UHS-I card 32GB)							
SDDD2-032G-G46USD			32 GB	Up to 80MB/s read, write lower (card); micro-USB and USB 3.0 up to 130MB/s (Dual USB Drive)	Class 10	Full HD Video	5 years (card) / 2 years (Dual USB Drive)
PRODUCT NAME / PART #		IDEAL FOR	CAPACITY¹	INTERFACE	VIDEO CAPTURE SPEED	VIDEO PICTURE DEFINITION²	LIMITED WARRANTY³
SanDisk Ultra® Dual USB Drive 3.0							
SDDD2-016G-G46			16 GB	micro-USB and USB 3.0 up to 130MB/s	N/A	N/A	2 Years
SDDD2-032G-G46			32 GB				
SDDD2-064G-G46			64 GB				
SDDD2-128G-G46			128 GB				
SDDD2-032G-G46W. White			32 GB				
SanDisk iXpand™ Flash Drive							
SDIX-016G-G57			16 GB	Lightning and USB 3.0	N/A	N/A	2 Years
SDIX-032G-G57			32 GB				
SDIX-064G-G57			64 GB				
SDIX-128G-G57			128 GB				
SanDisk Dual USB Drive Type-C							
SDDDC-032G-G46			32 GB	micro-USB and USB 3.0	N/A	N/A	2 Years
PRODUCT NAME / PART #		IDEAL FOR	CAPACITY¹	INTERFACE	VIDEO CAPTURE SPEED	VIDEO PICTURE DEFINITION²	LIMITED WARRANTY³
SanDisk Connect™ Wireless Stick							
SDWS4-016G-G46			16 GB	USB 2.0 or higher	N/A	N/A	2 Years
SDWS4-032G-G46			32 GB				
SDWS4-064G-G46			64 GB				
SDWS4-128G-G46			128GB				
SDWS4-200G-G46. White			200GB				
SanDisk Connect™ Wireless Media Drive							
SDWS1-032G-E57			32 GB	USB 2.0 or higher	N/A	N/A	2 Years
SDWS1-064G-E57			64 GB				

SOLID STATE DRIVES			MP3 PLAYERS			READER			
									
SanDisk® Solid State Drives (SSD)			SanDisk® Clip Sport MP3 Players			SanDisk Clip Jam MP3 Players			
ImageMate® Reader									
PRODUCT NAME / PART #			IDEAL FOR	CAPACITY¹	PERFORMANCE* / VIDEO CAPTURE SPEED	INTERFACE	LIMITED WARRANTY³		
SOLID STATE DRIVES	SanDisk Extreme PRO® Solid State Drive								
	SDSSDXPS-480G-G25		Power gamers, game developers, media professional	480GB	Up to 550MB/s read, write lower	SATA 6GB/s	10 Years		
	SDSSDXPS-960G-G25			960GB					
	SanDisk Ultra® II Solid State Drive								
	SDSSDHII-240G-G25		Up to 28x better performance than HDD¹³	240GB	Up to 550MB/s read, write lower	SATA 6GB/s	3 Years		
	SDSSDHII-480G-G25			480GB					
	SDSSDHII-960G-G25			960GB					
	SanDisk® SSD PLUS Solid State Drive								
	SDSSDA-120G-G25		To speed up your notebook or desktop	120GB	Up to 520MB/s read, write lower	SATA 6GB/s	3 Years		
	SDSSDA-240G-G25			240GB					
SDSSDA-480G-G25	480GB			Up to 480MB/s read, Up to 400MB/s write					
SanDisk® Solid State Drive (SSD) Conversion Kit									
SDSSDCK-AAA-G27		Hassle-free installation kit	N/A	N/A	N/A	3 Years			
PRODUCT NAME / PART #			IDEAL FOR	CAPACITY¹	PERFORMANCE* / VIDEO CAPTURE SPEED	INTERFACE	LIMITED WARRANTY³		
PORTABLE SSDs	SanDisk Extreme® 500 Portable SSD								
	SDSSDEXT-120G-G25		High-speed Storage for High-res Photos and Videos On-The-Go	120GB	Up to 415MB/s read, Up to 340MB/s write	USB 3.0	3 Years		
	SDSSDEXT-240G-G25			240GB					
	SDSSDEXT-480G-G25			480GB					
	SanDisk Extreme® 510 Portable SSD								
	SDSSDEXTW-480G-G25		All-terrain, high-speed, water-resistant portable SSD	480GB	Up to 430MB/s read, Up to 400MB/s write	USB 3.0	2 Years		
	SanDisk Extreme® 900 Portable SSD								
	SDSSDEX2-480G-G25		Serious Storage Speeds for High-res Photos and Videos	480GB	Up to 850MB/s read, Up to 850MB/s write	USB 3.1 Gen 2	3 Years		
	SDSSDEX2-960G-G25			960GB					
	SDSSDEX2-1T92-G25			1.92TB					
PRODUCT NAME / PART #			IDEAL FOR	CAPACITY¹	MEMORY CARD SLOT	BATTERY	OTHER FEATURES	LIMITED WARRANTY³	
MP3 PLAYERS	SanDisk Clip Jam™								
	SDMX26-008G-G46B, Bright Blue		Personal music player	8GB	microSDHC™ (card sold separately)	Up to 18 hours battery life¹⁰	FM tuner Lightweight Tangle-free earbuds in matching colors	2 Years	
	SDMX26-008G-G46G, Bright Green			8GB					
	SDMX26-008G-G46K, Black			8GB					
	SDMX26-008G-G46O, Bright Orange			8GB					
	SDMX26-008G-G46P, Bright Pink			8GB					
	SanDisk® Clip Sport MP3 Players								
	SDMX24-004G-G46K, Black		Personal music player	4GB	microSDHC™ (card sold separately)	Up to 25 hours battery life¹⁰	FM tuner Lightweight, clips on 1.44" TFT-LCD Tangle-free earbuds in matching colors	1 Year	
	SDMX24-004G-G46R, Red			4GB					
	SDMX24-004G-G46Y, Yellow			4GB					
	SDMX24-008G-G46K, Black			8GB					
	SDMX24-008G-G46Y, Yellow			8GB					
	SDMX24-008G-G46B, Blue			8GB					
	SDMX24-008G-G46P, Pink			8GB					
	SDMX24-008G-G46L, Lime			8GB					
PRODUCT NAME / PART #			IDEAL FOR	CAPACITY¹	PERFORMANCE*	LIMITED WARRANTY³			
READERS	SanDisk Extreme PRO® CFast™ 2.0 Reader/Writer								
	SDDR-299-G46		Fast transfer of video and photos	N/A	USB 3.0 interface transfer speed up to 500MB/s	2 Years			
	SanDisk Extreme PRO® UHS-II SD™ Reader/Write								
	SDDR-329-G46		Fast transfers for your UHS-II SD card	N/A	USB 3.0 interface transfer speed up to 500MB/s	2 Years			
	ImageMate® All-in-one USB 3.0 Reader/Writer								
SDDR-289-X20		Transfer files to your computer	N/A	Up to 500MB/s interface transfer speed	2 Years				
MobileMate® Duo (SD™ Adapter + USB Reader)									
SDDRK-121-B35		Transfer files between your computer, mobile phone & camera	N/A	N/A	2 Years				

To learn more about SanDisk products and promotions visit www.sandisk.com

IMAGING MEMORY CARDS

SanDisk Extreme PRO®, SanDisk Extreme® PLUS and SanDisk Extreme® Memory Cards



Engineered with blazing read/write speeds and professional-grade responsiveness, the **SanDisk Extreme PRO®**, **SanDisk Extreme® PLUS** and **SanDisk Extreme®** line of memory cards delivers reliability, durability and our best in speed for advanced cameras and DSLRs.

- Up to 160MB/s* read speed (SanDisk Extreme PRO CompactFlash®) and up to 280MB/s* read speed (SanDisk Extreme PRO SDHC™/SDXC™ UHS-II)
- World's highest capacity SDXC card at 512GB¹
- Ideal for continuous burst shooting
- Perfect for Full HD and 4K Ultra HD video²
- Lifetime limited warranty⁵

SanDisk Ultra® Memory Cards



Step up to faster transfer performance with **SanDisk Ultra® CompactFlash®** and **SanDisk Ultra® SDHC™/SDXC™ UHS-I** memory cards.

- Up to 50MB/s* read (SanDisk Ultra CompactFlash) and up to 80MB/s* read (SanDisk Ultra SDHC/SDXC UHS-I)
- Ideal for capturing Full HD and 3D video²
- Great for entry to mid-range DSLRs

SanDisk® Memory Cards



Capture life's everyday memories on **SanDisk SDHC™/SDXC™** and **SanDisk microSDHC™/microSDXC™** memory cards, perfect for standard point-and-shoot cameras.

- Writable label for easy identification and organization
- Dependability and solid performance
- 5-year limited warranty

MOBILE STORAGE SOLUTIONS

SanDisk Extreme PRO® UHS-I Memory Cards



SanDisk Extreme PRO® microSDHC™/microSDXC™ UHS-I memory cards on the market now come with up to 64GB¹ of storage for uncompromising smartphone, tablet and camera performance. Enjoy transfer speeds of up to 95MB/s* so you can shoot like a pro and still experience world-class responsiveness from your phone.

- Pro Video Performance with both Class 10 and UHS Speed Class 3 (U3)⁴ ratings for capturing 4K Ultra HD and Full HD video²
- SanDisk Memory Zone App with the new OptiMem™ feature makes it easy to manage your smartphone memory and your media files⁵

SanDisk Extreme® PLUS and SanDisk Extreme® UHS-I Memory Cards



Capture more fast action and record more 4K Ultra HD and Full HD video² with your Android™-based smartphone or action camera. **SanDisk Extreme® PLUS** and **SanDisk Extreme® microSDHC™/microSDXC™ UHS-I** cards come with fast write speeds to reduce the time you're on hold while moving content to your card.

- Delivers 4K Ultra HD and Full HD video recording and playback
- Built for extreme conditions: temperature proof, water proof, shock proof, and x-ray proof⁶

SanDisk Ultra® UHS-I Memory Cards



Shoot and save more high-quality photos and Full HD video² on your Android-based smartphone or tablet with **SanDisk Ultra® microSDHC™/microSDXC™ UHS-I** cards. With storage capacities up to 200GB¹ you can take more photos and videos without worrying about running out of space.

- Class 10 to capture Full HD video
- Transfer faster with speeds up to 90MB/s* (200GB capacity; 16-128GB capacities 80MB/s*)

SanDisk® Memory Cards



Capture more photos, record more HD videos² and play more music on your mobile phone or tablet with reliable **SanDisk® microSDHC™ UHS-I** cards. Do more with SanDisk mobile memory cards.

- Adds storage up to 32GB¹
- Supports microSDHC compatible host devices

Mobile Flash Drives



SanDisk Ultra® Dual USB Drive 3.0 makes it easy to transfer or share files from your OTG-enabled Android smartphone or tablet onto your PC or Mac computer. Sleek, retractable design offers both USB 3.0 and micro-USB connectors.

SanDisk iXpand™ Flash Drive makes it easy to transfer photos and videos between your iPhone, iPad, PCs and Mac computers. Quickly frees up memory on your iPhone and iPad, and plays all popular video formats⁹ directly from the drive.

WIRELESS DRIVES

SanDisk Connect™ Wireless Stick



The **SanDisk Connect™ Wireless Stick** features an intuitive App that makes it easy to free up memory, back up your photos and stream content to your smartphones and tablets¹.

- Instantly adds up to 200GB¹ of storage for your mobile devices
- Connects wirelessly to multiple devices – no Internet required

SanDisk Connect™ Wireless Media Drive



The **SanDisk Connect™ Wireless Media Drive** is the perfect pocket-sized entertainment device that streams high-definition movies, photos, and music on tablets, smartphones, and computers.

- Up to 8 hours of wireless streaming per charge
- Includes SDHC™/SDXC™ memory card slot for storage expansion

To learn more about SanDisk products and promotions visit www.sandisk.com

SOLID STATE DRIVES

SanDisk® Solid State Drives (SSD)



Experience faster boot up times, gaming, photo and video editing, and improved overall computing performance, while extending the life of your existing computers. SanDisk Extreme PRO® SSD, SanDisk Ultra® II SSD, and SanDisk® SSD Plus are the smart affordable choices for your next laptop and desktop upgrades.

- **Faster system boot up and shutdown**—faster boot and application load times
- **Speedy read and write performance**—launch applications faster
- **Designed for high durability**—engineered to withstand shocks and vibration
- **Lower power consumption**—as compared to a standard 7200 RPM Hard Disk Drive
- **Noise reduction**—provides quiet drive operation

SANDISK® PORTABLE SSDS

SanDisk® Solid State Drives (SSD)



Designed for high durability when you're out on location, SanDisk portable SSDs fit neatly into your pocket or bag. Optimise your workflow by transferring your photos and videos at **incredible speeds** via the high speed USB connection, ready to edit on SanDisk SSDs back in your studio.

- **SanDisk Extreme® 500:** Speedy storage for high-res photos and videos on-the-go
- **SanDisk Extreme® 510:** High-speed, water-resistant storage for high-res photos and videos
- **SanDisk Extreme® 900:** Serious USB 3.1 Gen 2 speed for USB Type C (Also includes USB Type A cable)

USB FLASH DRIVES

SanDisk® USB Flash Drives



SanDisk USB Flash Drives offer a fast, convenient way to back up, share, carry and transfer your files. These flash drives provide enough space to store your photos, videos, music, and other personal files. With their pocket-sized designs and expansive capacities, SanDisk USB drives let you take your files wherever you go.

- **Cruzer Blade™:** Made to fit in your pocket
- **Cruzer Edge™:** Safely carry your data on a keychain
- **Cruzer Facet™:** Faceted texture in rich vibrant colors
- **Cruzer Fit™:** Low-profile storage for notebooks, tablets, TVs, or car audio players
- **Cruzer Glide™:** Retractable slider protects your USB connector
- **Cruzer U™:** U-clip it to your backpack or to your bag
- **SanDisk Ultra Fit™ USB 3.0:** Low-profile storage, transfer speeds up to 10× faster than USB 2.0[®]
- **SanDisk Ultra Flair™ USB 3.0:** Speed meets style with transfer speeds up to 15× faster than USB 2.0[®]
- **SanDisk Ultra® USB 3.0:** Transfer speeds up to 10× faster than USB 2.0[®]
- **SanDisk Extreme® USB 3.0:** Transfer speeds up to 45× faster than USB 2.0[®]
- **SanDisk Extreme PRO® USB 3.0:** Transfer speeds up to 60× faster than USB 2.0[®]

READER

ImageMate® Reader



ImageMate® All-in-One USB 3.0 Reader can transfer your files to your PC quickly, easily and safely.

- Fast and easy data transfer between memory card and computer
- Supports all popular card formats
- Supports up to 500MB/s⁷ interface transfer speed for fast transfer of photos and videos

MP3 PLAYERS

SanDisk® Clip Sport MP3 Players



Listen to music, audiobooks, podcasts, and other digital audio files while you're working out with the **SanDisk® Clip Sport MP3 Player**. Great for athletes or fitness enthusiasts, this lightweight MP3 player clips to your shirt or wristband, allowing you to enjoy music while keeping your hands and pockets free.

- Large color LCD screen for simple navigation during workouts
- Rechargeable battery lasts up to 25 hours¹⁰
- Tangle-free earbuds in matching colors

SanDisk Clip Jam MP3 Players



Clip on the compact and colorful Clip Jam™ digital music player and take it anywhere! The bright one-inch screen and big navigation buttons make it easy to drag, drop and play files in popular audio formats including AAC. Add even more music via the microSD™ card slot for up to 18 hours of big sound.

- Super-lightweight, wearable personal music player
- Deep, rich sound quality
- 8GB internal storage, with a microSD™ card slot
- Up to 18 hour battery life

SanDisk®

* Up to stated speed. Based on internal testing; performance may be lower depending on host device. ** USB 3.0 port required. Based on internal testing; performance may be lower depending upon host device. 1MB=1,000,000 bytes. 1MB = 1,000,000 bytes. 1GB = 1,000,000,000 bytes. Actual user storage less. ² Compatible device required. HD (1280×720), Full HD video (1920×1080), 4K (4096×2160), 4K Ultra video (3840×2160) and 3D video support may vary based upon host device, file attributes and other factors. See: www.sandisk.com/HD. **3** 30 year warranty in Germany, Canada, and regions not recognizing lifetime warranty. See www.sandisk.com/wug. **4** UHS Speed Class 3 designates a performance option designed to support 4K Ultra HD video recording with UHS enabled host devices. UHS Speed Class 1 designates a performance option designed to support real-time video recording with UHS enabled host device. **5** Download required. See www.sandiskmemoryzone.com. **6** See product packaging and www.sandisk.com/proof for additional information and limitations. **7** Based on USB 3.0 specification; performance may vary depending upon use case and host device. 1MB=1,000,000 bytes. **8** For SanDisk Ultra Fit USB 3.0: Read speed up to 130MB/s. 16GB: Write speed to drive up to 5× faster than standard USB 2.0 drives (4MB/s). 32/64GB: Write speed to drive up to 10× faster than standard USB 2.0 drives (4MB/s). For SanDisk Ultra USB 3.0: Read speed up to 100MB/s. 16GB: Write speed to drive up to 5× faster than standard USB 2.0 drives (4MB/s). 32/64/128GB: Write speed to drive up to 10× faster than standard USB 2.0 drives (4MB/s). For SanDisk Extreme USB 3.0: Read speed up to 245MB/s. 16GB: Up to 55MB/s write speed, up to 12× faster than standard USB 2.0 drives (4MB/s). 32GB: Up to 100MB/s write speed, up to 25× faster than standard USB 2.0 drives (4MB/s). 64GB: Up to 190MB/s write speed, up to 45× faster than standard USB 2.0 drives (4MB/s). For SanDisk Extreme PRO USB 3.0 128GB: Up to 240MB/s write speed to drive, up to 60× faster than standard USB 2.0 drives (4MB/s); up to 260MB/s read speed. USB 3.0 port required. Based on internal testing; performance may be lower depending upon host device. 1MB = 1,000,000 bytes. For SanDisk Ultra Flair: Up to 15× faster than standard USB 2.0 drives (4MB/s); up to 150MB/s read speed. **9** Support for .WMV, .AVI, .MKV, .MP4, .MOV video formats. Compatible device required. **10** Based on continuous playback at 128 kbps MP3; actual life and performance may vary depending upon usage and settings; battery not replaceable. **11** Some DRM-protected content cannot be streamed. Check with the content provider for playback restrictions. **12** Video Performance Guarantee enabled to ensure video recording at 65MB/s minimum sustained write speed. **13** As compared to 7200 RPM SATA 2.5" hard drive. Based on published specifications and internal benchmarking tests using PCMark Vantage scores. **14** SanDisk Extreme PRO USB 3.0 Flash Drive: Up to 240MB/s write speed to drive, up to 60 times faster than standard USB 2.0 drives (4MB/s); up to 260MB/s read speed. **15** 64GB only: up to 190MB/s write, up to 60 times faster than standard USB 2.0 drives (4MB/s). SanDisk Extreme USB 3.0 Flash Drives: Up to 245MB/s read speed; 64GB 32GB up to 100MB/s write. 16GB up to 50MB/s write. **16** SanDisk Ultra USB 3.0 Flash Drive: 32GB and 64GB only: write to drive up to 10 times faster than standard USB 2.0 drives (4MB/s); up to 100MB/s read speed. **17** SanDisk Ultra Fit™ USB 3.0 Flash Drive: Write to drive up to 10 times faster than standard USB 2.0 drives (4MB/s); up to 130MB/s read. **18** SanDisk Ultra Flair™ USB 3.0 Flash Drive: Write to drive up to 15 times faster than standard USB 2.0 drives (4MB/s); up to 150MB/s read speed.

SanDisk, CompactFlash, ImageMate, MobileMate, SanDisk Extreme PRO, SanDisk Extreme, SanDisk Ultra and Sansa are trademarks of SanDisk Corporation, registered in the United States and other countries. Telling Life's Stories From Memory, SanDisk Connect, SanDisk ReadyCache, SanDisk Ultra Fit, SanDisk Ultra Flair, SanDisk Blade, SanDisk Edge, SanDisk Facet, SanDisk Fit, SanDisk Force, SanDisk Glide, SanDisk Pop, SanDisk Switch, SanDisk U and iXpand are trademarks of SanDisk Corporation. The SD, SDHC, SDXC, microSD, microSDHC and microSDXC marks and logos are trademarks of SD-3C, LLC. Android is a trademark of Google Inc. Mac, iPad, iPhone and MacBook are trademarks of Apple Inc., registered in the United States and other countries. All other trademarks are the property of their respective owners. ©2016 SanDisk Corporation. All rights reserved. 02/2016

To learn more about SanDisk products and promotions visit www.sandisk.com