



Part Number : [1300940450](#)


Product Description : Heavy Duty Support Grip, Double Eye, Double Weave, Closed Mesh, Cable Diameter 63.50-75.95mm (2.500-2.990"), Approximate Break Strength 4572.21kg (10080 lbs)

Series Number : 130094

Status : Active

Product Category : Cable Grips

Engineering Number : 35430

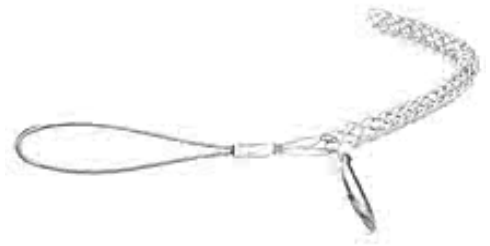

Documents & Resources

Drawings

[PK-130227-004-001.pdf](#)

Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

Part Details

General

Status	Active
Category	Cable Grips
Series	130094
Description	Heavy Duty Support Grip, Double Eye, Double Weave, Closed Mesh, Cable Diameter 63.50-75.95mm (2.500-2.990"), Approximate Break Strength 4572.21kg (10080 lbs)
Product Name	Heavy Duty
Type	Support Grip
UPC	78678835430

Agency

CSA	LR32159
-----	---------

Physical

Approximate Break Strength	4572.21kg (10080 lbs)
Bale Length	0.254m (10.00")
Body Style	Straight
Cable Diameter	63.50-75.95mm (2.500-2.990")
Color - Grommet	N/A
Eye Type	Double
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.965m (38.00")
Net Weight	1.000/g
Number of Holes	N/A
O-Ring	N/A
Thread Size	N/A

This document was generated on Sep 10, 2025