

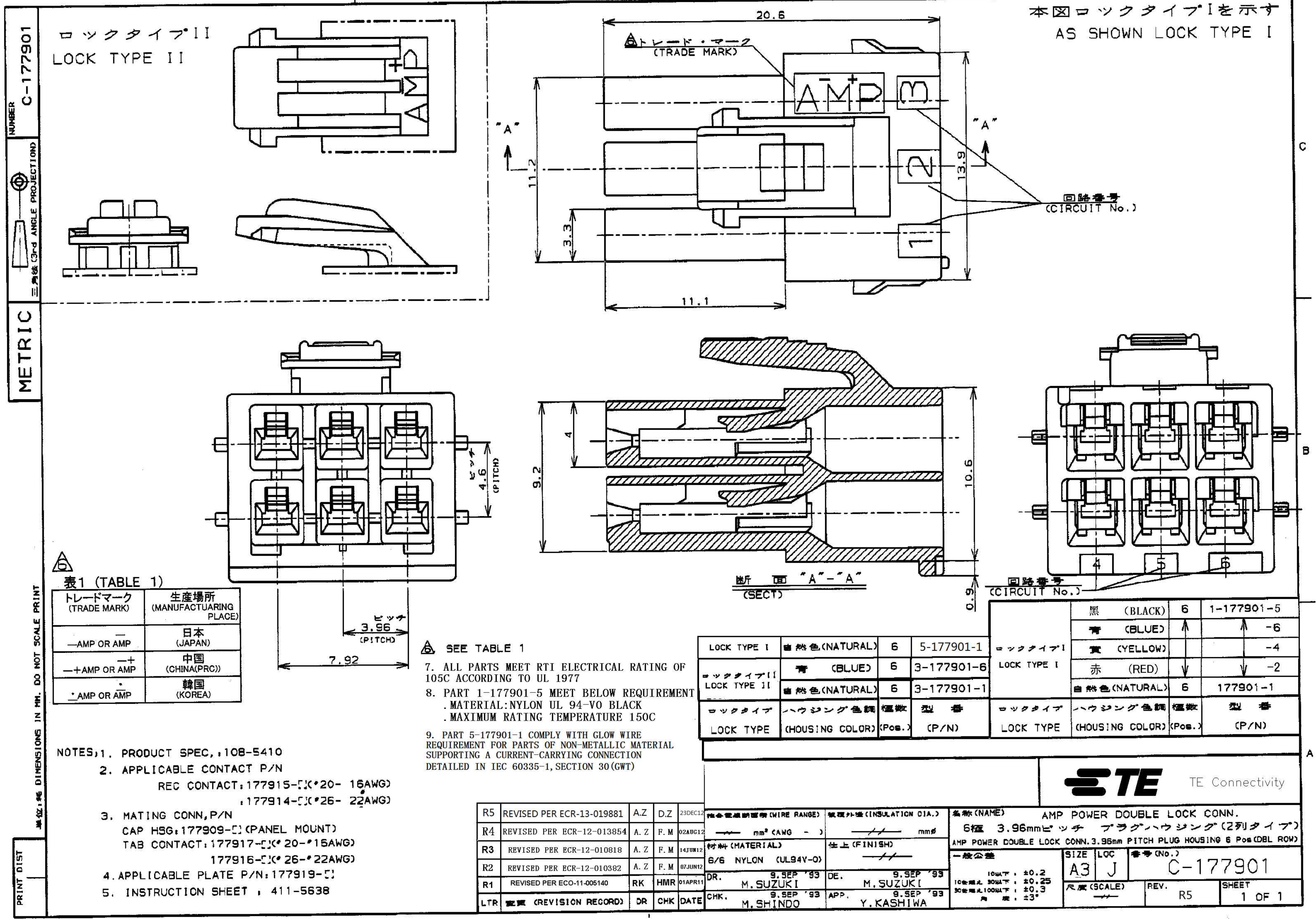


表1 (TABLE 1)

トレードマーク (TRADE MARK)	生産場所 (MANUFACTURING PLACE)
—AMP OR AMP	日本 (JAPAN)
—+AMP OR AMP	中国 (CHINA(PCR))
*AMP OR AMP	韓国 (KOREA)

- NOTES, 1. PRODUCT SPEC, 108-5410
2. APPLICABLE CONTACT P/N
REC CONTACT: 177915-□(×20- 15AWG)
177914-□(×26- 22AWG)
3. MATING CONN, P/N
CAP HSG: 177909-□ (PANEL MOUNT)
TAB CONTACT: 177917-□(×20- 15AWG)
177916-□(×26- 22AWG)
4. APPLICABLE PLATE P/N: 177919-□
5. INSTRUCTION SHEET, 411-5638

- SEE TABLE 1
7. ALL PARTS MEET RTI ELECTRICAL RATING OF 105C ACCORDING TO UL 1977
8. PART 1-177901-5 MEET BELOW REQUIREMENT
MATERIAL: NYLON UL 94-V0 BLACK
MAXIMUM RATING TEMPERATURE 150C
9. PART 5-177901-1 COMPLY WITH GLOW WIRE REQUIREMENT FOR PARTS OF NON-METALLIC MATERIAL SUPPORTING A CURRENT-CARRYING CONNECTION DETAILED IN IEC 60335-1, SECTION 30 (GWT)

R5	REVISED PER ECR-13-019881	A.Z	D.Z	23DEC12
R4	REVISED PER ECR-12-013854	A.Z	F.M	02AUG12
R3	REVISED PER ECR-12-010818	A.Z	F.M	14JUN12
R2	REVISED PER ECR-12-010382	A.Z	F.M	07JUN12
R1	REVISED PER ECO-11-005140	RK	HMR	01APR11
LTR	変更 (REVISION RECORD)	DR	CHK	DATE

LOCK TYPE I	自然色(NATURAL)	6	5-177901-1
ロックタイプII LOCK TYPE II	青 (BLUE)	6	3-177901-6
	自然色(NATURAL)	6	3-177901-1
ロックタイプ LOCK TYPE	ハウジング色調 (HOUSING COLOR)	極数 (Pos.)	型番 (P/N)

ロックタイプI LOCK TYPE I	黒 (BLACK)	6	1-177901-5
	青 (BLUE)	↑	↑ -6
	黄 (YELLOW)	↑	↑ -4
	赤 (RED)	↓	↓ -2
	自然色(NATURAL)	6	177901-1
ロックタイプ LOCK TYPE	ハウジング色調 (HOUSING COLOR)	極数 (Pos.)	型番 (P/N)



R5 REVISED PER ECR-13-019881 A.Z D.Z 23DEC12		名称 (NAME) AMP POWER DOUBLE LOCK CONN.	
R4 REVISED PER ECR-12-013854 A.Z F.M 02AUG12		6極 3.96mmピッチ プラグハウジング (2列タイプ)	
R3 REVISED PER ECR-12-010818 A.Z F.M 14JUN12		AMP POWER DOUBLE LOCK CONN. 3.96mm PITCH PLUG HOUSING 6 Pos (DBL ROW)	
R2 REVISED PER ECR-12-010382 A.Z F.M 07JUN12		一般公差	
R1 REVISED PER ECO-11-005140 RK HMR 01APR11		10以下: ±0.2	
LTR 変更 (REVISION RECORD) DR CHK DATE		10を超え 30以下: ±0.25	
		30を超え 100以下: ±0.3	
		角 度: ±3°	
		SIZE LOC 番号 (No.)	
		A3 J C-177901	
		尺度 (SCALE) REV. R5 SHEET 1 OF 1	