


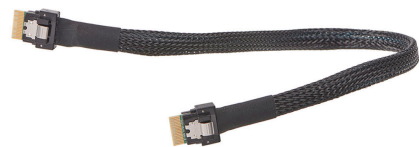

Part Number : 2073681001
Product Description : SlimSAS Cable
Assembly, SAS 4.0, Straight Plug-to-Straight
Plug, 4x (38 Circuits), 32 AWG, 0.30m Length
Series Number : 207368
Status : Active
Product Category : Power and Signal Cable
Assemblies



Documents & Resources

Drawings
2073681001_sd.pdf

Specifications
2073680002-000.pdf

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Reviewed per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Not Reviewed per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Part Details

General

Status	Active
Category	Power and Signal Cable Assemblies
Series	207368
Description	SlimSAS Cable Assembly, SAS 4.0, Straight Plug-to-Straight Plug, 4x (38 Circuits), 32 AWG, 0.30m Length
Assembly Configuration	Dual Ended Connectors
Connector to Connector	SlimSAS-to-SlimSAS
Product Name	SlimSAS
UPC	191130022380

Electrical

Current - Maximum per Contact	0.5A
Impedance	100Ω
Voltage - Maximum	30V AC

Physical

Cable Length	0.30m
Circuits (Loaded)	38
Circuits (maximum)	38
Color - Resin	Black
Gender	Plug/Plug
Lock to Mating Part	Yes
Material - Resin	Polycarbonate
Net Weight	17.200/g
Packaging Type	Bag
Single Ended	No
Wire/Cable Type	Ribbon Cable
Wire Size (AWG)	32

This document was generated on Feb 07, 2025