


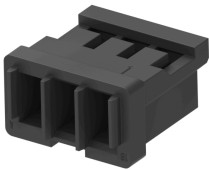

**Part Number :** [874390301](#)  
**Product Description :** 1.50mm Pitch, Pico-SPOX Receptacle Crimp Housing, Single Row, Friction Lock, 3 Circuits, Black  
**Series Number :** 87439  
**Status :** Active  
**Product Category :** Connector Housings



## Documents & Resources

**Drawings**  
[874390301\\_sd.pdf](#)

**3D Models and Design Files**  
[874390301.dxf](#)  
[874390301.pdf](#)  
[874390301\\_stp.zip](#)

**Specifications**  
[874370000-AS-000.pdf](#)  
[SPK-87439-001-001.pdf](#)  
[2027050000-000.pdf](#)  
[2027051000-PS-000.pdf](#)  
[PS-78047-001-001.pdf](#)  
[874371001-PS-001.pdf](#)  
[PS-87437-001-001.pdf](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements  
- Eu RoHS

- REACH SVHC

- Low-Halogen

#### Multiple Part Industry Compliance Documents

- IPC 1752A Class C

- IPC 1752A Class D

- Molex Product Compliance Declaration

- IEC-62474

- chemSHERPA (xml)

#### EU RoHS Certificate of Compliance

---

## Part Details

### General

Status	Active
Category	Connector Housings
Series	87439
Description	1.50mm Pitch, Pico-SPOX Receptacle Crimp Housing, Single Row, Friction Lock, 3 Circuits, Black
Application	Signal, Wire-to-Board
Product Name	Pico-SPOX
UPC	756054763827

### Agency

CSA	LR19980
UL	E29179

### Physical

Circuits (maximum)	3
Color - Resin	Natural
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	48.840/mg
Number of Rows	1

Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.50mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-55° to +105°C

---

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
Pico-SPOX Vertical, Single Row, Surface Mount Headers	<u>87437</u>
Pico-SPOX Right-Angle, Single Row, Surface Mount Headers	<u>87438</u>

### Use with Part(s)

Description	Part Number
Pico-SPOX Female Crimp Terminals	<u>87421</u>

---

This document was generated on Mar 12, 2025