



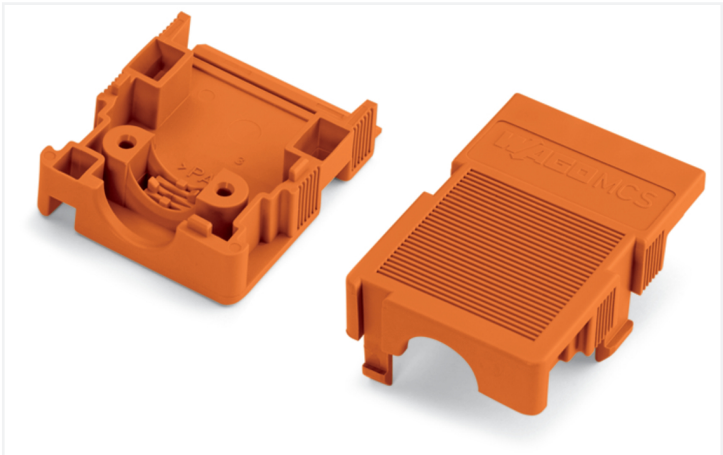

Color: ■ orange                      Similar to illustration

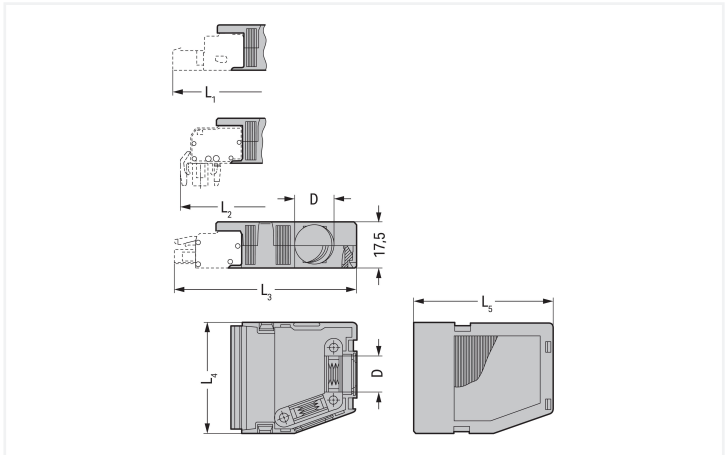

Dimensions in mm  
2- to 3-pole; only suitable for cable ties; 1 cable outlet (rear side); max. 3.6 mm cable tie width  
4- to 6-pole; suitable for cable clamp; 1 x cable outlet (rear side)  
7- to 8-pole; suitable for cable clamp; 1 x cable outlet (rear side) and 1 x cable outlet (side); 1 cover (included)  
9- to 16-pole; suitable for cable clamp; 1 x cable outlet (rear side) and 2 x cable outlets (side); 2 covers (included)  
Cable ties and binding tools are not offered by WAGO.

- Suitable for cable clamp
- 1 x cable outlet, rear

Connection data

| Connection 1 |   |
|--------------|---|
| Pole number  | 6 |

Physical data

|             |                        |
|-------------|------------------------|
| Pin spacing | 5.08 mm / 0.2 inches   |
| Width       | 33 mm / 1.299 inches   |
| Height      | 17.5 mm / 0.689 inches |
| Depth       | 41.5 mm / 1.634 inches |

Mechanical data

|          |                                         |
|----------|-----------------------------------------|
| Suitable | for standard male and female connectors |
|----------|-----------------------------------------|

Material data

|                                                                          |                  |
|--------------------------------------------------------------------------|------------------|
| Note (material data)                                                     |                  |
| <a href="#">Information on material specifications can be found here</a> |                  |
| Color                                                                    | orange           |
| Material group                                                           | I                |
| Insulation material (main housing)                                       | Polyamide (PA66) |
| Flammability class per UL94                                              | V0               |
| Fire load                                                                | 0.335 MJ         |
| Weight                                                                   | 7.4 g            |



| Commercial data       |                        |
|-----------------------|------------------------|
| Product Group         | 3 (Multi Conn. System) |
| PU (SPU)              | 25 pcs                 |
| Packaging type        | Box                    |
| Country of origin     | DE                     |
| GTIN                  | 4017332283120          |
| Customs tariff number | 39269097900            |

| Product Classification |                      |
|------------------------|----------------------|
| UNSPSC                 | 39121421             |
| eCl@ss 10.0            | 27-14-11-92          |
| eCl@ss 9.0             | 27-44-04-92          |
| ETIM 9.0               | EC002848             |
| ETIM 8.0               | EC002848             |
| ECCN                   | NO US CLASSIFICATION |

| Environmental Product Compliance |                        |
|----------------------------------|------------------------|
| RoHS Compliance Status           | Compliant,No Exemption |

| Approvals / Certificates                                                           |          |                  |                                                                                     |          |                   |
|------------------------------------------------------------------------------------|----------|------------------|-------------------------------------------------------------------------------------|----------|-------------------|
| General approvals                                                                  |          |                  | Approvals for marine applications                                                   |          |                   |
|  |          |                  |  |          |                   |
| Approval                                                                           | Standard | Certificate Name | Approval                                                                            | Standard | Certificate Name  |
| KEMA/KEUR<br>DEKRA Certification B.V.                                              | EN 61984 | 71-130478 REV.1  | ABS<br>American Bureau of Ship-<br>ping                                             | -        | 19-HG15869876-PDA |
| UL<br>UL International Germany<br>GmbH                                             | UL 1977  | E45171           |                                                                                     |          |                   |

| Downloads                                   |                                                                                     |
|---------------------------------------------|-------------------------------------------------------------------------------------|
| Environmental Product Compliance            |                                                                                     |
| Compliance Search                           |                                                                                     |
| Environmental Product<br>Compliance 232-636 |  |

| Documentation          |            |                   |                                                                                     |
|------------------------|------------|-------------------|-------------------------------------------------------------------------------------|
| Additional Information |            |                   |                                                                                     |
| Technical Section      | 03.04.2019 | pdf<br>2027.26 KB |  |



| CAD/CAE-Data                                                     |                                                                       |
|------------------------------------------------------------------|-----------------------------------------------------------------------|
| <div>CAD data</div> <div>2D/3D Models 232-636</div> <div>↓</div> | <div>CAE data</div> <div>EPLAN Data Portal 232-636</div> <div>↓</div> |

| 1 Compatible Products        |
|------------------------------|
| 1.1 Optional Accessories     |
| 1.1.1 Installation           |
| 1.1.1.1 Mounting accessories |



|                                                                                      |                                                                                      |
|--------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------|
| <div>Item No.: 209-177</div> <div>Cable clamp; for strain relief; 4- to 6-pole</div> | <div>Item No.: 209-176</div> <div>Fixing screws; for cable clamp; 4- to 6-pole</div> |
|--------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------|


| 1.1.2 Marking  |
|----------------|
| 1.1.2.1 Marker |



|                                                                                                                                                                                                                                                                           |                                                                                                                                                                                                                                                                      |                                                                                                                                                                                                                                                                     |                                                                                                                                                                                                                                                                        |
|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| <div>Item No.: 793-5501/000-006</div> <div>WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; blue</div> <div></div>        | <div>Item No.: 793-5501/000-014</div> <div>WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; brown</div> <div></div>  | <div>Item No.: 793-5501/000-007</div> <div>WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; gray</div> <div></div> | <div>Item No.: 793-5501/000-023</div> <div>WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; green</div> <div></div>  |
| <div>Item No.: 793-5501/000-017</div> <div>WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; light green</div> <div></div> | <div>Item No.: 793-5501/000-012</div> <div>WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; orange</div> <div></div> | <div>Item No.: 793-5501/000-005</div> <div>WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; red</div> <div></div>  | <div>Item No.: 793-5501/000-024</div> <div>WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; violet</div> <div></div> |
| <div>Item No.: 793-5501</div> <div>WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; white</div> <div></div>               | <div>Item No.: 793-5501/000-002</div> <div>WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; yellow</div> <div></div> | <div>Item No.: 793-501/000-006</div> <div>WMB marking card; as card; not stretchable; plain; snap-on type; blue</div> <div></div>                                               | <div>Item No.: 793-501/000-007</div> <div>WMB marking card; as card; not stretchable; plain; snap-on type; gray</div> <div></div>                                                 |
| <div>Item No.: 793-501/000-023</div> <div>WMB marking card; as card; not stretchable; plain; snap-on type; green</div> <div></div>                                                     | <div>Item No.: 793-501/000-017</div> <div>WMB marking card; as card; not stretchable; plain; snap-on type; light green</div> <div></div>                                          | <div>Item No.: 793-501/000-012</div> <div>WMB marking card; as card; not stretchable; plain; snap-on type; orange</div> <div></div>                                             | <div>Item No.: 793-501/000-005</div> <div>WMB marking card; as card; not stretchable; plain; snap-on type; red</div> <div></div>                                                  |
| <div>Item No.: 793-501/000-024</div> <div>WMB marking card; as card; not stretchable; plain; snap-on type; violet</div> <div></div>                                                    | <div>Item No.: 793-501</div> <div>WMB marking card; as card; not stretchable; plain; snap-on type; white</div> <div></div>                                                        | <div>Item No.: 793-501/000-002</div> <div>WMB marking card; as card; not stretchable; plain; snap-on type; yellow</div> <div></div>                                             | <div>Item No.: 2009-115/000-006</div> <div>WMB-Inline; for Smart Printer; 1500 pieces on roll; stretchable 5 - 5.2 mm; plain; snap-on type; blue</div> <div></div>                |
| <div>Item No.: 2009-115/000-007</div> <div>WMB-Inline; for Smart Printer; 1500 pieces on roll; stretchable 5 - 5.2 mm; plain; snap-on type; gray</div> <div></div>                     | <div>Item No.: 2009-115/000-023</div> <div>WMB-Inline; for Smart Printer; 1500 pieces on roll; stretchable 5 - 5.2 mm; plain; snap-on type; green</div> <div></div>               | <div>Item No.: 2009-115/000-017</div> <div>WMB-Inline; for Smart Printer; 1500 pieces on roll; stretchable 5 - 5.2 mm; plain; snap-on type; light green</div> <div></div>       | <div>Item No.: 2009-115/000-012</div> <div>WMB-Inline; for Smart Printer; 1500 pieces on roll; stretchable 5 - 5.2 mm; plain; snap-on type; orange</div> <div></div>              |
| <div>Item No.: 2009-115/000-024</div> <div>WMB-Inline; for Smart Printer; 1500 pieces on roll; stretchable 5 - 5.2 mm; plain; snap-on type; violet</div> <div></div>                   | <div>Item No.: 2009-115</div> <div>WMB-Inline; for Smart Printer; 1500 pieces on roll; stretchable 5 - 5.2 mm; plain; snap-on type; white</div> <div></div>                       | <div>Item No.: 2009-115/000-002</div> <div>WMB-Inline; for Smart Printer; 1500 pieces on roll; stretchable 5 - 5.2 mm; plain; snap-on type; yellow</div> <div></div>            |                                                                                                                                                                                                                                                                        |


Installation Notes

Application

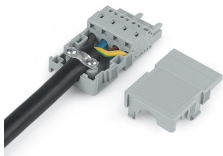


2- to 3-pole; only suitable for cable ties;  
max. 3.6 mm cable tie width  
4- to 16-pole; suitable for cable clamp, co-  
vers (included)  
Cable ties and binding tools are not offered by WAGO.


Installation

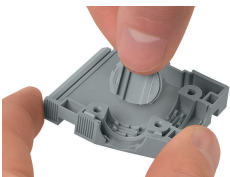

Snapping a cover into the unused cable outlet.

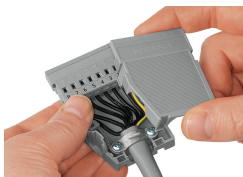

Strain relief housing shown with a male connector equipped with CAGE CLAMP®

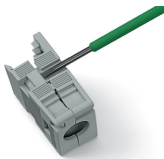

Disassembling a strain relief housing is only possible using an operating tool (e.g., 210-719).