

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1804140001](#)
Status: **Active**
Overview: [LED Array Holders for Citizen and Similar COB Arrays](#)
Description: LED Array Holder for 13.50 by 13.50mm and 19.00 by 19.00mm COB, Gold (Au) Plating, Two-Piece Design, without Tab Cap

Documents:

3D Model	Application Specification AS-180412-001-001 (PDF)
3D Model (PDF)	Packaging Specification PK-180419-002-001 (PDF)
Drawing (PDF)	Test Summary TS-180412-001-001 (PDF)
Product Specification PS-180412-001-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

UL E345583

General

Product Family	Solid State Lighting
Series	180414
Array Type	Citizen
Beam Angle	N/A
Overview	LED Array Holders for Citizen and Similar COB Arrays
Product Name	Wire Trap Holder
Type	LED COB Array Holder
UPC	884982954878

Physical

Base Type	N/A
Color Rendering Index (CRI)	N/A
Correlated Color Temp (CCT)	N/A
Depth	0.60mm
Flammability	94V-0
Lamp Type	N/A
Material - Metal	Copper Alloy
Mounting Style	Screws
Net Weight	1.110/g
Packaging Type	Tray


Electrical

Lamp Wattage - Maximum	N/A
Lumens	N/A
Voltage (Fixture) - Maximum	300V DC
Wiring Style	Poke In Wire Traps

Material Info

Reference - Drawing Numbers

Application Specification	AS-180412-001-001
Packaging Specification	PK-180419-002-001
Product Specification	PS-180412-001-001
Sales Drawing	SD-180414-001
Test Summary	TS-180412-001-001

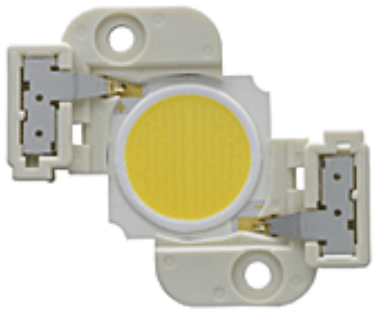

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ECHA_01_2020 (16
January 2020

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[180414](#) Series

Use With

13.50mm by 13.50mm COB|19.00mm by
19.00mm COB

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION