

Product Line

- [DeepTronica](#) >
- [Single Pair Ethernet](#) >
- [ZConnect](#) >
- [Ceres](#) >
- [X-Lok](#) >
- [Accessory](#)
- [Middle Size](#)
- [Mini Size](#)
- [Large Size](#)
- [Standard Size](#)
- [M Series](#) >
- [FLOS & FLOS+](#) >
- [Power](#) >
- [RBL](#) >
- [HS-Lok](#) >
- [NMEA 2000](#) >
- [Heavy Duty Shielded](#) >
- [RJ](#) >
- [USB](#) >
- [SSL](#) >
- [HDMI](#) >
- [DVI](#) >
- [Fiber Optic](#) >
- [RF](#) >
- [Cable Joiner](#) >
- [Cable Gland](#) >
- [Pressure Relief Vent](#) >
- [LED Light Guide](#) >
- [D-Sub](#) >

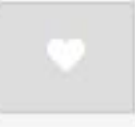


BB-04AFFM-QL8E02

Operating Temperature: -20°C ~ +105°C
Transmission Speed: N/A
Shielded: Plastic, Non-shielded
Jacket Material: PVC
Certificate: UL2238, UL50e

You must login first for view the price

Quantity - 1 +

[Add to Cart](#) [Inquiry](#) 

Can't find? [Customize your part](#)

Mating Pair & Accessories

Connector Type ▼ [Search](#)



X-Lok, Standard...
AB-BB04ML-BBFL...
-20°C ~ +80°C

- 0 +

☐



X-Lok, Standard...
AB-BB04ML-BBFL...
-20°C ~ +80°C

- 0 +

☐



X-Lok, Standard...
AB-BB04ML-BBFL...
-20°C ~ +80°C

- 0 +

☐



X-Lok, Standard...
AB-BB04ML-BBFL...
-20°C ~ +80°C

- 0 +

☐



X-Lok, Standard...
AB-BB04ML-BBFL...
-20°C ~ +80°C

- 0 +

☐



X-Lok, Standard...
AB-BB04ML-BBFL...
-20°C ~ +80°C

- 0 +

☐

[Add to Cart](#) [Inquiry](#)

Specifications	Download / CAD
Nominal Current 10A	Connector Type Overmolded
Shielded Plastic, Non-shielded	No. of Contacts 04
Connector Gender Female	Backshell Straight
Mating Style Push Lock	IP Rating IP68
Assembly Style N/A	
More Options	

People Also Bought

- 

BB-04AFFM-QL8E02
- 

TC-31201A0-A02-...
- 

DD-12AMMM-RL8D03
- 

M12A-05BMMM-...
- 

CB-04RFMC-RC7AA0