



T-3/4 Micro-Midget Flange Base

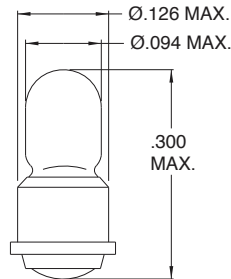


Part Number	Design Voltage	Amps	MSCP	Life Hours	Filament Type
8383	5.0	.080	.150	15,000	C-2R
8538	5.0	.015	.020	1,000	C-2R
8587	5.0	.060	.030	6,000	C-2R
8828	5.0	.075	.090	25,000	C-2R
8913	5.0	.060	.050	25,000	C-2R

T-3/4 Bi-Pin Base (.050")

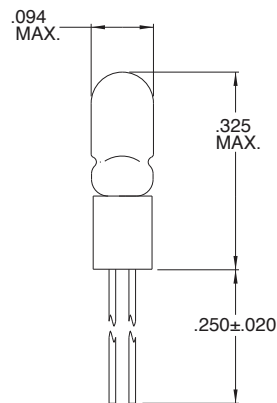

Part Number	Design Voltage	Amps	MSCP	Life Hours	Filament Type
7811	1.5	.015	.01	5,000	C-6
7112	5.0	.021	.03	10,000	C-2
7113	5.0	.060	.03	60,000	C-2R
7114	5.0	.060	.05	25,000	C-2R
7115	5.0	.060	.15	3,000	C-2R
7116	5.0	.075	.09	25,000	C-2R
7117	5.0	.080	.15	15,000	C-2R
7118	5.0	.115	.15	40,000	C-2R
7119	5.0	.115	.20	5,000	C-2R
7538	5.0	.015	.02	1,000	C-2R

T-1 Wire Terminal (short)

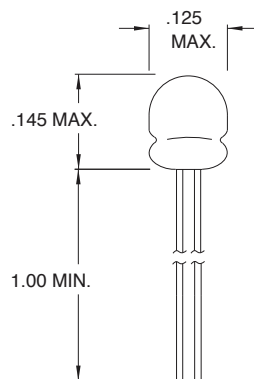

Part Number	Design Voltage	Amps	MSCP	Life Hours	Filament Type
2022	5.0	.021	.030	10,000	C-2R
6152	5.0	.060	.150	5,000	C-2R
6802	5.0	.060	.030	60,000	C-2R
6832	5.0	.060	.050	25,000	C-2R
7132	5.0	.075	.090	25,000	C-2R
7152	5.0	.115	.150	40,000	C-2R
7009	28.0	.024	.150	1,500	CC-2F