




eMMC

# KLMDGAWEBD-B031

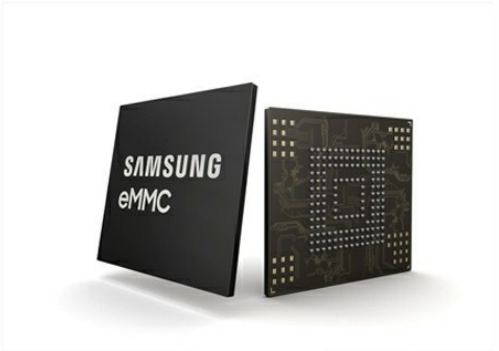

OVERVIEW

SPECIFICATIONS

RELATED RESOURCES

RELATED INSIGHTS

## Definitive Performance for Mobile Storage

With superior power efficiency and noticeably fast speed, Samsung's eMMC is the definitive choice for flash storage to develop slim mobile design.

- Consistent Optimal Speed
- High Performance at Low Power
- Extensive Lineup, Quick Response

## Specifications

|                |                    |           |             |
|----------------|--------------------|-----------|-------------|
| Version        | eMMC 5.0           | Density   | 128GB       |
| Voltage        | 1.8 / 3.3 V        | Interface | HS400       |
| Package Size   | 11.5 x 13 x 1.4 mm | Temp.     | -25 ~ 85 °C |
| Product Status | EOL                |           |             |

SEE ALL

## Related Resources



**Samsung Memory**  
Solutions for Auto  
motive




**Samsung Smart M**  
emory



**Samsung eMMC**

## Related Insights

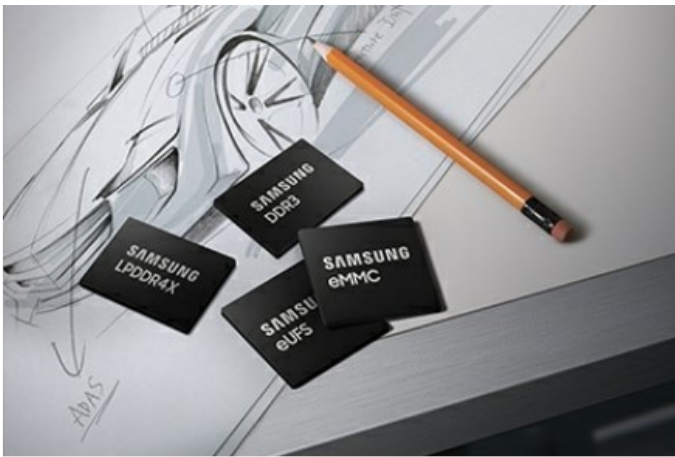

### Samsung Memory Solutions for Automotive

Reliable memory solutions for next level business and driving experience

[LEARN MORE >](#)



### Automotive Driven by Small Packages Under the Hood

Discover Samsung's semiconductor solutions that are used in a wide array of automotive applications.

[LEARN MORE >](#)



All product specifications reflect internal test results and are subject to variations by user's system configuration. All product images shown are for illustration purposes only and may not be an exact representation of the product. Samsung reserves the right to change product images and specifications at any time without notice.

#### Insights

**Product Finder**

**Technical Resources**

**TCO Calculator**

#### PRODUCTS

DRAM

SSD

eSTORAGE

MCP

#### SOLUTIONS

APPLICATIONS

#### Global Sites

Samsung Business [↗](#)

Exynos [↗](#)

LED [↗](#)

#### Follow us



