

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0453391604

Status:


Active

Overview:

HandyLink I/O Interconnect System

Description:

0.80mm Pitch HandyLink Plug for Wire Termination, 16 Circuit (pins 7,10,11,14,15,16 voided)

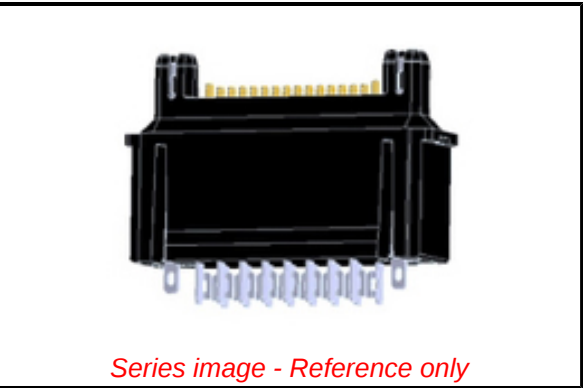

Documents:

3D Model

Drawing (PDF)

Product Specification PS-44828-001-001 (PDF)

Packaging Specification PK-45593-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	I/O Connectors
Series	45339
Application	Wire-to-Board
Comments	Please reference Application Specification AS-44828-001 when designing, Please reference Application Specification AS-44828-001 when designing Plug
Component Type	handylink@molex.com
More Detailed Tech Information	HandyLink I/O Interconnect System
Overview	HandyLink
Product Name	N/A
Type	822348013593
UPC	
Physical	
Circuits (Loaded)	10
Circuits (maximum)	16
Circuits Detail	Terminals 1, 2, 3, 4, 5, 6, 8, 9, 12, 13, loaded
Color - Resin	Black
Flammability	94V-0
Lock to Mating Part	Yes
Material - Metal	High Performance Alloy (HPA), Stainless Steel
Material - Plating Mating	Gold, Tin
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	5.921/g
Orientation	Vertical
PCB Retention	N/A
Packaging Type	Tray
Panel Mount	No
Pitch - Mating Interface	0.80mm
Plating min - Mating	0.102µm, 1.270µm
Plating min - Termination	1.270µm, 5.080µm
Polarized to Mating Part	Yes
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-40° to +85°C
Termination Interface: Style	Solder or Weld
Wire Size AWG	22
Electrical	
Current - Maximum per Contact	1.5A
Shielded	No

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per -ED/88/2018 (15 January 2019)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

45339 Series

Mates With

44828

Voltage - Maximum	30V
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-45593-001
Product Specification	PS-44828-001-001
Sales Drawing	SD-45339-001, SD-45339-001-002

This document was generated on 02/26/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION