



 
Flexible cable support HelaDuct Flex40SK

HelaDuct Flex, Article number: 164-41108



Images (1)

Downloads



Features

- Space-saving wiring system
- Highly flexible, can be installed at angles of 90° and higher
- Cable clearly open to view
- Rapid mounting with screws or adhesive strip with high-quality foam bonding layer

Certifications & Approvals

HF

RoHS

Application

HelaDuct flexible cable supports are commonly used in switching cabinets. They are also used in the furniture industry, where cables need to be routed rapidly and attractively.

HelaDuct Flex is suitable for following markets and industries

Electrical Installation

More products in this product group

[Flexible cable support >](#)

Base Data

Colour	White (WH)
Current leak stable Yes/No	Yes
Description Short (BMEcat) (max. 150 characters)	Flexible cable support 45x48 mm, 500 mm, PP, white
Fixation Method	Screw Mounting and Adhesive
GLOBAL PART DESCRIPTION	HelaDuct Flex40SK-PP-WH
No. of Wires	81 x 2.50 mm²
No. of Wires	81 x 1.50 mm²
No. of Wires	60 x 2.50 mm²
Pack Cont.	24 pcs.
Package Quantity per	box
Product Family	HelaDuct Flex
Product Group	Flexible cable support
Type of side wall	Slotted

Product Dimensions



Diameter (D)	40 mm
Height (H)	48 mm
Inside Ø (ID)	40 mm
Length (L)	500 mm
Max. load on a length of 500 mm at 70 °C (g)	400
Nominal ø	40 mm
Width (W)	45 mm
Width (W2)	5 mm
Width (W3)	8 mm

Material and Specifications



Adhesive	Synthetic rubber with base of polyethylene foam
Adhesive Operating Temperature	-40 °C to +80 °C
ELV compliant (Article 4 - 2)	YES
Flammability	UL 94 V0 (excluding adhesive)
Halogenfree	Yes
Hazardous good	No
Material	Polypropylene (PP)
Operating Temperature - °C	-20 °C to +70 °C, (+80 °C, 200 h)
Self extinguishing (Yes/No) ETIM	Yes
Specifications	 

Logistics and Packaging



More Information



ETIM 5.0	EC000012
ETIM 6.0	EC000012


Further information to HelaDuct Flex40SK



Catalogue page
(December 2017)



All catalogue pages

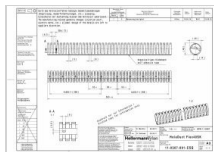

Technical drawing 11-
0307-001-CSG

 [Download >](#)

[More information >](#)

 [Download >](#)

Similar products



HelaDuct Flex10
164-11008
Flexible cable support



HelaDuct Flex20
164-21008
Flexible cable support



HelaDuct Flex30
164-31008
Flexible cable support



HelaDuct Flex40
164-41008
Flexible cable support



HelaDuct Flex10SK
164-11108
Flexible cable support



HelaDuct Flex20SK
164-21108
Flexible cable support

Show all ▾

Stay in touch with us!



Global Company

About us
Worldwide
Philosophy
Environment & Quality
Corporate Social
Responsibility
Product Development
E-Business
ACADEMY
Careers
MADE FOR REAL

Products

Product overview
Cable Ties and Fixings
Insulation
Cable Protection Systems
Electrical Installation
Identification Systems
Application Tooling
Connectivity

Competences

Cable Ties
Heat Shrink Tubing
Industrial Identification
and Self-Adhesive Labels
Cable Protection
Conduits
Electrical Installation
Electrical tape
Wire connectors
Cable rods
Downlight covers
Cable jointing
Gel-filled cable joints
Cable Tie Guns
Connectivity Products
RFID tracking
Cable tie mounts
Thermal Transfer Printer
P-Clamp
Wiring ducts
Cable clips for edges
Cable management high
temperature
applications

Markets & Industries

Automotive Industry
Solar plants
Wind turbines
Shipbuilding
Panel building
Rail industry
Food Industry
Chemical Industry
Aerospace Industry
Defence Industry

Media Centre

Videos
Product Catalogue
2018/2019
Automotive Catalogue
2016/2017
Connectivity Catalogues
2016/2017
Brochures
Software & Drivers
Helatag & Helafix
Templates
Manuals & Operating
Instructions

Events

Update: 07/10/2018

You can easily accept or reject the cookies on this site by choosing one of the following links: [I accept cookies](#) [I refuse cookies](#) [Privacy statement](#)

Contact Terms of Service Imprint Privacy Policy

© Heller