


MOC Clip to MOC Clip Perpendicular, 19 mm, 10 mm Perpendicular, PA66HIRHSUV, Black, 2000/ctn

Part Number: 156-02156

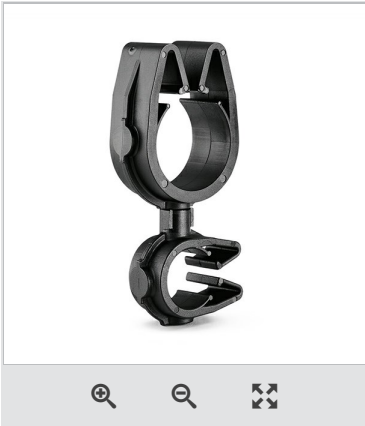

Features & Benefits

- Patented retention design features inverted retaining legs, narrow opening and circular retainer to prevent inadvertent disengagement.
- Controlled flex and angled entry promote easy installation.
- Independent rotation allows for adjustable routing orientation.

Certifications & Approvals



Qty: 1

Add To Order

Downloads

Drawing(s)

Spec Sheet

Base Data	Product Dimensions	Logistic & Packaging	Materials & Specifications
Article Number	156-02156		
Type	MOC19FMOC10M180		
Color	Black (BK)		
Features & Benefits	• Patented retention design features inverted retaining legs, narrow opening and circular retainer to prevent inadvertent disengagement. • Controlled flex and angled entry promote easy installation. • Independent rotation allows for adjustable routing orientation.		
Quantity Per	carton		
Product Description	The MOC to MOC 180 is a rotatable dual routing clip that keeps two routings secured and separated. One clip is orientated 90 degrees from the other to provide alternative access for bundle attachment. A swivel coupler allows them to rotate independently of each other.		
Short Description	MOC Clip to MOC Clip Perpendicular, 19 mm, 10 mm Perpendicular, PA66HIRHSUV, Black, 2000/ctn		



HellermannTyton is a leading global manufacturer of systems and solutions that help world-class customers better manage and identify wire, cable and components.

Contact Us

**HOW CAN WE HELP
YOU?**



**Find Us
Worldwide**



Follow Us

Products

Featured Products
Application Tools
Bundling & Securing
Electrical Installation
Identification
Network Connectivity
Routing, Protection and Insulation

Industries

Aerospace
Automotive
Data Communication
Defense
Energies - Solar
Energies - Wind
Industrial Automation
Machine and Equipment Builders (OEMs)
Medical Equipment
Cable Management
Products For Rail Industry
Truck/Heavy Equipment

Resources

Cross Reference
Literature
Logo Downloads
Materials
Product Selector
Videos & Webinars

About

About HellermannTyton
MADE FOR REAL
The HellermannTyton Difference
Environmental Commitment
North American Locations

Support

Customer Service
ID Solutions
Product Instructions
Product & Certification Training
Quality Certifications
Warranty Policies