

Enter Part #

Pulse-Lok® Configuration Options [Reset](#)

Series	PL-500SM-N Plastic Shell
Housing Material	Plastic
Housing Style	Plug, Cable-Mount
Circuit Count	5
Contact Size	22
Contact Type	Machined, Gold Plated
Contact Plating	Gold
Contact Termination	Solder Cup
Mating Key	1
Max Wire Gauge	22
Max Cable Dia.	0.26
Housing Color	black
Coupling Ring Color	black

Specifications

Environmentally Sealed	Yes
Housing Size	0.500"
Latch Mechanism	Pulse-Lok
Operating Current	3
Operating Voltage	300 V RMS
RF Immunity	No

Configure a Mating Connector [Reset](#)

Contact Termination	Select Option
Contact Type	Machined, Gold Plated
Housing Color	black
Housing Style	Select Option
Max Cable Dia.	0.26
Matching Mating Connectors: 3	

You Selected Part #:

320056

[DOWNLOAD A CAD FILE](#)


[REQUEST A PULSE-LOK® SAMPLE AND / OR QUOTE](#)

[ADD THIS PART TO MY PART LIBRARY](#)

PL-500 Series Plug, Cable -Mount



Circuit Configuration

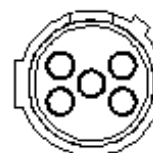

5 Pole, Key 1 (front view)

Component List

Item	Part #	Description	Quantity
1	107138	Interface Seal	1
2	107197-25	Core Assembly	1
3	107713-01	Plug Housing/Coupler Assembly	1

Cable Assembly

