

AMMA00131364100MV1

Search by : [Part Number](#) [Characteristics](#) [Cross reference](#)




NEW ?

Closed Magnetic Circuit Type
Molding Processing & for Ultra High Current

Series Pdf

Product detail		
L(mm) ±		12.9Max.
W(mm) ±		13.2±0.5
T(mm) ±		6.4Max.
Inductance(uH)		10
Tolerance(±%)		20
Test Frequency		100kHz,0.25V
RDC(Ω)Max		0.0172
RDC(Ω)Typ		0.0164
Isat(A)Typ		15.5
Irms(A)Typ		10
Operating Temperature		−55℃~125℃

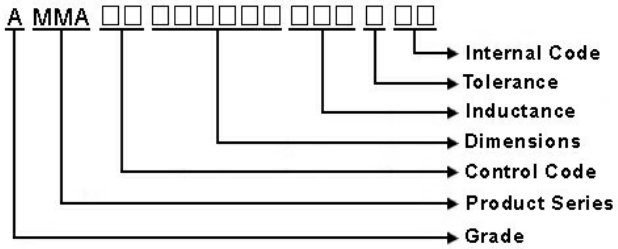

Products

Power Inductor
EMI-Common Mode Choke
EMI-Bead
RF-Signal Inductor
RF-Filter/Antennas
RF-Wireless Power Transfer
LAN Transformer
Resistor & Current Sensor

Applications

Automotive
Industrial
Server/DataCenter
Communication
Mobile and Tablet
Computer/Laptop
Consumer

Design Tools

Simulation Tool
Product Search Engine
E-Catalogue

About Us

Corporate Overview
Corporate Milestones
Core Technology
Certificates & Awards
Quality and Social Responsibility

Investor

Financial Information
Corporate governance
Stakeholder Contacts

News

[Media Center](#)

[New Products](#)

[Events](#)

[Product Notices](#)

Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisin](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisin. All rights reserved.