



Part Number : [1300940472](#)


Product Description : Heavy Duty Support Grip, Double Eye, Double Weave, Split Lace, Cable Diameter 50.80-63.25mm (2.000-2.490"), Approximate Break Strength 4572.21kg (10080 lbs)

Series Number : 130094

Status : Active

Product Category : Cable Grips

Engineering Number : 35444

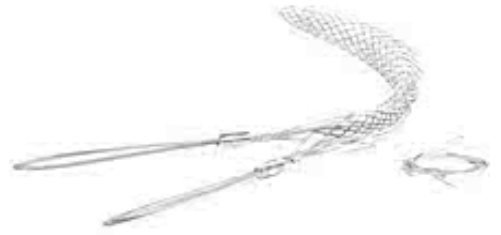

Documents & Resources

Drawings

[PK-130227-004-001.pdf](#)

Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

Part Details

General

Status	Active
Category	Cable Grips
Series	130094
Description	Heavy Duty Support Grip, Double Eye, Double Weave, Split Lace, Cable Diameter 50.80-63.25mm (2.000-2.490"), Approximate Break Strength 4572.21kg (10080 lbs)
Product Name	Heavy Duty
Type	Support Grip
UPC	78678835444

Agency

CSA	LR32159
-----	---------

Physical

Approximate Break Strength	4572.21kg (10080 lbs)
Bale Length	0.254m (10.00")
Body Style	Straight
Cable Diameter	50.80-63.25mm (2.000-2.490")
Color - Grommet	N/A
Eye Type	Double
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.94m (37.00")
Number of Holes	N/A
O-Ring	N/A
Thread Size	N/A