

[Products](#)[Customize Your Parts](#)[Industries Solutions](#)[Search](#)[News & Events](#)[First Time?](#)

[Home](#) / [Products](#) / [FLOS & FLOS+](#) / [B Series C Size](#)

Product Line

Single Pair Ethernet >

ZConnect >

Ceres >

X-Lok >

M Series >

FLOS & FLOS+ >

- Accessory
- B Series A Size
- B Series B Size
- B Series C Size
- B Series D Size
- K Series B Size
- K Series C Size
- K Series D Size
- Y Series B Size

Power >

RBL >

HS-Lok >

NMEA 8088 >

ABOUT AMPHENOL LTW

Heavy Duty Shielded >

RJ >

USB >

SSL >

HDMI >

DVI >

Fiber Optic >

RF >


Cable Joiner >

Cable Gland >

Pressure Relief Vent >

LED Light Guide >

D-Sub >

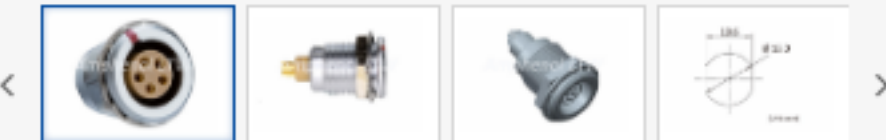

FLBC-02EGFS-GCP-001

Operating Temperature: -40°C ~ +125°C

Transmission Speed: N/A

Shielded: Metal, Shielded

Jacket Material: N/A

Certificate: N/A

You must login first for view the price

Quantity

- 1 +

 Add to Cart

 Inquiry



Can't find? [Customize your part](#)

Mating Pair & Accessories

Connector Type

Search



FLOS & FLOS+,...
CAP-DLBFQME3
-40°C ~ +125°C



FLOS, B Series C Size,...
FLBC-02FGMS-GCP-...
-40°C ~ +125°C



FLOS, B Series C Size,...
FLBC-02FGMS-GCP-211
-40°C ~ +125°C

 Add to Cart

 Inquiry

Specifications	Download / CAD
Nominal Current 15A	Connector Type Receptacle
Shielded Metal, Shielded	No. of Contacts 02
Connector Gender Female	Backshell Circular
Mating Style Push Pull	IP Rating IP50
Assembly Style Solder	
 More Options	

People Also Bought

