

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:


0526741091

Status:

Active

Description:

2.00mm Pitch LCD Pin Connector, Black, 10 Circuits

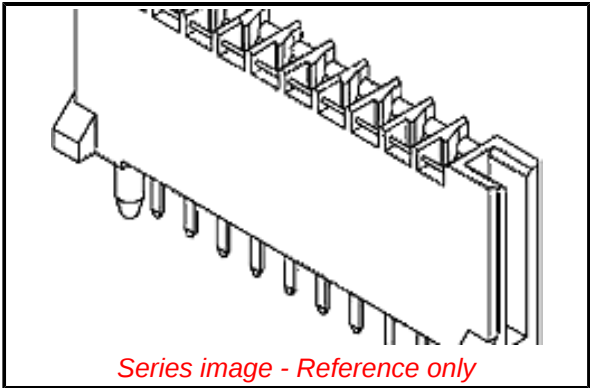

Documents:	
3D Model	Product Specification PS-52674-002 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	Other Sockets
Series	52674
Component Type	Socket
Product Name	2.0 LCD Socket
UPC	800753343405
Physical	
Circuits (Loaded)	10
Circuits (maximum)	10
Color - Resin	Black
Durability (mating cycles max)	10
Entry Angle	Vertical (Top Entry)
Keying to Mating Part	N/A
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	1070.500/mg
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	1.60mm
Packaging Type	Tube
Pitch - Mating Interface	2.00mm
Pitch - Termination Interface	2.00mm
Plating min - Mating	0.914µm
Plating min - Termination	0.914µm
Temperature Range - Operating	-40° to +100°C
Termination Interface: Style	Through Hole
Electrical	
Current - Maximum per Contact	1.0A
Voltage - Maximum	125V
Solder Process Data	
Duration at Max. Process Temperature (seconds)	025
Lead-freeProcess Capability	SMC&WAVE
Max. Cycles at Max. Process Temperature	001
Process Temperature max. C	260
Material Info	
Reference - Drawing Numbers	
Product Specification	PS-52674-002
Sales Drawing	SD-52674-XX21, SD-52674-XX91

EU ELV Compliant	
EU RoHS Compliant	China RoHS
REACH SVHC Not Contained Per -ED/88/2018 (15 January 2019)	
Halogen-Free Status Not Low-Halogen	
For more information, please visit Contact US	
China ROHS ELV	Green Image Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
52674 Series

Mates With
LCD Pin 0.30 x 0.50mm (.012 x .020")

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION