

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0795161063

Status:

Active

Overview:

Micro-Fit 3.0™ Connectors

Description:

Micro-Fit 3.0™ Overmolded Cable Assembly, 6 Circuit, 3.0m Length

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family

Cable Assemblies

Series

79516

Assembly Configuration

Dual Ended Connectors

Comments

When using 30 AWG current max per contact is 5A.

Connector to Connector

Micro-Fit 3.0™ Both Ends

Overview

Micro-Fit 3.0™ Connectors

Product Name

Micro-Fit 3.0™

UPC

822348120529

Physical

Cable Length

3.0m

Circuits (Loaded)

6

Color - Resin

Black

Gender

Female-Female

Lock to Mating Part

Yes

Material - Metal

Phosphor Bronze

Material - Plating Mating

Tin

Material - Plating Termination

Tin

Material - Resin

Polyester

Net Weight

145.700/g

Packaging Type

Bag

Pitch - Mating Interface

3.00mm

Plating min - Mating

1.016µm

Plating min - Termination

1.016µm

Single Ended

No

Wire Insulation Diameter

N/A

Wire Size AWG

26

Wire/Cable Type

Jacketed

Electrical

Current - Maximum per Contact

3.0A

Shielded

No

Voltage - Maximum


250V

Material Info

Reference - Drawing Numbers

Sales Drawing

SD-79516-003

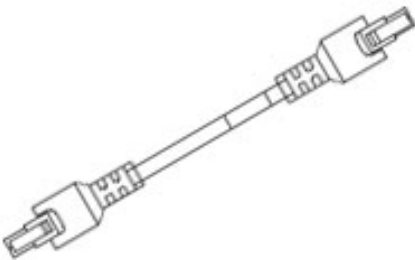

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -

ED/21/2016 (20 June

2016)

Halogen-Free

Status

Not Low-Halogen

Need more information on product

environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

79516 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION