

Tactile Switches

- ***MP3 accessories***
- ***Bluetooth headset***
- ***Remote controls***
- ***Garage door opener***

B

NOTE: Specifications listed above are for switches with standard options.
For information on specific and custom switches, consult Customer Service Center.

Switches in reels of 7,000 pieces.
Dimensions of reels according to EIA 481B
External diameter 330 mm

Termination
G Gullwing

Actuation Force
N 100 gf
M 160 gf
H 200 gf
K 260 gf
G 400 gf
S 600 gf

Body Type
055 0.55mm height for 100, 160, 200 and 260 gf
065 0.65mm height for 400 and 600 gf

Packaging
SMTR Tape & reel

 
LFS RoHS, silver plated



PTS 530 Series
Ultra Low Profile SMT Top Actuated



TERMINATION

G GULLWING





BODY TYPE / ACTUATION FORCE

055 0,55 MM HEIGHT

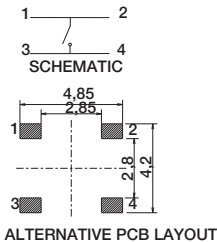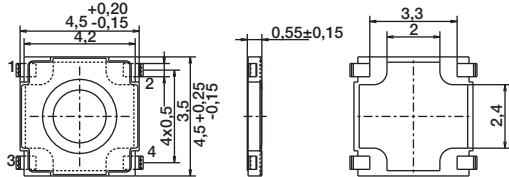


065 0,65 MM HEIGHT

PART NUMBER	HEIGHT
PTS 530 GS 065 SMTR LFS	0,72
PTS 530 GG 065 SMTR LFS	0,68

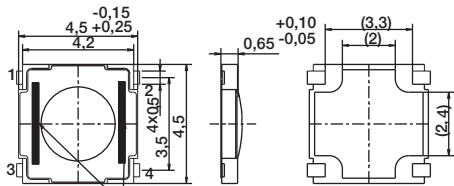 


 
Force symbol lines for 600 gf
No symbol line for 400 gf



Actuation force identification lines:

N: 100 gf	
M: 160 gf	No Lines
H: 200 gf	
K: 260 gf	
G: 400 gf	No Lines
S: 600 gf	

TAPE & REEL

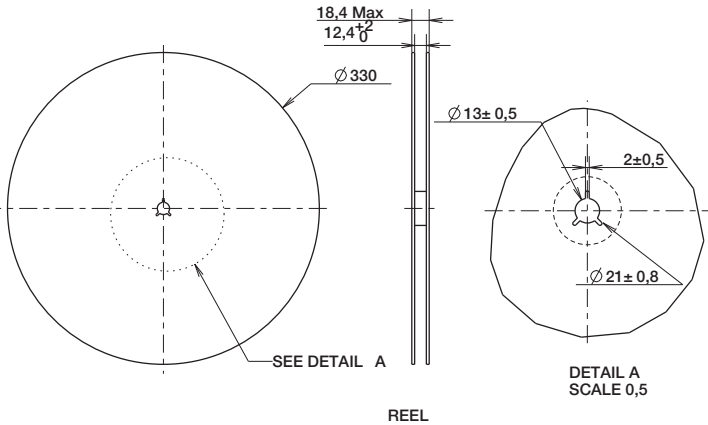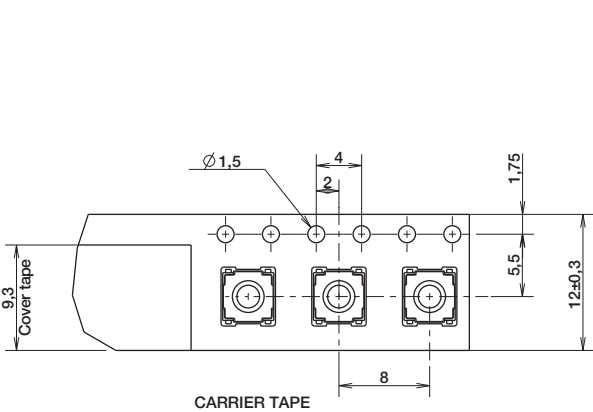

Dimensions are shown: mm
Specifications and dimensions subject to change