



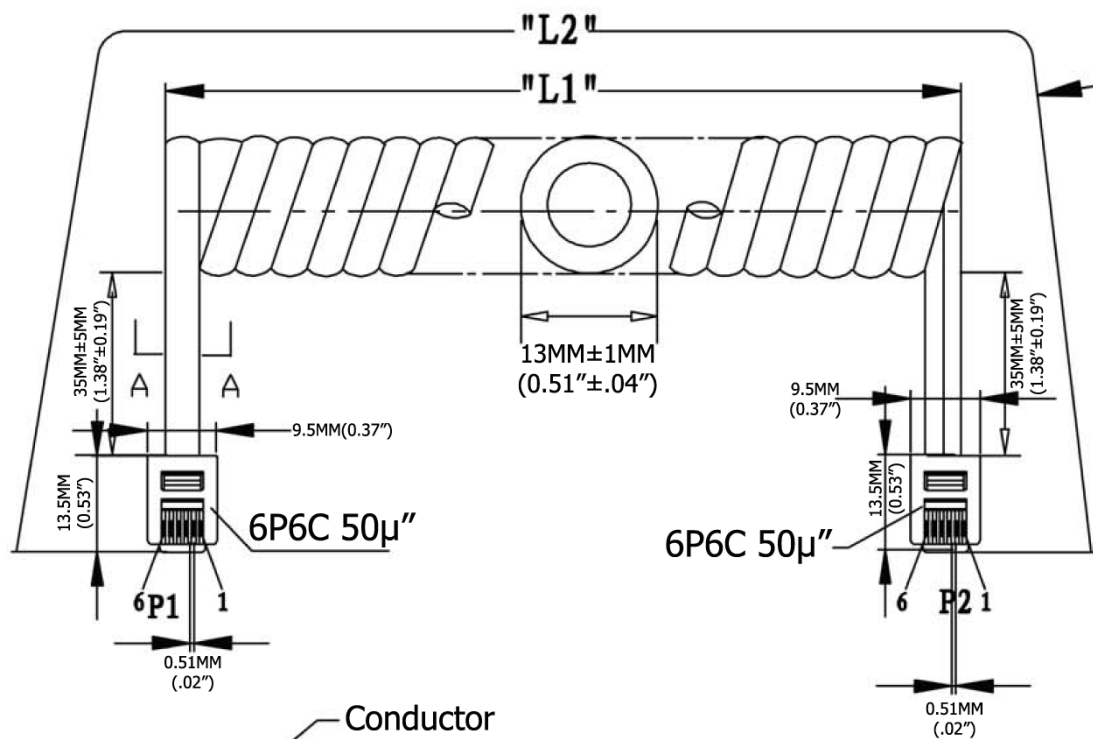

Extended length is with 500g of force

Materials:

- Plug Housing: Polycarbonate, clear
- Plug Terminal: 0.36" [.014MM] Thick Phosphor Bronze
- Connector: 50µ" of Selective Gold Contact Plating
 - Area, Gold flash over the remainder
 - Over 2.54µm [.000100] thick nickel underplate
- Conductor(X4C): 26AWG (0.12X12) Bare Copper
- Insulation(X4C): PP6331 ID 0.95-1.0
- Jacket: PVC NOUL 80P
- Package: Individual PE Bag

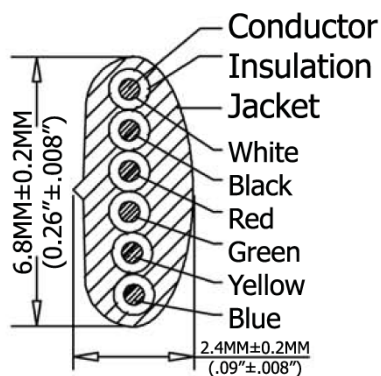

SEC: A-A

P1		P2	
1	WHITE	1	
2	BLACK	2	
3	RED	3	
4	GREEN	4	
5	YELLOW	5	
6	BLUE	6	

Extended Length ("L2")	Typical Retracted Length ("L1")
144.0 Inches - 165.6 Inches	51.5 Inches
3,657.6MM-4,206.24MM	1,308.1MM

RoHS
Compliant

ITEM NO

AT-C-26-6/6/B-12/R

TITLE NON-UL 26AWG (0.16/7)*6C, O.D.: 2.4*6.8MM

Reverse Plug, 50µ" of contact plating, BLACK

ASSMANN
Electronics, Inc.

1840 W. Drake Drive, Suite 101 - Tempe, AZ 85283

Toll Free: 1-877-277-6266 Email: info@usa-assmann.com

THIS DRAWING IS UNPUBLISHED

© Copyright 2009 by Assmann Electronic Components
All International Rights Reserved