

APCA00070745151M00

Search by :

Part Number

Characteristics

Cross reference



MP


Auto

?

SMD Shielded Type
Wire-winding Process & Ultra High Current

Series Pdf

Product detail	
L(mm) ±	7.0±0.2
W(mm) ±	7.4±0.2
T(mm) ±	4.5±0.3
Inductance(uH)	150
Tolerance(±%)	20
Test Frequency	100kHz,1V
RDC(Ω)Max	0.516
Isat(A)Typ	0.8
Isat(A)Max	0.65
Irms(A)	0.95
Operating Temperature	−40℃~125℃(Including self - temperature rise)

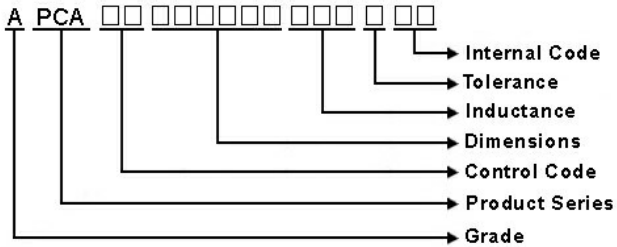

Products

- Power Inductor
- EMI-Common Mode Choke
- EMI-Bead
- RF-Signal Inductor
- RF-Passives/Antennas
- LAN Transformer
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

- Financial Information
- Corporate governance
- Stakeholder Contacts

[Media Center](#)
[New Products](#)
[Events](#)
[Product Notices](#)

Contact Us

[Contact Info](#)
[Contact Form](#)
[Join Chilisín](#)

[Terms of Use](#)
[Privacy policy](#)
[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisín. All rights reserved.