

## For 1/4" x 1/4" Fuses



# Series 8000

### Bolt-in and Snap-in Mounting for 1/4" x 1 1/4" Fuses

**Construction:** Blocks are molded flame retarded thermoplastic. Clips are spring-bronze.

**Voltage Rating:** 300V

**Agency Information:**

UL Recognized : File E14853A, Guide IZLT2

CSA Certified Class 6225-01, File 47235

**Anti-Rotation Pin:** Single pole blocks may be ordered without the antirotational pin simply by adding an "X" to the number of poles (Example: BK/S-8000-1X).

**Carton Quantity:** 10; shelf package: 100.

**Bulk Carton:** Single-pole and 2-pole fuse blocks—1,000; Multiple-pole fuse blocks—3-8 pole; 200; 9-12 pole; 50. When ordering bulk quantities, prefix "BK" to catalog number. (Example: BK/S-8001-1-SNP)

## Bolt-in Mounting

| Series | Terminal                       | Angle             | Basic Cat. No.                | Amperes           | Poles (Suffix) |
|--------|--------------------------------|-------------------|-------------------------------|-------------------|----------------|
| 8000   | Solder                         | 0°                | S-8001-<br>S-8002-            | UL 25A<br>CSA 21A | 1 - 12         |
| 8100   | $\frac{3}{16}$ " Quick Connect | 0°                | S-8101-<br>S-8102-            | UL 20A<br>CSA 13A |                |
| 8200   | $\frac{1}{4}$ " Quick Connect  | 0°<br>40°<br>Side | S-8201-<br>S-8202-<br>S-8203- | UL 20A<br>CSA 16A |                |
| 8300   | Screw                          | —                 | S-8301-                       | UL 30A<br>CSA 25A |                |

## Snap-in Mounting

| Series | Terminal         | Angle | Cat. No.     | Amperes | Poles (Suffix)                |
|--------|------------------|-------|--------------|---------|-------------------------------|
| 8000   | Solder           | 0°    | S-8001-1-SNP | UL 25A  | Available only in single pole |
|        |                  |       | S-8002-1-SNP | CSA 21A |                               |
| 8100   | ¾" Quick Connect | 0°    | S-8101-1-SNP | UL 20A  |                               |
|        |                  |       | S-8102-1-SNP | CSA 13A |                               |
| 8200   | ¼" Quick Connect | Side  | S-8201-1-SNP | UL 20A  |                               |
|        |                  |       | S-8203-1-SNP | CSA 16A |                               |

**Catalog Code**

|                          |     |   |    |     |
|--------------------------|-----|---|----|-----|
| BK/                      | S-8 | 0 | 00 | -00 |
| Prefix for Bulk          |     |   |    |     |
| Packing                  |     |   |    |     |
| Series 8000              |     |   |    |     |
| Product Line             |     |   |    |     |
| Type Terminal            |     |   |    |     |
| "0" - Solder             |     |   |    |     |
| "1" = 3/4" Quick Connect |     |   |    |     |
| "2" - 1/2" Quick Connect |     |   |    |     |
| "3" - Screw              |     |   |    |     |
| Terminal Angle           |     |   |    |     |
| "0" - straight (0°)      |     |   |    |     |
| "2" - 40°                |     |   |    |     |
| "3" - Side               |     |   |    |     |
| Number of Poles (1-12)   |     |   |    |     |



**CE** CE logo denotes compliance with European Union Low Voltage Directive (50-1000Vac, 75-1500Vdc). Refer to Data Sheet: 8002 or contact Bussmann Application Engineering at 636-527-1270 for more information.

\*Available only in single pole




4405

**1/4" x 1/4" Single Pole**  
(6.4mm x 31.8mm)


Bakelite base; spring-bronze, bright tin-lead plate clips; 30A, 250V, base width  $\frac{1}{2}$ " (12.7mm).

**No. 4405**—0° Solder Terminals.

Integral terminal and clip.

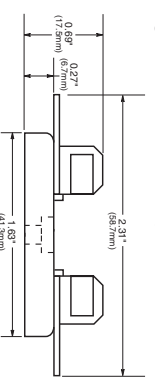


**No. 4406**—Side Solder Terminal  
**No. 4574**—Spare Fuseblock

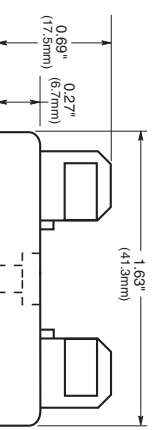

## No. 2499—Side Quick-Connect

Terminals. 1/4" (6.4mm); 15A, 250V.  
UL Recognized,  
Guide IZLT2, File E14853.

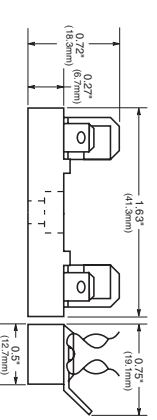

Note—Mounting screw hole diameter is 0.147” (3.7mm). Counterbore diameter, 0.636” (8.0mm). Max. Mounting Screw No. 6.



2499

4574



**For complete specification data, call Bussmann Information Fax ~ 636.527.1450**

**Data Sheet: 2101**