
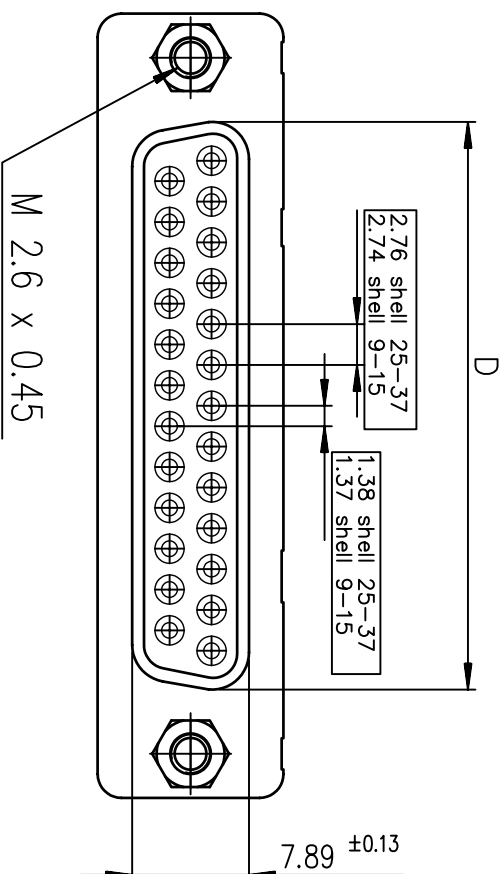


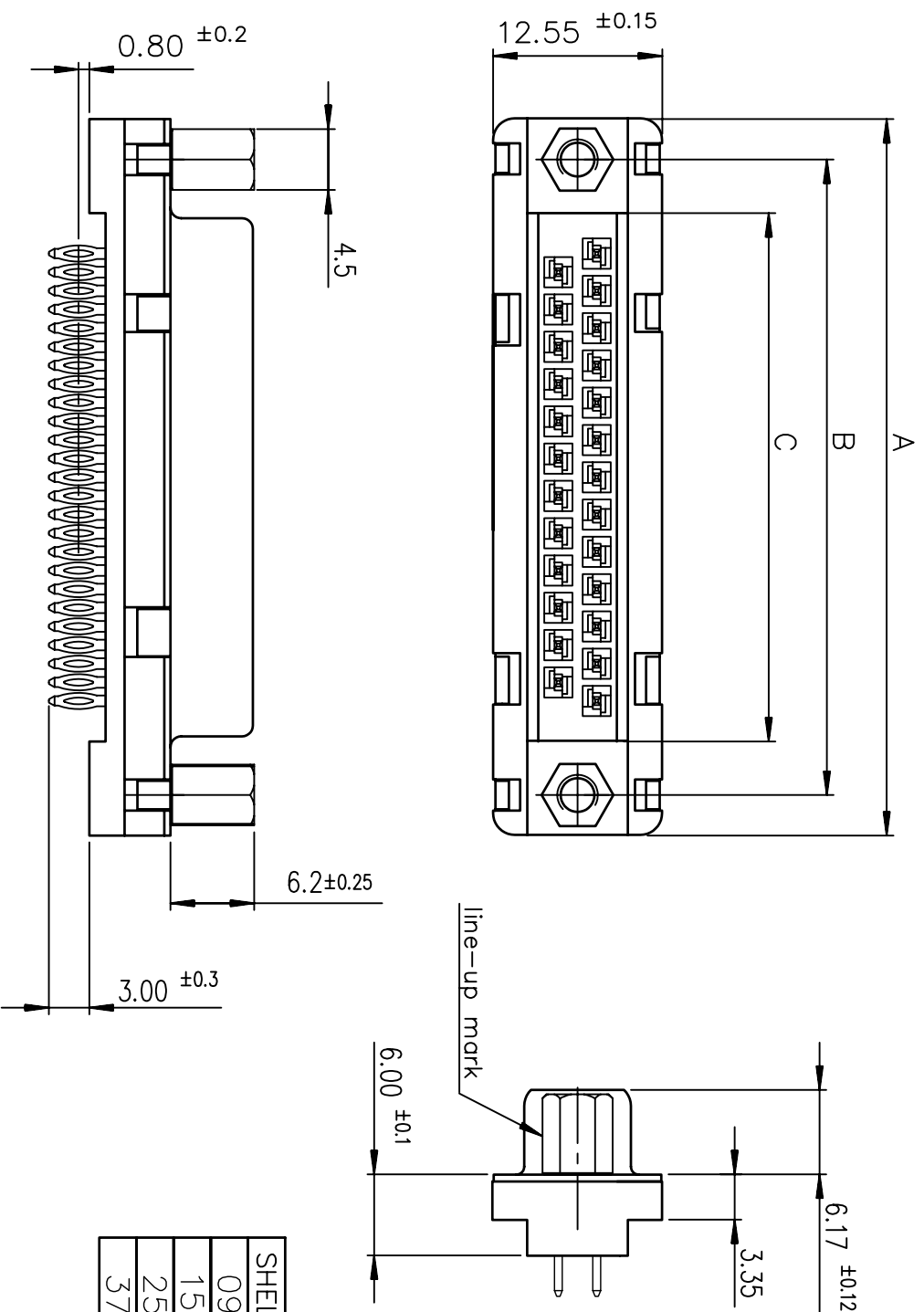


	A ± 0.38	B ± 0.12	C ± 0.10	D ± 0.25	E ± 0.07	PART NUMBER	PART NUMBER
SHELL							
09	30.81	24.99	16.96	16.21	10.96	D09S91C4PS00LF	D09S91C6PS00LF
15	39.14	33.32	25.18	24.54	19.18	D15S91C4PS00LF	D15S91C6PS00LF
25	53.03	47.04	39.12	38.25	33.12	D25S91C4PS00LF	D25S91C6PS00LF
37	69.32	63.50	55.68	54.71	49.68	D37S91C4PS00LF	D37S91C6PS00LF
						200 Matings	500 Matings

- LEAD FREE: ROHS INFORMATIONS

- The "LF" products meet European union Directives and other country regulations as described in GS-22-008.
- Termination plating spec: 0.5 to 3 »m Nickel, 0.5 to 1.5 »m Sn
- Packaging spec: see GS-14-920
- Shell plating : Copper + Nickel + bright pure tin
- Accessories: Copper + Nickel + bright pure tin

 
GENERAL CHARACTERISTICS AND ROHS INFORMATIONS:

SEE DRAWING C01-8646-0001

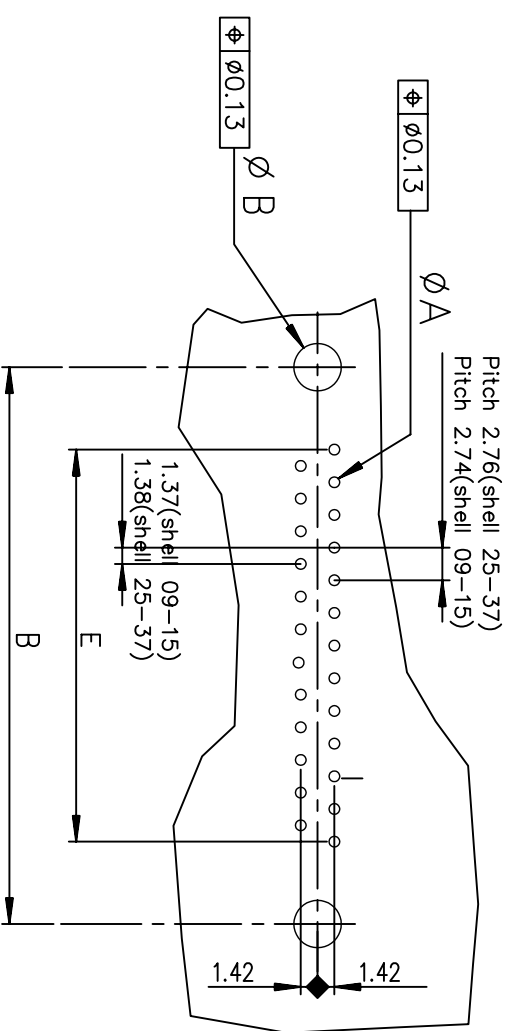

PC CARD LAYOUT

rev	econ no	dr	date
A	-	CJA	2003-11-08
B	-	CJA	2004-01-09
C	-	PCR	2007-12-03
D	09-0219	NG	2009-10-13
-	-	-	-
-	-	-	-
-	-	-	-

www.fciconnect.com		surface ISO 1302		tolerance std ISO 406 ISO 1101	projection 	mm 
		TOLERANCES UNLESS OTHERWISE SPECIFIED				
Dr	C. JARRY	2003-11-08	ANGULAR		size	Scale
Eng	NIRMAL GEORGE	2009-10-13		0.X	A3	2:1
Chr	NIRMAL GEORGE	2009-10-13	LINEAR	0.XX		
Appr	SUDHIR VARMA	2009-10-13	0.XX ± 2°	0.XXX	ECN	-
Product family			D SUB		Spec ref -	
FEMALE DELTA D EUROPE STRAIGHT COMPLIANT PRESS-FIT			D SUB		Rev.	
title catalog no			dwg no		D	
-			C01-8646-0838		CUSTOMER sheet 1 of 1	

