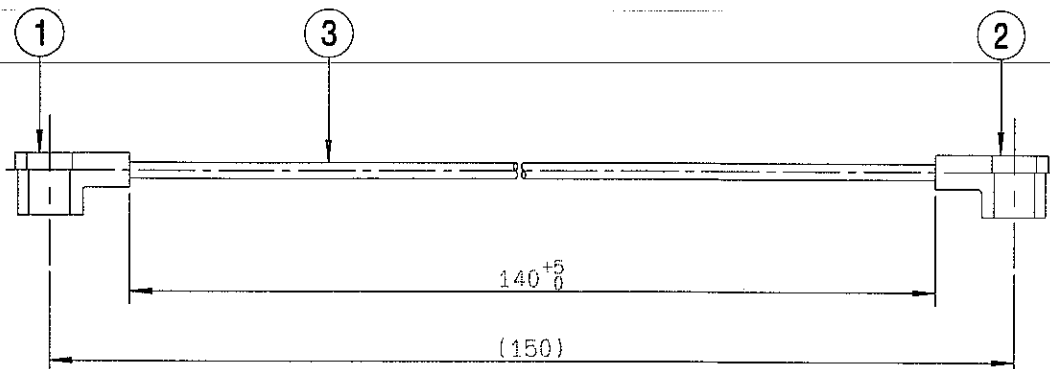


RIGHT ANGLE MALE-MALE MMS**R284V0113003****CABLE 1/50 S-BR, LENGHT: 14 CM****Series : CORD-SPECIF**

* 1 * Connector A : **R209.351.020**
 * 2 * Connector B : **R209.351.020**
 * 3 * Cable : **C291.050.066**
 Type : **CAB 1/55 - 50 VMTX - BLANC**

ELECTRICAL CHARACTERISTICS

Impedance	50 Ω
Frequency	0-3 GHz
Operating temperature	-40/+90 ° C
VSWR	1.31 + 0 x F(GHz) Maxi
Insertion loss	0.421 $\sqrt{F}$(GHz) dB Maxi
Voltage rating	50 Veff Maxi
Dielectric withstanding voltage	250 Veff mini
Insulation resistance	500 MΩ mini

SPECIFICATION**6403-025-000 A 00**

Weight	1 g
Cable retention	15 N mini
Others :	

**Edition : 0120 A**

Design changes may be in order to improve the product.