




WIRE AND CABLE

HOOK UP WIRE

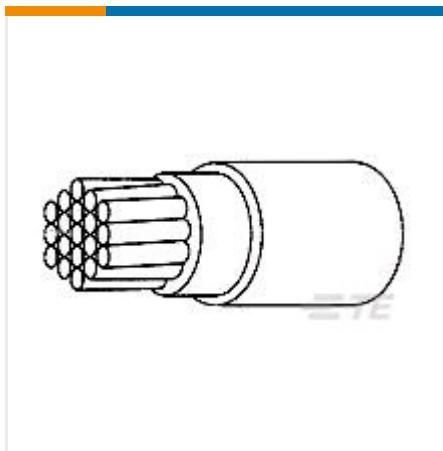

✓ Active

TE CONNECTIVITY (TE)

99M0111-18-1

Raychem | SP

99M0111-18-1

TE Internal Number: 4874733001

Alias ID: 4-1193647-9

EU RoHS Compliant

EU ELV Compliant

Cable Type Spec 99M

Voltage Rating (V) 600

Insulation Material Radiation-Crosslinked, Modified Polyester

Conductor Material Tin-Plated Copper

Wire Size (AWG) 18

PRODUCT DRAWING

English

DOCUMENTATION

Product Drawings

Customer Drawing

PDF

English

FEATURES

Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features



Cable Type Spec 99M
Cable Style Primary
Product Classification Cable - Spec 99 & 100
Product Type Cable

Configuration Features

Number of Strands 19
Number of Conductors 1

Electrical Characteristics

Voltage Rating (V) 600

Body Features

Insulation Material Radiation-Crosslinked, Modified Polyester
Conductor Material Tin-Plated Copper
Wire Color Brown

Dimensions

Strand Size (AWG) 30
Wire Size (AWG) 18
Wire Size (mm²) .823
Conductor Diameter 1.27 mm [.05 in]
Insulation Thickness .15 mm [.006 in]
Overall Outside Diameter 1.75 mm [.0689 in]
Wire Diameter 1.55 mm [.061 in]

Usage Conditions

Operating Temperature Range (°C) -55 – 125

Other

Wire Source United Kingdom

PRODUCT COMPLIANCE



Statement of Compliance

Statement of Compliance

PDF
