


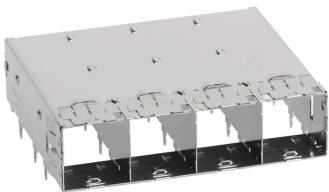

Part Number : [1724735004](#)
Product Description : iPass+ zHD External
Cage Assembly, 1x4, with Press-Fit Pins
Series Number : 172473
Status : Active
Product Category : High-Speed I/O
Connectors



Documents & Resources

Drawings
[1724735004_sd.pdf](#)

Specifications
[1724730001-000.pdf](#)
[1724730100-000.pdf](#)
[1724730011-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474

Part Details

General

Status	Active
Category	High-Speed I/O Connectors
Series	172473
Description	iPass+ zHD External Cage Assembly, 1x4, with Press-Fit Pins
Application	Wire-to-Board
Component Type	External Cage Assembly
Product Name	iPass+,zHD
Type	Pluggable
UPC	191128789714

Electrical

Current - Maximum per Contact	N/A
-------------------------------	-----

Physical

Circuits (Loaded)	0
Lock to Mating Part	Yes
Material - Metal	Stainless Steel
Material - Plating Mating	N/A
Net Weight	9.490/g
Orientation	Right Angle
Packaging Type	Tray
Panel Mount	Yes
PCB Thickness - Recommended	1.57mm
Pitch - Mating Interface	N/A
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Ports	4
Termination Interface Style	Through Hole - Compliant Pin

Use with Part(s)

Description	Part Number
iPass+ zHD Right-Angle External Connector Module, 1x1, Surface Mount, 0.76µm Gold (Au) Plating	<u>1724736001</u>

This document was generated on Apr 23, 2025