


EDSTLZ965/X

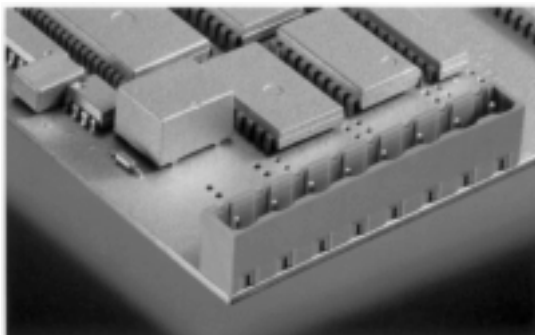

2-16 poles, Spacing 7.62 mm

insert required no. of poles **x**

How to order see page 5



Ratings:

Rated Voltage **300 V**

Rated Current **15 A**

Rating Impulse Voltage/Dirt Level

400 V

12 A (T60)

6 kV/3

Dimensions

Spacing **7.62 mm**

PCB Hole Diameter **1.4 mm**

Materials

Insulating Material **PA/PBTP**

Flammability Class **UL94 V-0**

Temperature Range **-30°C/+105°C**

Contact Pin **Cu**

Color

Green

