


Specification Sheet

Part Number: T50IDH0M4

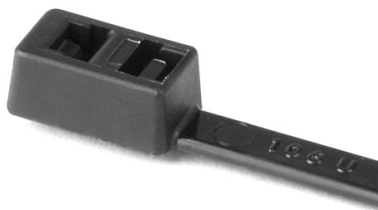

Double-Head Cable Tie, 12" Long, 50lb Tensile Strength, PA66, Black, 1000/pkg

Article Number	117-05300
Type	T50IDH
Color	Black (BK)
Features & Benefits	• The tie contains a dual locking design to secure two bundles at once. • Head design can also provide spacing between parallel bundles. • Bent tail allows for quick insertion into head.
Quantity Per	bag
Product Description	The double head cable tie was designed with a dual locking head that creates two loops to secure two bundles simultaneously. The head also provides separation between bundles or bundles running parallel to each other. The bent tail design allows quick and simple installations by hand. For high volume applications, tensioning tools are available to ensure consistent and safe installation.

Short Description	Double-Head Cable Tie, 12" Long, 50lb Tensile Strength, PA66, Black, 1000/pkg
Global Part Name	T50IDH-PA66-BK
Minimum Tensile Strength (Imperial)	50.0
Minimum Tensile Strength (Metric)	225.0
Length L (Imperial)	12.0
Length L (Metric)	305.0
Identification Plate Position	none
Releasable Closure	No
Tie Closure	plastic pawl
Variant	Inside Serrated
Width W (Imperial)	0.19
Width W (Metric)	4.7
Bundle Diameter Min (Imperial)	0.06
Bundle Diameter Min (Metric)	1.6
Bundle Diameter Max (Imperial)	3.0

Bundle Diameter Max (Metric)	76.2
Bundle Diameter 1st Loop Max (Imperial)	3.0
Bundle Diameter 1st Loop Max (Metric)	76.2
Bundle Diameter 2nd Loop Max (Imperial)	1.5
Bundle Diameter 2nd Loop Max (Metric)	38.1
Thickness T (Metric)	1.4
Material	Polyamide 6.6 (PA66)
Material Shortcut	PA66
Flammability	UL 94 V2
Halogen free	Yes
Operating Temperature (Metric)	-40°F to +185°F (-40°C to +85°C)
ROHS Complaint	Yes
Certification/Specification WEB	UL-ZODZ2.E64139
UL Recognized (US)	Yes
UL Recognized (US and Canada)	Yes

Package Quantity(Imperial)	1000
Package Quantity (Metric)	1000
Customs Number	3926909988

© 2020 HellermannTyton. All Rights Reserved.

[Contact Us](#)

[RoHS/WEEE Compliance](#)

[Disclaimer](#)

[Terms and Conditions](#)