



Part Number : [1211290098](#)


Product Description : mPm DIN Nitrile Profiled Gasket, Form C-8mm and Form C-Micro 9.4mm, 1 Bag of 100

Series Number : 121129

Status : Active

Product Category : Circular Industrial Connectors

Engineering Part Number : 3011-21

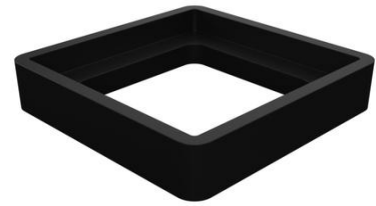

Documents and Resources

Drawings

[1211290098_sd.pdf](#)


[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D

- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

UKCA - Declaration of Conformity

CE - Declaration of Conformity

Part Details

General

Status	Active
Category	Circular Industrial Connectors
Series	121129
Description	mPm DIN Nitrile Profiled Gasket, Form C-8mm and Form C-Micro 9.4mm, 1 Bag of 100
IP Rating	IP65, IP67
Product Name	mPm
Type	Field Attachable Connector
UPC	78678848297

Electrical

Current - Maximum per Contact	N/A
Voltage - Maximum	N/A

Physical

Cable Diameter	N/A
Coupling Type	N/A
Diagnostics / LEDs	No
Diagnostics Port	No
Form	C - Micro 9.4mm
Gender	N/A
Keyway	None
Material - Connector Body	Nitrile

Material - Contact	N/A
Material - Coupling Nut	N/A
Material - Plating Mating	N/A
Net Weight	53.100/g
Orientation	N/A
Pitch - Mating Interface	N/A
Poles	N/A
Temperature Range - Operating	N/A
Wire Size (AWG)	N/A

This document was generated on Jun 02, 2026