


CD-HF 30X100 BU - Cable duct

3240589

<https://www.phoenixcontact.com/us/products/3240589>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

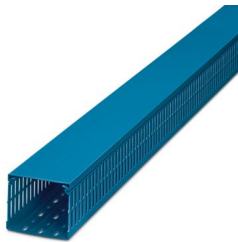

Cable duct for installation and mounting in control cabinets, blue, halogen-free, comprising upper part and mounting base, width: 30 mm, height: 100 mm, length: 2000 mm

Commercial data

Item number	3240589
Packing unit	12 pc
Minimum order quantity	12 pc
Sales key	BE74
Product key	BE7442
Catalog page	Page 579 (C-3-2019)
GTIN	4046356630078
Weight per piece (including packing)	900 g
Weight per piece (excluding packing)	900 g
Customs tariff number	39259020
Country of origin	DE

CD-HF 30X100 BU - Cable duct

3240589

<https://www.phoenixcontact.com/us/products/3240589>



Technical data


Product properties

Product type	Wiring duct
Data management status	
Article revision	01

Connection data

Nominal cross section	1875 mm ²
-----------------------	----------------------

Dimensions

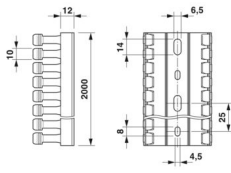Dimensional drawing	
Width	30 mm
Height	2000 mm
Depth	100 mm
Length	2000 mm

Material specifications

Color	blue
Material	PC/ABS
Flammability rating according to UL 94	V0
Components	halogen-free

Cable/line

Halogen-free	yes
--------------	-----

Environmental and real-life conditions

Ambient conditions	
Ambient temperature (operation)	-40 °C ... 90 °C

CD-HF 30X100 BU - Cable duct


3240589

<https://www.phoenixcontact.com/us/products/3240589>



Drawings

Dimensional drawing

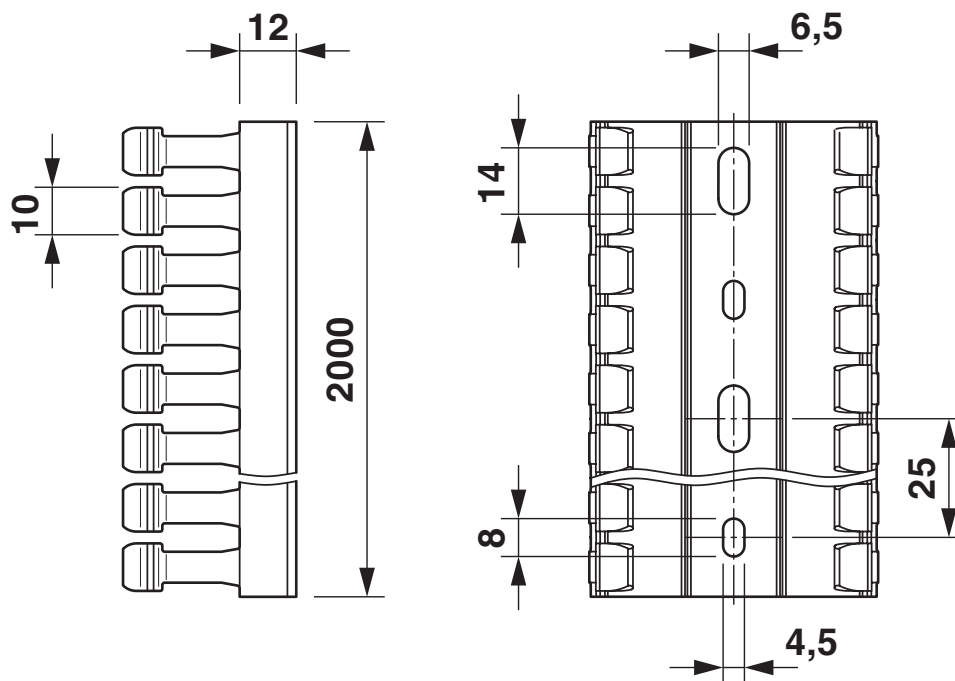

Base perforation according to DIN EN 50085

CD-HF 30X100 BU - Cable duct

3240589

<https://www.phoenixcontact.com/us/products/3240589>



Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/3240589>



CSA

Approval ID: 248269



VDE Zeichengenehmigung

Approval ID: 40028972



EAC

Approval ID: RU C-DE.PB68.W.00513



UL Recognized

Approval ID: FILE E 328576

CD-HF 30X100 BU - Cable duct



3240589

<https://www.phoenixcontact.com/us/products/3240589>

Classifications

ECLASS

ECLASS-11.0	27400703
ECLASS-12.0	27400703
ECLASS-13.0	27400703

ETIM

ETIM 9.0	EC000012
----------	----------

UNSPSC

UNSPSC 21.0	39131700
-------------	----------

CD-HF 30X100 BU - Cable duct

3240589

<https://www.phoenixcontact.com/us/products/3240589>



Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

CD-HF 30X100 BU - Cable duct

3240589

<https://www.phoenixcontact.com/us/products/3240589>



Accessories

RVT-PA 4 - Fastening clip

3240498

<https://www.phoenixcontact.com/us/products/3240498>



Plastic body-bound rivet, for hole diameter of 4 mm and a material thickness of 1.5 ... 6 mm

RVT-PA 6 - Fastening clip

3240499

<https://www.phoenixcontact.com/us/products/3240499>



Plastic body-bound rivet, for hole diameter of 6 mm and a material thickness of 1.5 ... 6 mm

CD-HF 30X100 BU - Cable duct

3240589


<https://www.phoenixcontact.com/us/products/3240589>



CD-HF COVER 30 BU - Cover profile

3240612

<https://www.phoenixcontact.com/us/products/3240612>

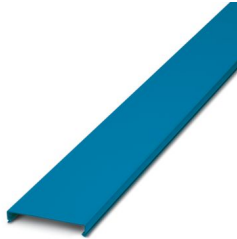

Cover for cable duct, blue, halogen-free, width: 30 mm, length: 2000 mm

UNIFOX-RVT P 4 - Tool

1212478

<https://www.phoenixcontact.com/us/products/1212478>



Rivet setting tool, for use with RVT-PA 4 plastic body-bound rivets

CD-HF 30X100 BU - Cable duct

3240589

<https://www.phoenixcontact.com/us/products/3240589>



UNIFOX-RVT P 6 - Tool

1212509

<https://www.phoenixcontact.com/us/products/1212509>

Rivet setting tool, for use with RVT-PA 6 plastic body-bound rivets



Phoenix Contact 2024 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com