



All Products

Login/Register My Account Cart

- Products ▾
- Industries & Solutions ▾
- Services & Trainings ▾
- Tools & Resources ▾
- About TE ▾
- Shop TE Store

Connectors > PCB Connectors > PCB Headers & Receptacles

2350434-3 ACTIVE


PCB Mount Header, Vertical, Wire-to-Board, 3 Position, 2.5 mm [.098 in] Centerline, Fully Shrouded, Tin, Signal, Natural



TE Internal #: **2350434-3**
 TE Internal Description: **3P RAST2.5 TAB HEADER WO PEG**

Connector System : **Wire-to-Board**
 Number of Positions : **3**
 Number of Rows : **1**
 Centerline (Pitch) : **2.5 mm [.098 in]**
 PCB Mount Orientation : **Vertical**

- [Add to List ▾](#) | [Similar Products](#) |
- [Digital Datasheet](#)

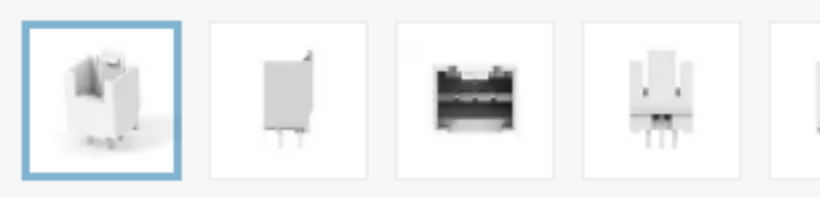

GET FREE SAMPLES

Compatible Parts & Tooling

SHOP OUR DISTRIBUTORS

North America See all price breaks

Distributor	1	10,000	Buy
Digi-Key Electronics 2,543 in-stock	\$0.570	\$0.278	SHOP NOW

We are here to help!
 Get in touch with our product experts.

- [CHAT WITH US](#)
- [EMAIL US](#)
- [CALL US](#)

- Documents
- Features
- Product Compliance

CAD Files	3D PDF
	3D_CVM_CVM_2350434-3_A.pdf
	3D
	Customer View Model
	ENG_CVM_CVM_2350434-3_A.3d_stp.zip
	English
	ENG_CVM_CVM_2350434-3_A.2d_dxf.zip
	English
	ENG_CVM_CVM_2350434-3_A.3d_igs.zip
	English

Product Specifications	Product Specification
	ENG_SS_108-106079_B7.pdf
	English

Compatible Parts

[Filter By Specification](#)

MATING Non-Stocked

1-2304525-3

Standard Edge Connectors, Wire-to-Board, 3 Position, .098 in [2.5...

[VIEW PRODUCT](#)

Products with Similar Specs

[View All Similar Products](#)

THIS PRODUCT	TOP RESULTS		
<p>PCB HEADERS & RECEPTACLES</p> <p>2350434-3</p> <p>PCB Mount Header, Vertical, Wire-to-Board, 3 Position, 2.5 mm [.098...]</p> <p style="text-align: center;">In-Stock</p> <p>Connector System : Wire-to-Board Number of Positions : 3 Number of Rows : 1 Centerline (Pitch) : 2.5 mm PCB Mount Orientation : Vertical</p>	<p>PCB HEADERS & RECEPTACLES</p> <p>2371042-3</p> <p>PCB Mount Header, Vertical, Wire-to-Board, 3 Position, 5 mm [.196 in]...</p> <p style="text-align: center;">Non-Stocked</p> <p>Connector System : Wire-to-Board Number of Positions : 3 Number of Rows : 1 Centerline (Pitch) : 5 mm PCB Mount Orientation : Vertical</p>	<p>PCB HEADERS & RECEPTACLES</p> <p>3-2232960-3</p> <p>PCB Mount Header, Vertical, Wire-to-Board, 3 Position, 2.5 mm [.098...]</p> <p style="text-align: center;">In-Stock</p> <p>Connector System : Wire-to-Board Number of Positions : 3 Number of Rows : 1 Centerline (Pitch) : 2.5 mm PCB Mount Orientation : Vertical</p>	<p>PCB HEADERS & RECEPTACLES</p> <p>2371042-6</p> <p>PCB Mount Header, Vertical, Wire-to-Board, 6 Position, 5 mm [.196 in]...</p> <p style="text-align: center;">Non-Stocked</p> <p>Connector System : Wire-to-Board Number of Positions : 6 Number of Rows : 1 Centerline (Pitch) : 5 mm PCB Mount Orientation : Vertical</p>

Customers Also Bought

<p>TE Part #: 3-647502-3</p> <p>PCB Mount Header, Vertical, Wire-to-Board, 3 Position...</p> <p>\$3.891 per unit Inventory: In-Stock</p> <p>Add To Cart</p>	<p>TE Part #: 2118717-2</p> <p>Board Level Shielding (BLS), Two-Piece, Cold Rolled Steel</p> <p>\$1.052 per unit Inventory: In-Stock</p> <p>Add To Cart</p>	<p>TE Part #: 2118718-2</p> <p>Board Level Shielding (BLS), Two-Piece, Cold Rolled Steel</p> <p>\$1.095 per unit Inventory: In-Stock</p> <p>Add To Cart</p>	<p>TE Part #: 1415899-9</p> <p>Power Relays, Standard, Monostable, DC, 400 mW...</p> <p>View Product</p>
-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------	-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------	-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------	---------------------------------------------------------------------------------------------------------------------------------

Contact Our Team – 24/7 Support

- [+1 800 522 6752](#)
- [Live Chat](#)
- [See Support Details](#)

Connect With Us



Access Partner Information

- [Distributors](#)
- [Suppliers](#)
- [TE Notice on COVID](#)

Get Answers Now

- [Authorized Distributors & Resellers](#)
- [Product FAQs](#)
- [Samples FAQs](#)
- [TE Store FAQs](#)
- [Terms and Conditions of Sale](#)
- [Samples Terms and Conditions](#)

Select Country

- [United States \(EN\)](#)
- [Germany \(DE\)](#)
- [China \(中文\)](#)
- [Japan \(日本語\)](#)
- [See All Countries](#)

Feedback