



Common Mode Choke

TCK-088


Order Code	TCK-088
Inductance (each winding)	521 μ H $\pm$ 35% (at 100 kHz / 100 mV)
Impedance (DCR)	14.25 m Ω max.
Rated Current	7.7 A max.
Rated Voltage	500 VDC max. (between windings)
Operating Temperature	-40°C to +105°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-088

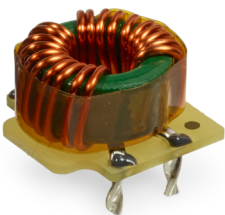

Impedance Curve

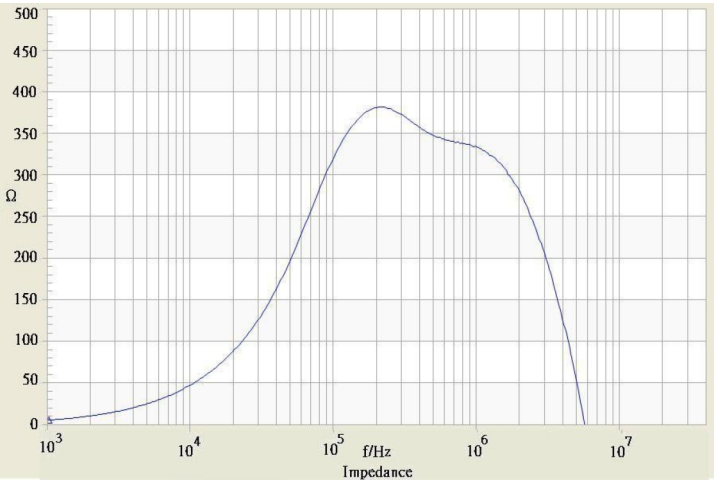

Outline Dimensions

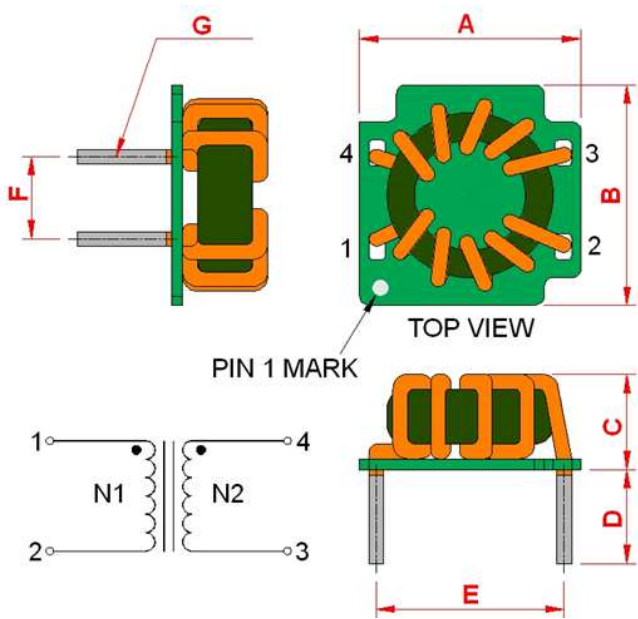

Dimensions [mm]	
A	16.6 $\pm$ 0.4
B	16.4 $\pm$ 0.4
C	12.5 max.
D	5.0 $\pm$ 1.0
E	14.5 $\pm$ 0.5
F	6.1 $\pm$ 0.5
G	$\varnothing$ 0.8 max.

All specifications valid at +25°C, unless otherwise stated.