

SPECIFICATION SHEET



14 AWG 250 Volt Power Extension Cords (C14 to C15)

- Made with heavy duty 14AWG components
- Rated up to 250V and 15A
- CE rated
- TAA compliant
- Lifetime Warranty


Specifications: 14 AWG 250 Volt Power Extension Cords (C14 to C15)

Electrical Specifications:

Voltage Rating:	300V
Amp Rating:	15A
Conductor:	41/0.254MM + 0.002/-0.001

Physical Specifications:

Average Thickness:	0.76mm
Overall Diameter:	ø9.2mm±0.2
Operating Temperature:	-10°C to 70°C; 50±20% RH
Storage Temperature:	-20°C to 50°C; 50±20RH
Approvals:	CE
Warranty:	Lifetime

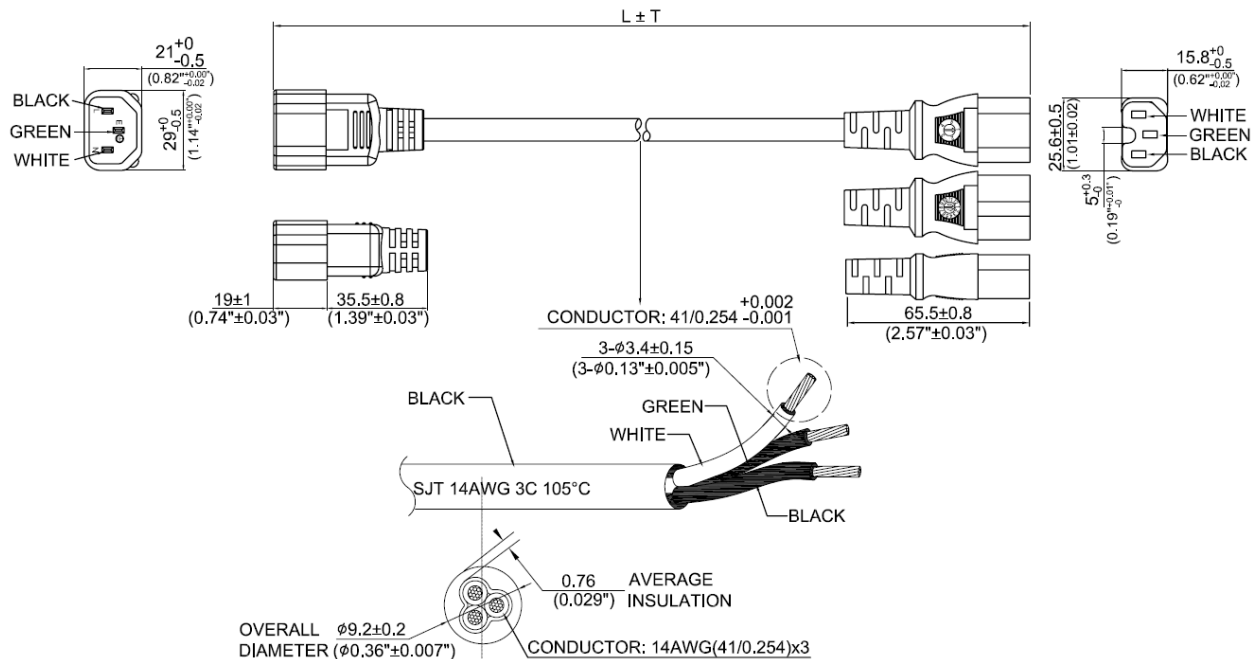

Part Number	Description	Weight (lbs)
10340	3ft 14 AWG 250 Volt Power Extension Cords (C14 to C15)	
10341	6ft 14 AWG 250 Volt Power Extension Cords (C14 to C15)	



CABLES TO GO

Cables To Go
3555 Kettering Blvd.
Moraine, OH 45439
Phone: 800.287.2843
www.c2g.com

Follow Us

