


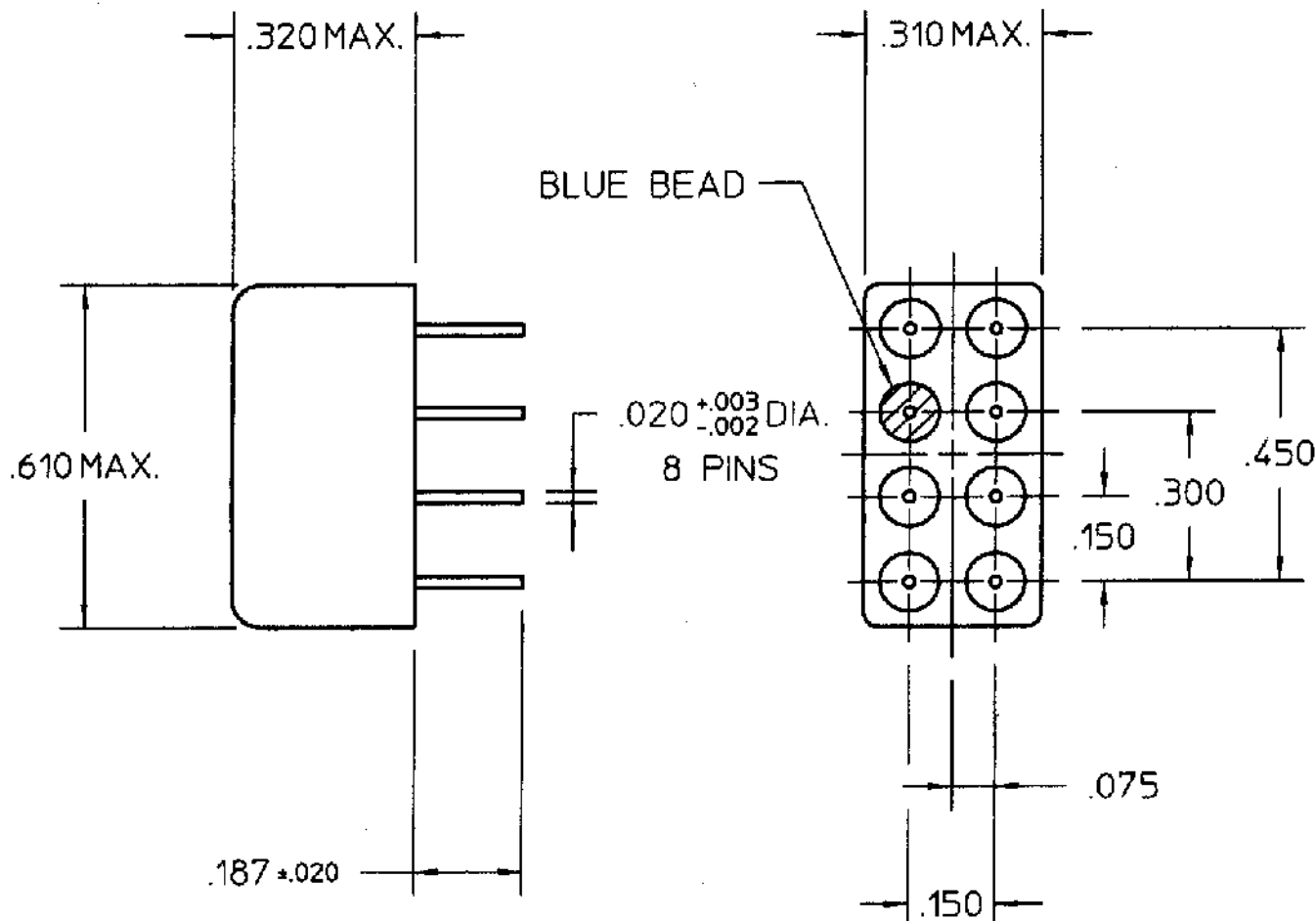

REV. 0

DCO 142026


COIL: @ 25°C
 RESISTANCE 1350 OHMS ± 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 13.5 VDC
 MUST RELEASE 8.1 VDC MAX, 1.5 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 4 MS MAX.
CONTACT STABILIZATION TIME 2.5 MS MAX.

CUSTOMER DATA SHEET

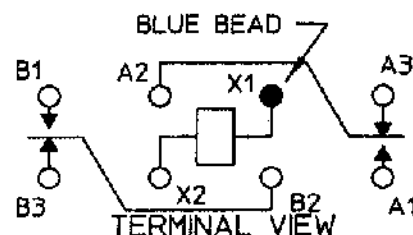

CONTACT RATING: LOW LEVEL TO
2 AMPS 28 VDC RESISTIVE
50,000 OPERATIONS

DR. PBB 5/22/00 CK. TUG 9-13-00

 COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
 CUST. NO. M39016/13-057M REV. 3SBC" RELAY

3SBC1518A2