


IB IL SCN 6-SHIELD-TWIN-GY - Inline shield connector

2862615
<https://www.phoenixcontact.com/us/products/2862615>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

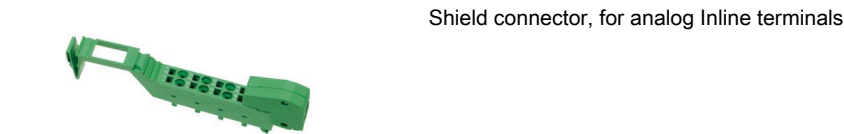

Commercial data

Item number	2862615
Packing unit	5 pc
Minimum order quantity	5 pc
Product key	DRI1Z1
GTIN	4017918902551
Weight per piece (including packing)	23.9 g
Weight per piece (excluding packing)	23.68 g
Country of origin	DE

2862615
<https://www.phoenixcontact.com/us/products/2862615>

Technical data

Product properties

Product type	Plug
--------------	------

Connection data

Conductor cross section, rigid	0.08 mm² ... 1.5 mm²
Conductor cross section, flexible	0.08 mm² ... 1.5 mm²
Conductor cross section AWG	28 ... 16
Stripping length	8 mm

Dimensions

Width	12 mm
Height	130.7 mm
Depth	41 mm

IB IL SCN 6-SHIELD-TWIN-GY - Inline shield connector



2862615

<https://www.phoenixcontact.com/us/products/2862615>

Classifications

ECLASS

ECLASS-11.0	27242692
ECLASS-12.0	27242692
ECLASS-13.0	27242692

ETIM

ETIM 9.0	EC002584
----------	----------

UNSPSC

UNSPSC 21.0	32151600
-------------	----------

2862615
<https://www.phoenixcontact.com/us/products/2862615>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2024 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com