
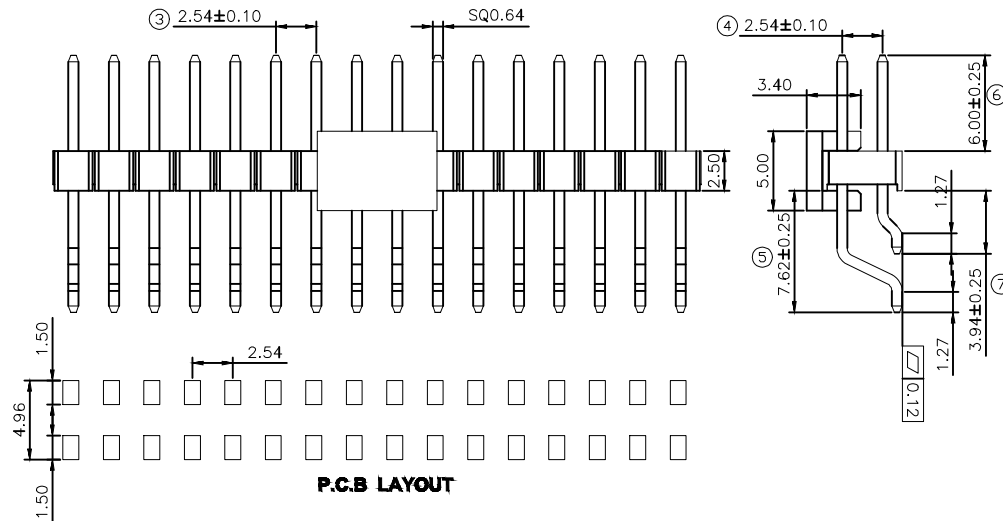


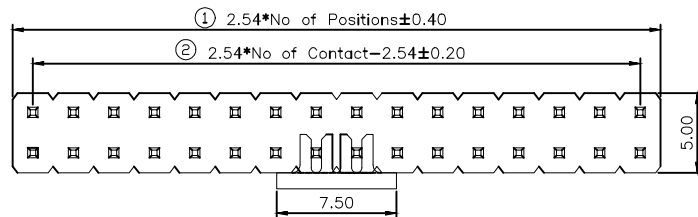

Technical Data

Material:
Contact Material: Brass
Contact plating: Au Plated
Insulator Material: Black Polyester UL94V-0
Standard: PA6T

Electrical:
Current rating: 3.0Amps/contact max.
Contact resistance: ≤20mΩ/contact
Insulation resistance: ≥1000MΩ at V=100V
Withstanding Voltage: 1000V AC/minute

Mechanical:
Mechanical life cycle: min.200
Operating temperatures: Gold Plated: -55° C to +105° C
Soldering temperature: +260° C max(PA6T)

⑤ Ordercode

A-SL254-DA-x xx M R 1:Tape&Reel+Cap:2*2P~2*25P

A-SL254-DA-x xx M P 1:Tube+Cap:2*4P~2*40P

Contact Plating ☐ No. of Contacts
G- Gold Flash
Z-Tin

RoHS compliant

Scale	1:1					Date	Name	Customer-No.
TOLERANCE		⑤	Correct ordercode	28.07.2023	Winnie	Drawn	03.09.2008	N.Schulz
X.	±x.50	④	Update the packing	08.04.2015	Winnie	Approved	28.07.2023	Winnie
X.X	±x.30	③	Change of production plant	14.11.2012	Joanna			
X.XX	±0.20	②	Update	28.08.2009	Dean	ASSMANN WSW components		
DIM	TOL	①	Drawn	03.09.2008	N.Schulz			
X°	±5°							
X.X°	±X°							
Angle	TOL	Id.	Modification	Date	Name			

ASSMANN WSW-No. A-SL254-DA-xxxMx1	
Drawing-No. ASS 2809 CO	rev05
Replace	Sheet